



Main

Product or component type	Shaft coupling
Accessory / separate part destination	Rotary encoder inox with solid shaft
Accessory / separate part category	Coupling accessories
Accessory / separate part type	Homokinetic with bellow
Bore diameter encoder side	0.39 in (10 mm)
Bore diameter machine side	0.39 in (10 mm)

Complementary

Collar material	Stainless steel 316L
Bellow material	Stainless steel 316 L
Maximum angular misalignment	4°
Maximum axial misalignment	+/- 0.5 mm
Maximum lateral misalignment	+/- 0.3 mm
Torque value	<= 7.08 lbf.in (0.8 N.m)
Product weight	0.03 lb(US) (0.015 kg)

Environment


Offer Sustainability

Not Green Premium product	Not Green Premium product
Reference not containing SVHC above the threshold	Reference not containing SVHC above the threshold
WARNING: This product can expose you to chemicals including:	WARNING: This product can expose you to chemicals including:
Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

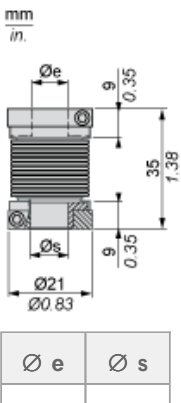



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[XCCRAS1010S](#)