

Product data sheet

Characteristics

XCCRAE0606

shaft coupling - for encoder - elastic monobloc
Ø 6 to 6 mm

Product availability: Non-Stock - Not normally stocked in distribution facility



Main

Product or component type	Shaft coupling
Accessory / separate part destination	Rotary encoder with solid shaft
Accessory / separate part category	Coupling accessories
Accessory / separate part type	Elastic monobloc
Bore diameter encoder side	0.24 in (6 mm)
Bore diameter machine side	0.24 in (6 mm)
Compression expansion	+/- 2 mm

Complementary

Bellow material	Glass fibre reinforced polyamide
Maximum angular misalignment	+/- 2.5°
Maximum radial misalignment	+/- 0.3 mm
Torque value	<= 1.77 lbf.in (0.2 N.m)
Product weight	0.02 lb(US) (0.01 kg)

Ordering and shipping details

Category	21581 - ENCODERS, XCC
Discount Schedule	DS2
GTIN	00785901943785
Nbr. of units in pkg.	1
Package weight(Lbs)	0.02
Returnability	N
Country of origin	FR


Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0701 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and
- - - - - Substance 2	Diisodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

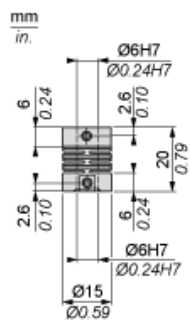

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Schneider Electric:

XCCRAE0606