


GS1AN11

Auxiliary contacts, TeSys GS, 1NC + 1NO,
instantaneous, left side mounting, for GS1-GS2
with front/right handle

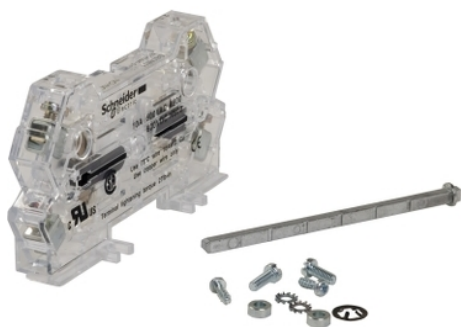

Main

Range of Product	TeSys
Device short name	GS1AN
Product or Component Type	Auxiliary contact
Contact application	O and I position signalling
Contacts type and composition	1 NC + 1 NO
Contact operation	Instantaneous
[I _{th}] conventional free air thermal current	20 A 104 °F (40 °C)
[I _e] rated operational current	1 A 220 V DC-13 10 A 230 V AC-15 12 A 127 V AC-15 4 A 48 V DC-13 6 A 440 V AC-15 8 A 400/415 V AC-15 1.2 A 110 V DC-13

Complementary

Range compatibility	TeSys GS switch-disconnector-fuse
Mechanical durability	30000 cycles
Electrical durability	30000 cycles AC-15
Switch rated current	1250 A 160 A 400 A 50 A 63 A 800 A 250 A 315 A 600 A 125 A 100 A 60 A 200 A 630 A
Fuse type	NFC DIN BS
Type of operating handle	Direct frontal Direct right side External right side External frontal
Net Weight	0.29 lb(US) (0.132 kg)

Ordering and shipping details

Category	22640 - IEC DISCONNECT-GS1,LK3
Discount Schedule	I11
GTIN	3389110563276
Nbr. of units in pkg.	1
Package weight(Lbs)	4.44 oz (126 g)
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	1.18 in (3 cm)
Package 1 width	2.76 in (7 cm)
Package 1 Length	5.12 in (13 cm)
Unit Type of Package 2	S01
Number of Units in Package 2	20
Package 2 Weight	5.96 lb(US) (2.704 kg)
Package 2 Height	5.91 in (15 cm)
Package 2 width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Styrene, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[GS1AN11](#)