

Product availability: Stock - Normally stocked in distribution facility



## Main

Range of product	Zelio Relay
Product or component type	Socket
Contact terminal arrangement	Mixed
Product compatibility	Plug-in relay RPM (1 C/O)
Device short name	RPZ

## Complementary

[I <sub>th</sub> ] conventional free air thermal current	15 A
System Voltage	250 V
Tightening torque	< 0.8 N.m (M3 screw(s)) < 1 N.m (M3.5 screw(s))
Fixing mode	By screw mounting on panel Clip-on mounting on 35 mm symmetrical DIN rail
Product weight	0.07 lb(US) (0.031 kg)

## Environment

Connections - terminals	Contact terminal - screw clamp terminals, 2 wires solid cable without cable end 0.5...4 mm <sup>2</sup> / AWG 20...AWG 12 Contact terminal - screw clamp terminals, 1 wire solid cable without cable end 0.5...4 mm <sup>2</sup> / AWG 20...AWG 12 Contact terminal - screw clamp terminals, 2 wires flexible cable with cable end 0.5...2.5 mm <sup>2</sup> / AWG 20...AWG 14 Contact terminal - screw clamp terminals, 1 wire flexible cable with cable end 0.5...2.5 mm <sup>2</sup> / AWG 20...AWG 14 Coil terminal - screw clamp terminals, 2 wires solid cable without cable end 0.5...2.5 mm <sup>2</sup> / AWG 20...AWG 14 Coil terminal - screw clamp terminals, 1 wire solid cable without cable end 0.5...2.5 mm <sup>2</sup> / AWG 20...AWG 14 Coil terminal - screw clamp terminals, 2 wires flexible cable with cable end 0.5...1.5 mm <sup>2</sup> / AWG 20...AWG 16 Coil terminal - screw clamp terminals, 1 wire flexible cable with cable end 0.5...1.5 mm <sup>2</sup> / AWG 20...AWG 16
Standards	CSA C22.2 No 14 IEC 61984 UL 508
Product certifications	CSA UL REACH CE RoHS China RoHS EAC
Ambient air temperature for storage	-40...185 °F (-40...85 °C)
Ambient air temperature for operation	-40...131 °F (-40...55 °C)
IP degree of protection	IP20 conforming to EN/IEC 60529
Dielectric strength	2500 V

### Ordering and shipping details

Category	21128 - ZELIO ICE CUBE RELAY ACCESSORIES
Discount Schedule	CP2
GTIN	00785901573265
Nbr. of units in pkg.	10
Package weight(Lbs)	8.999999999999997E-2
Returnability	Y
Country of origin	CN


### Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Nickel compounds, which is known to the State of California to cause cancer, and
- - - - - Substance 2	Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm.
- - - - - More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>


### Contractual warranty

Warranty period	18 months
-----------------	-----------

Dimensions

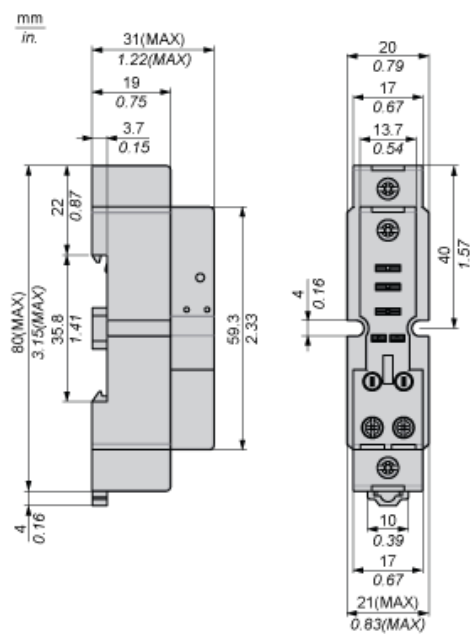

## Wiring Diagram

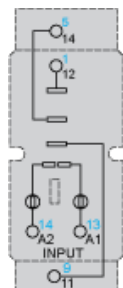

Symbols shown in blue correspond to Nema marking.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[RPZF1](#)