

# RPZF4

socket RPZ - mixed contact - 16 A - < 250 V -  
screw clamp - for relay RPM4

Product availability: Stock - Normally stocked in distribution facility



## Main

|                               |                           |
|-------------------------------|---------------------------|
| Range of product              | Zelio Relay               |
| Product or component type     | Socket                    |
| Contact terminal arrangement  | Mixed                     |
| Product compatibility         | Plug-in relay RPM (4 C/O) |
| Shape of pin                  | Flat                      |
| Device short name             | RPZ                       |
| Sale per indivisible quantity | 10                        |

## Complementary

|                                                          |                                                                              |
|----------------------------------------------------------|------------------------------------------------------------------------------|
| [I <sub>th</sub> ] conventional free air thermal current | 15 A                                                                         |
| System Voltage                                           | < 250 V                                                                      |
| Tightening torque                                        | < 1 N.m (M3.5 screw(s))                                                      |
| Fixing mode                                              | By screw mounting on panel<br>Clip-on mounting on 35 mm symmetrical DIN rail |
| Marking                                                  | CE                                                                           |
| Width                                                    | 1.97 in (50 mm)                                                              |
| Product weight                                           | 0.21 lb(US) (0.094 kg)                                                       |

## Environment

|                                       |                                                                                                                                                                                                                         |
|---------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Connections - terminals               | - screw clamp terminals, flexible cable with cable end 1 x 0.25...2 x 1 mm <sup>2</sup> / AWG 22...AWG 17<br>- screw clamp terminals, solid cable without cable end 1 x 0.5...2 x 1.5 mm <sup>2</sup> / AWG 20...AWG 16 |
| Standards                             | IEC 61984                                                                                                                                                                                                               |
| Product certifications                | CSA<br>UL                                                                                                                                                                                                               |
| Ambient air temperature for storage   | -40...185 °F (-40...85 °C)                                                                                                                                                                                              |
| Ambient air temperature for operation | -40...131 °F (-40...55 °C)                                                                                                                                                                                              |
| IP degree of protection               | IP20 conforming to EN/IEC 60529                                                                                                                                                                                         |
| Dielectric strength                   | 2500 V                                                                                                                                                                                                                  |

## Ordering and shipping details

|                       |                                          |
|-----------------------|------------------------------------------|
| Category              | 21128 - ZELIO ICE CUBE RELAY ACCESSORIES |
| Discount Schedule     | CP2                                      |
| GTIN                  | 00785901635697                           |
| Nbr. of units in pkg. | 10                                       |
| Package weight(Lbs)   | 0.20999999999999999                      |
| Returnability         | Y                                        |
| Country of origin     | CN                                       |


Offer Sustainability

|                           |                                                                                                                            |
|---------------------------|----------------------------------------------------------------------------------------------------------------------------|
| California proposition 65 | WARNING: This product can expose you to chemicals including:                                                               |
| ----- Substance 1         | Nickel compounds, which is known to the State of California to cause cancer, and                                           |
| ----- Substance 2         | Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. |
| ----- More information    | For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>                              |

Contractual warranty


|                 |           |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

## Dimensions

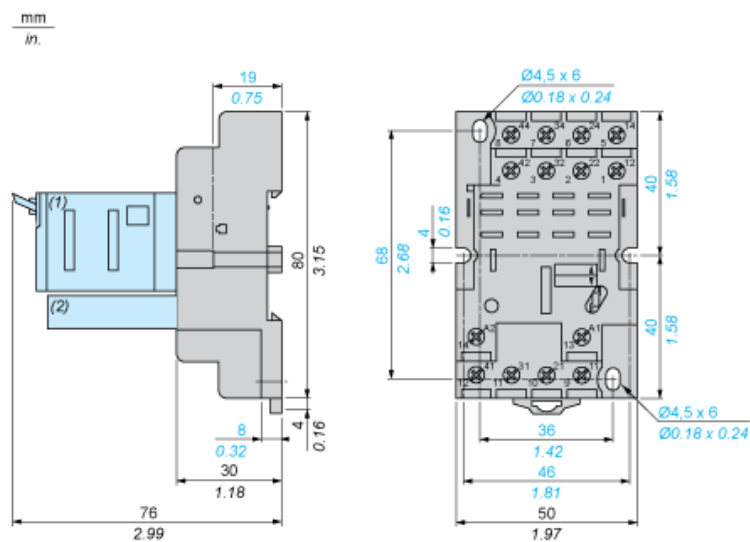

- (1) Relays
- (2) Protection module
- (3) Maintaining clamp

## Wiring Diagram

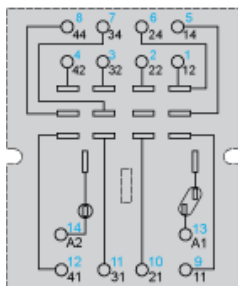

Symbols shown in blue correspond to Nema marking.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[RPZF4](#)