


Schneider Electric Relays
200 N. Martingale Rd., Suite 1000
Schaumburg, IL 60173
Phone: 847-441-2540 • **Fax:** 847-881-0741
E-Mail: relays@schneider-electric.com • **Web site:** www.serelays.com

ALL CATEGORIES > 976 SERIES RELAYS > ITEM # 976XBXH-240A

ITEM # 976XBXH-240A, SLIM-LINE PCB RELAY / DPDT, 5 AMP RATED

Less than 1 cubic inch

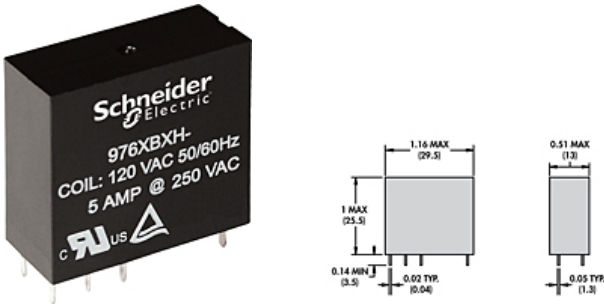

Specifications

Status	Standard
Check Inventory	Check Distributor Inventory
Contact Configuration	DPDT
Nominal Input Voltage	240 VAC 50/60 Hz
Coil Resistance (Ohms)	22000 Ohm
Current Rating	5 A
Contact Materials	Silver Alloy
Switching Voltage (AC, Resistive)	5 A at 240 VAC 50/60 Hz
Switching Voltage (DC, Resistive)	5 A at 30 VDC
Operating Range - % of Nominal (DC)	85 to 110 %
Average Consumption (AC / VA)	1.20 VA
Average Consumption (DC / W)	0.53 W
Drop-out Voltage Threshold (AC)	30 %
Drop-out Voltage Threshold (DC)	10 %
Electrical Life, Operations at Rated Current (Resistive)	100000
Mechanical Life, Unpowered	10000000
Operating Time (Response Time)	15 ms
Dielectric Strength - Between Poles (AC)	1000 V(rms) 5000 V(rms)
Vibration Resistance - Operational	3 g-n at 10-55 Hz
Shock Resistance	10 g-n

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[976XBXH-240A](#)