


SERPAC 191Ri9V

ELECTRONIC ENCLOSURES

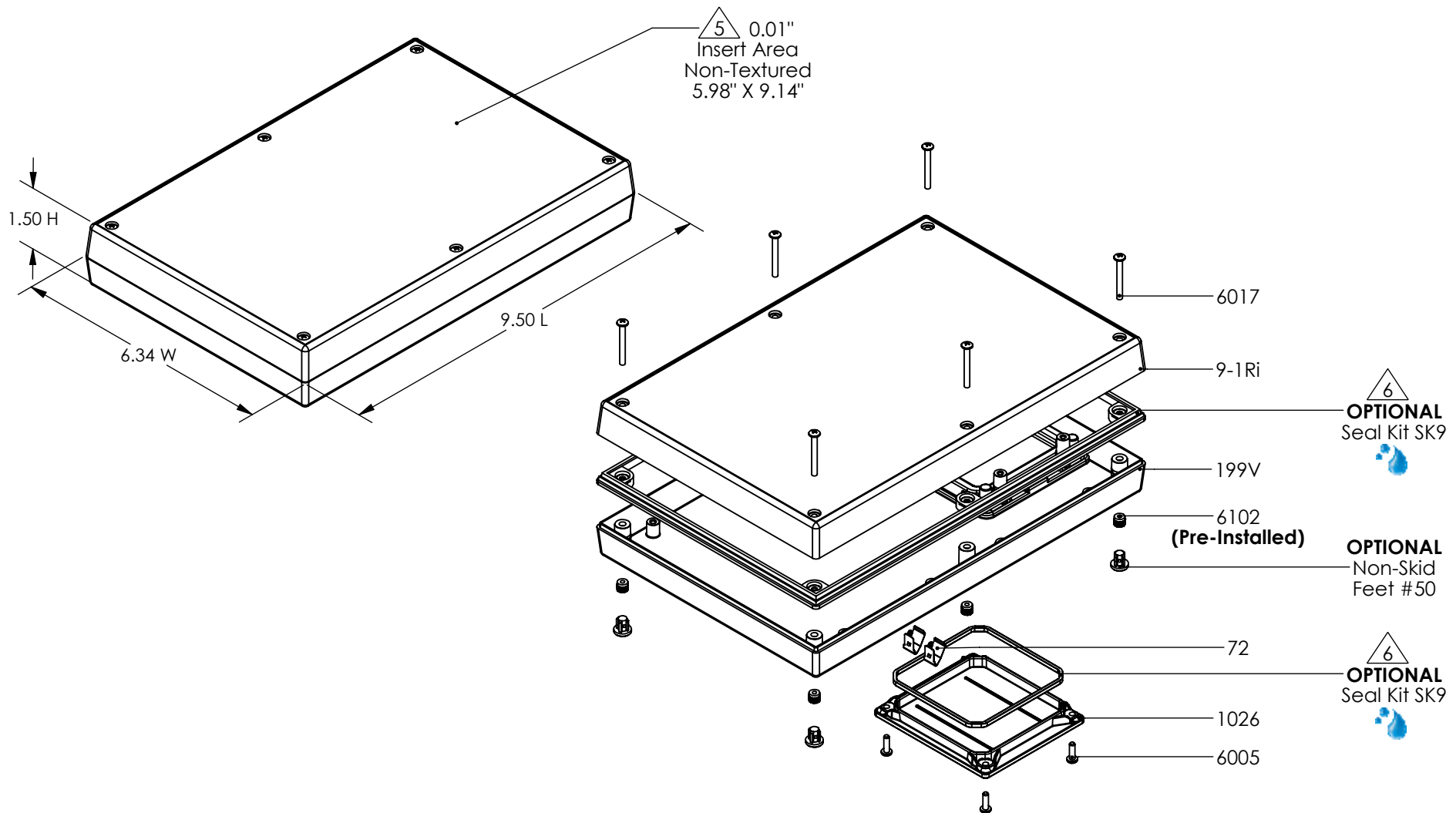





PART NO.	DESCRIPTION (Included)	PART NO.	DESCRIPTION
9-1Ri	Top	1030	Pocket Clip
199V	9V Bottom	50	Non-Skid Feet
6005	#4X3/8" Self-Tapping Screw (4)	55	Key Holder
1026	Access Door	60	Standoff Hole
72	Single Battery Contact (2)	61	Standoff Post
6017	4-40 x 1" Screw (4)	SK9	Waterproof Seal Kit
6102	4-40 Threaded Inserts (4)		

Notes: Enclosure weight .67 lb / 304 g


- 1) Enclosure meets or exceeds IP40 and NEMA 1
- 2) Circuit Board drawings see sheet 3.
- 3) All components are RoHS Compliant.
- 4) Material: Top and Bottom ABS.
- 5) Customizable molding area.
- 6) When used with SK9 the enclosure meets or exceeds IP 67 and NEMA 4X, 12 and 13 MIL-STD-810G 506.5 (.04 lb / 19g)

SERPAC 191Ri9V



ELECTRONIC ENCLOSURES

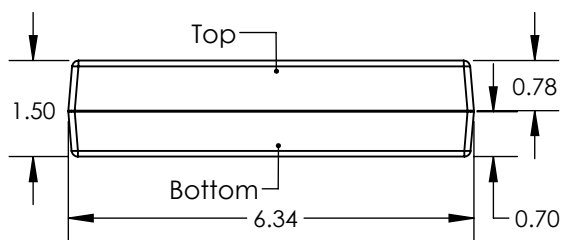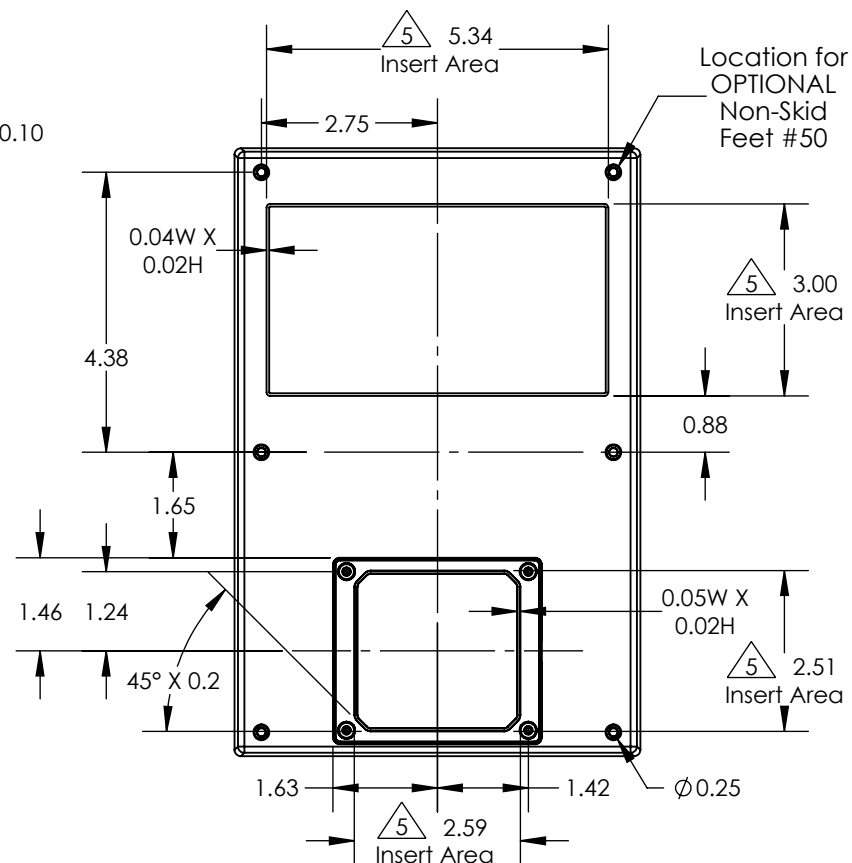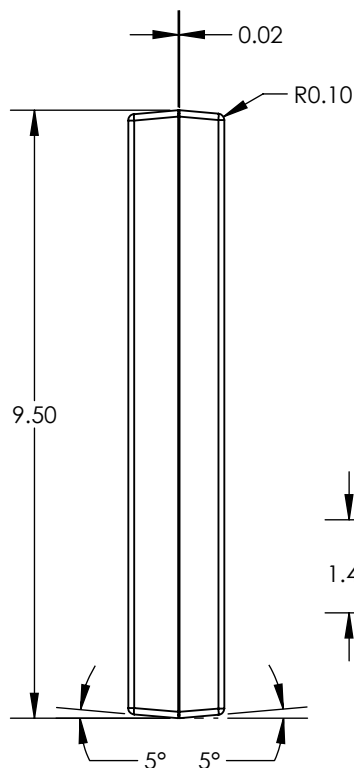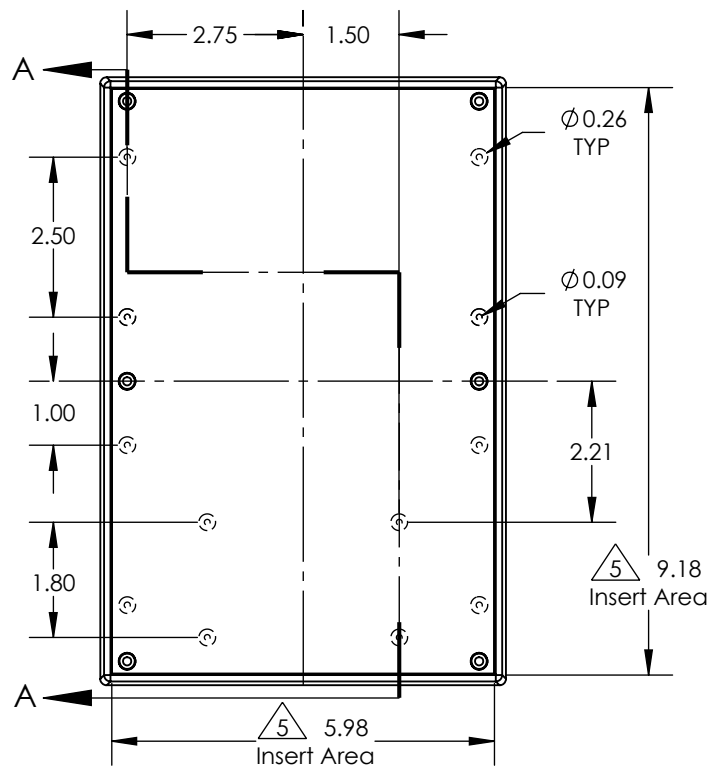



- Notes:
- 1) Enclosure meets or exceeds IP40 and NEMA 1
 - 2) Circuit Board drawings see sheet 3.
 - 3) All components are RoHS Compliant.
 - 4) Material: Top and Bottom ABS.
 - 5) Customizable molding areas. $\triangle 5$
 - 6) PCB Bosses accept #4 self tapping screw. $\triangle 6$
 - 7) When used with SK9 the enclosure meets or exceeds IP 67 and NEMA 4X, 12 and 13 MIL-STD-810G 506.5 (.04 lb / 19g)

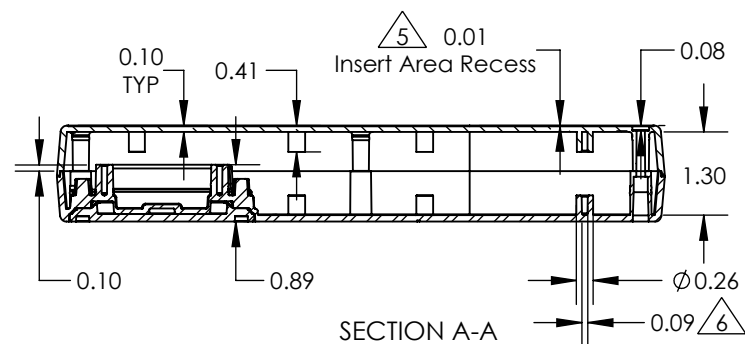



Top Option

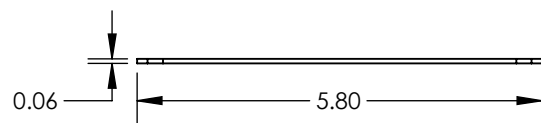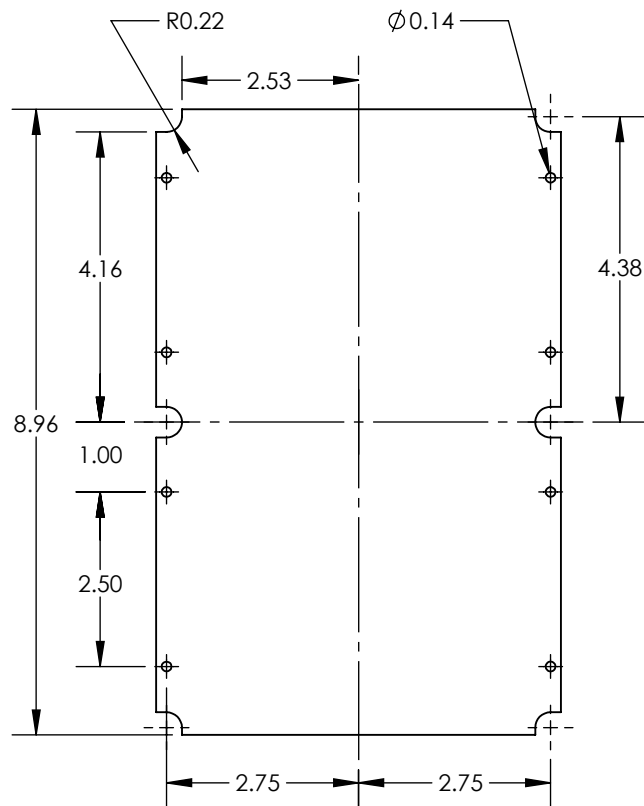

Bottom Option A

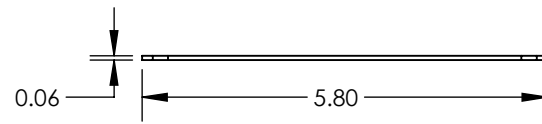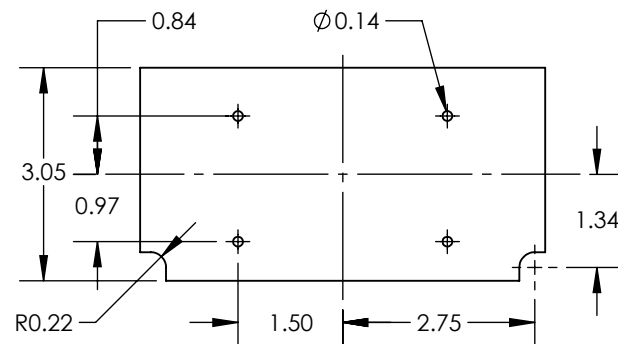

Bottom Option B

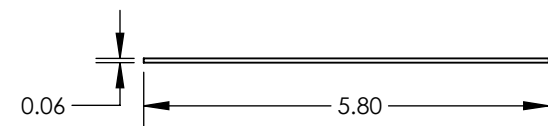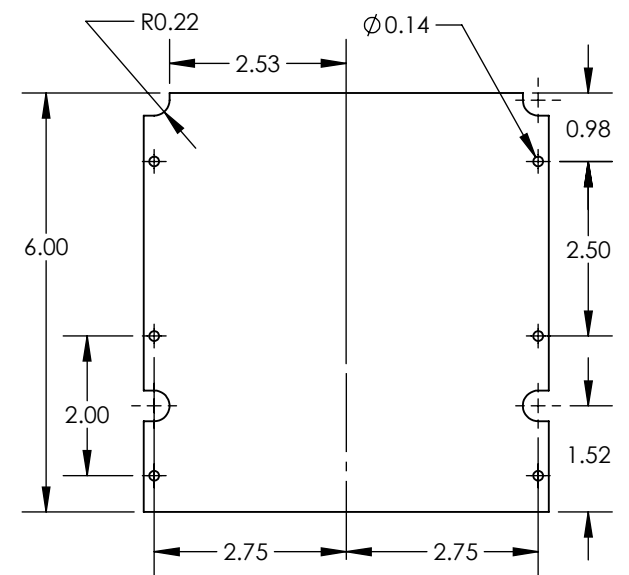

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SERPAC:](#)

[191Ri9VAL](#) [191Ri9VBK](#) [191Ri9VGY](#) [191Ri9V,GY](#) [191Ri9V,AL](#) [191Ri9V,BK](#)