


SERPAC 232RC






ELECTRONIC ENCLOSURES

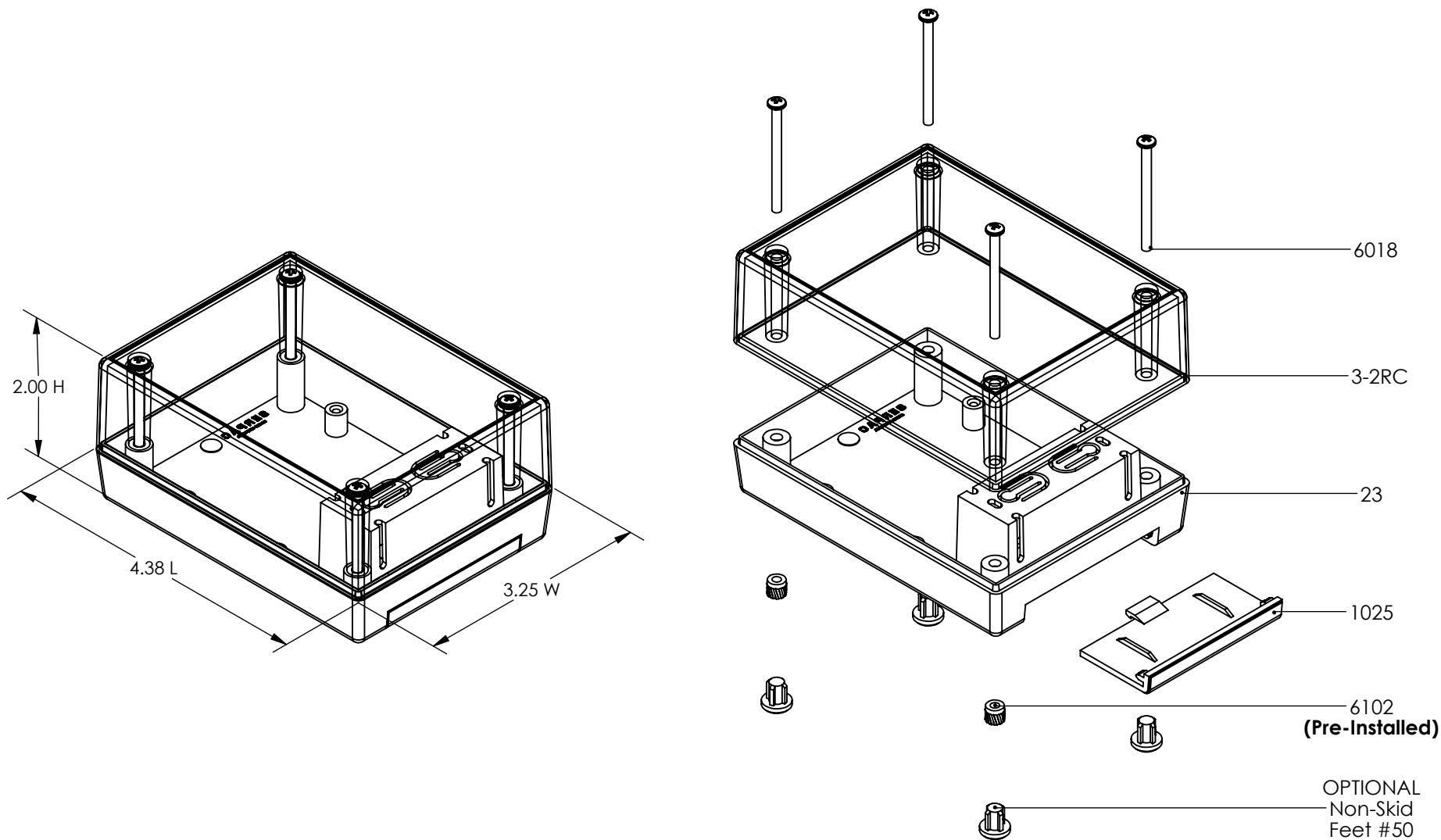

PART NO.	DESCRIPTION (Included)	ACCESSORIES (Optional)	
3-2RC	Top	PART NO.	DESCRIPTION
23	9V Bottom	1040	2AA Battery Holder
1025	Battery Cover	50	Non-skid Feet
6018	4-40 x 1 1/2" Screw (4)	60	Standoff Hole
6102	4-40 Threaded Inserts (4)	61	Standoff Post
		55	Key Holder
		1030	Pocket Clip

Notes: Enclosure weight .24 lb / 108 g
1) Enclosure meets or exceeds IP40 and NEMA 1
2) Circuit Board drawings see sheet 3.
3) All components are RoHS Compliant.
4) Material: Top PC and Bottom ABS.
5) Customizable molding areas. 5

SERPAC 232RC

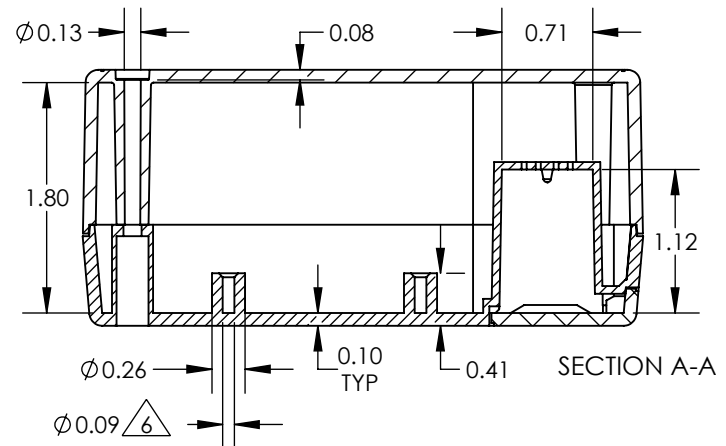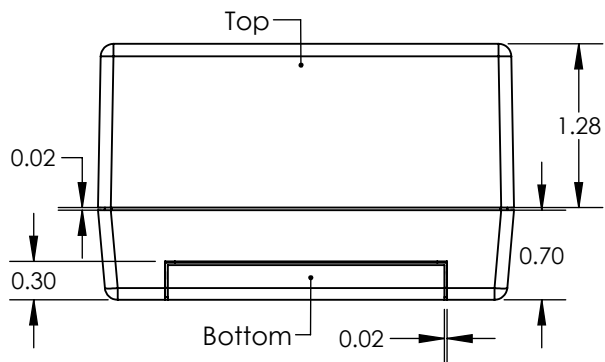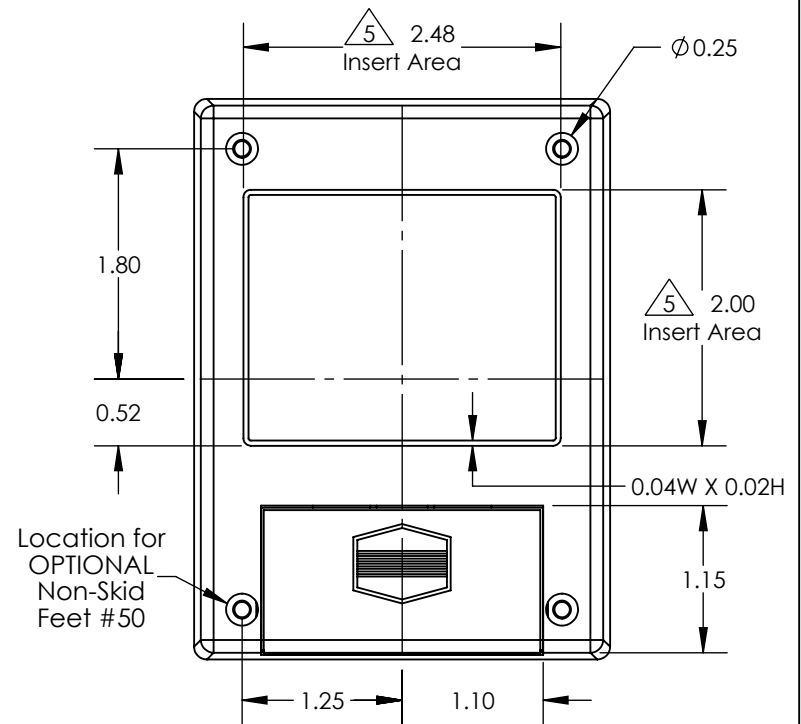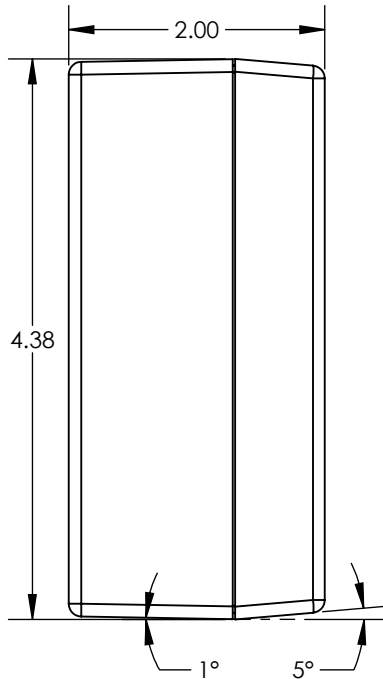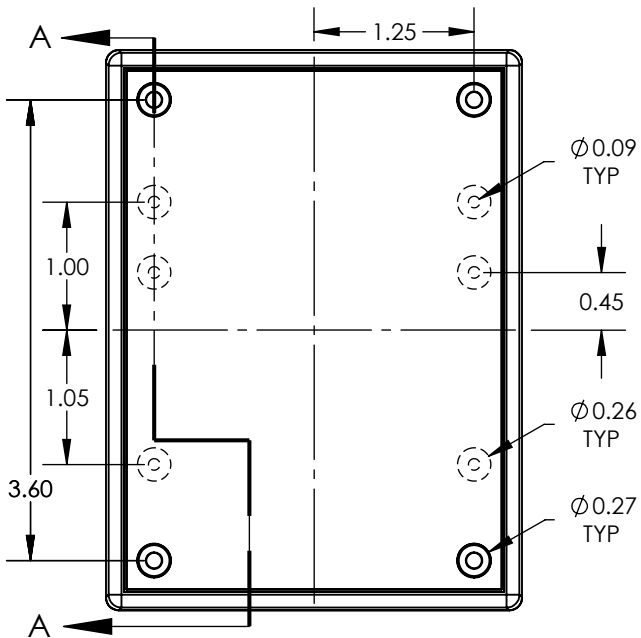



Notes: Enclosure weight .24 lb / 108 g

- 1) Enclosure meets or exceeds IP40 and NEMA 1
- 2) Circuit Board drawings see sheet 3.
- 3) All components are RoHS Compliant.
- 4) Material: Top PC and Bottom ABS.
- 5) Customizable molding areas.
- 6) PCB Bosses accept #4 self tapping screw.



SERPAC 232RC CIRCUIT BOARD

ELECTRONIC ENCLOSURES

Top Option

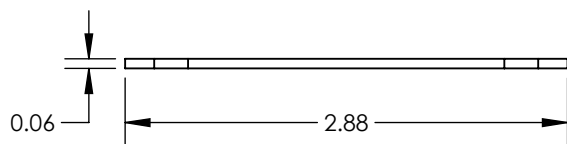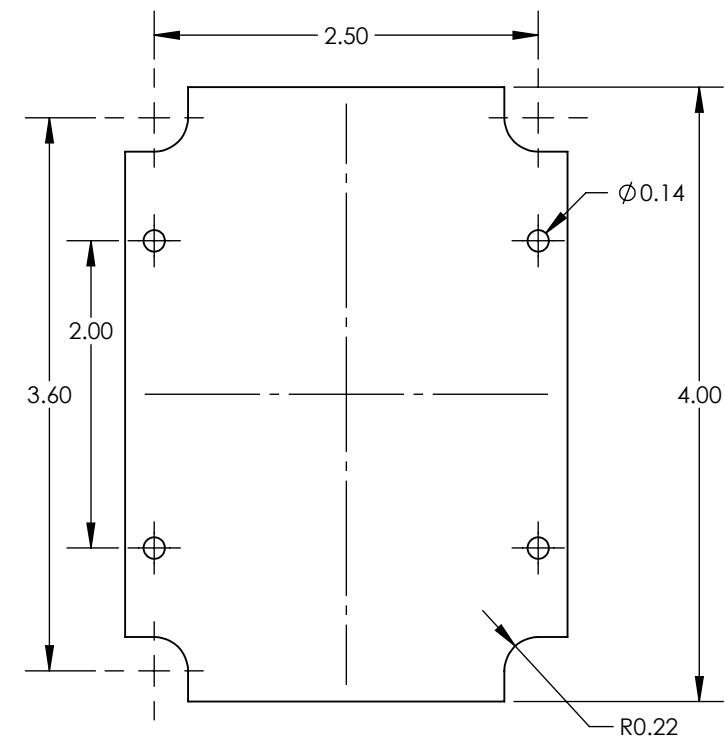

Bottom Option

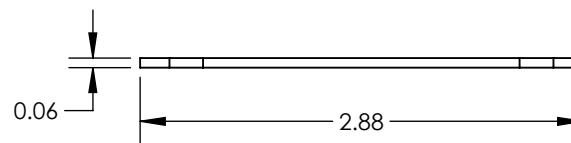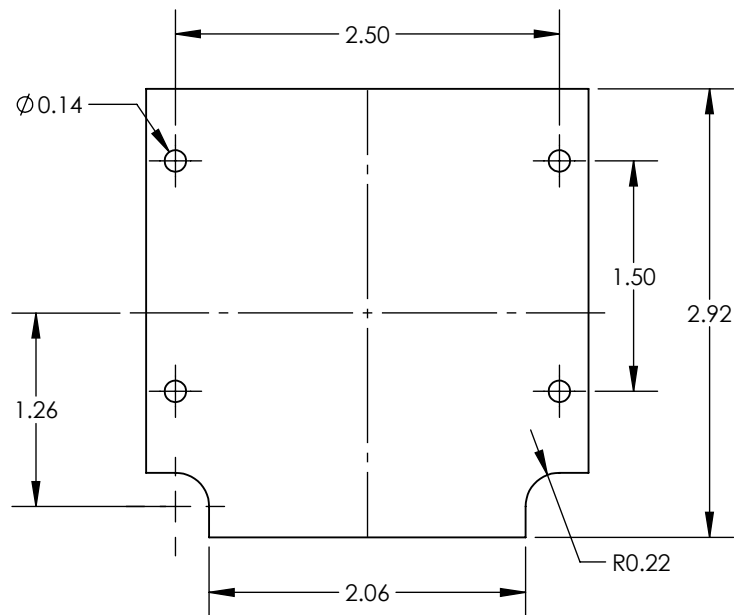

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SERPAC:](#)

[232RCAL](#) [232RCBK](#) [232RCGY](#) [232RC,AL](#) [232RC,BK](#) [232RC,GY](#)