

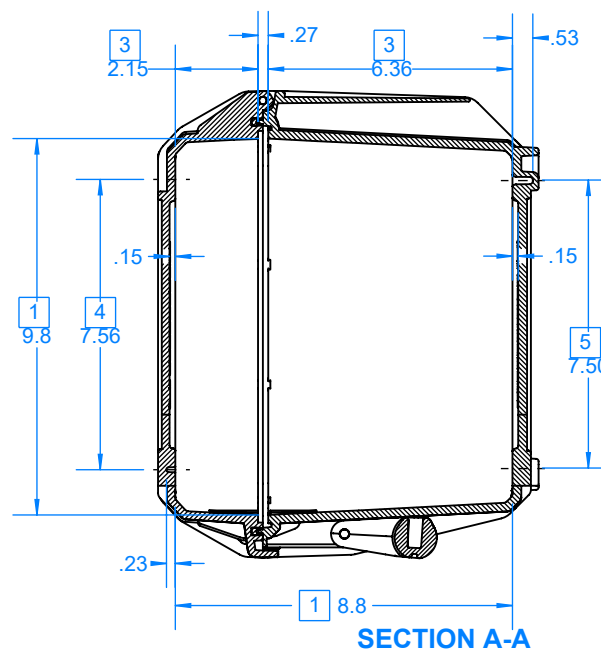
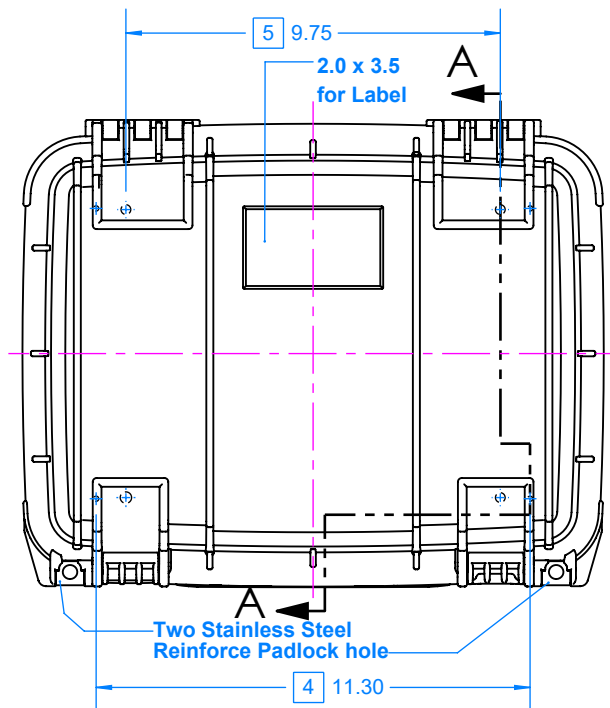
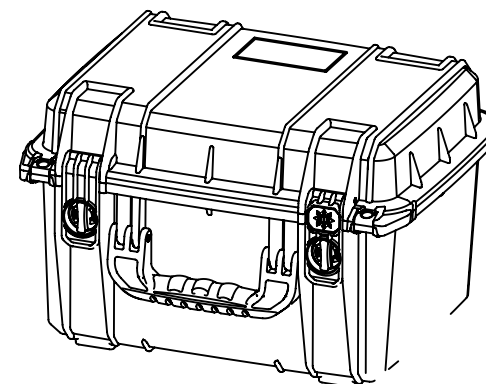
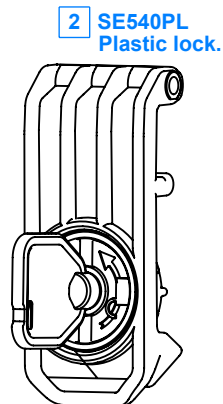
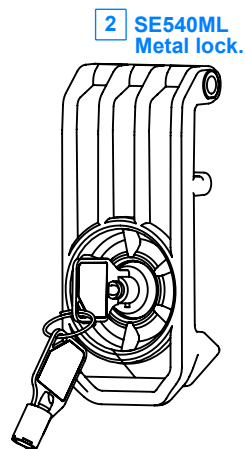


SE540

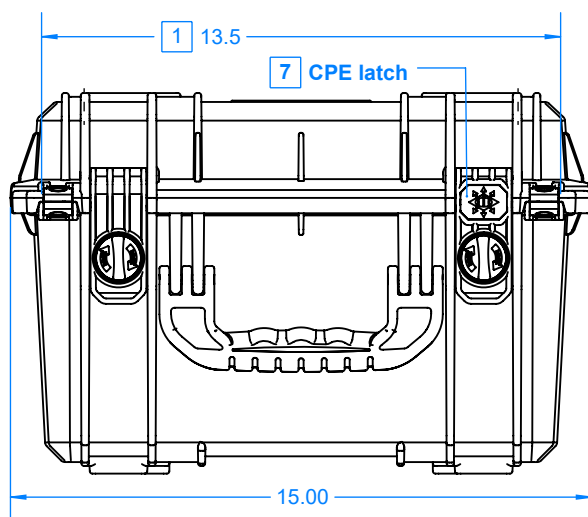

SEAHORSE

PROTECTIVE EQUIPMENT CASES

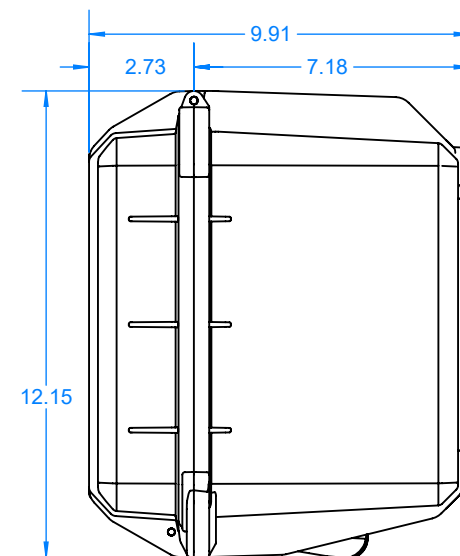


NOTES:

- 1) Max. usable inside dimensions are: 13.5" X 9.8" X 8.8"
- 2) Optional:
Metal Lock Latches p/n SE540ML
and Plastic Lock Latches p/n SE540PL
- 3) Dimensions to Top & Bottom of panel flange.
- 4) Bosses on Top use a #10 self tapping screw.
- 5) Bosses on bottom use a 1/4" self tapping screw.
- 6) Weight empty/w-foam: 6.45/7.25 lb.
Buoyancy: 34 lb.
Weight Capacity: 60 lb.
- 7) CPE = Continues Pressure Equalization latch.


Top panel for SE540

SEAHORSE
PROTECTIVE EQUIPMENT CASES

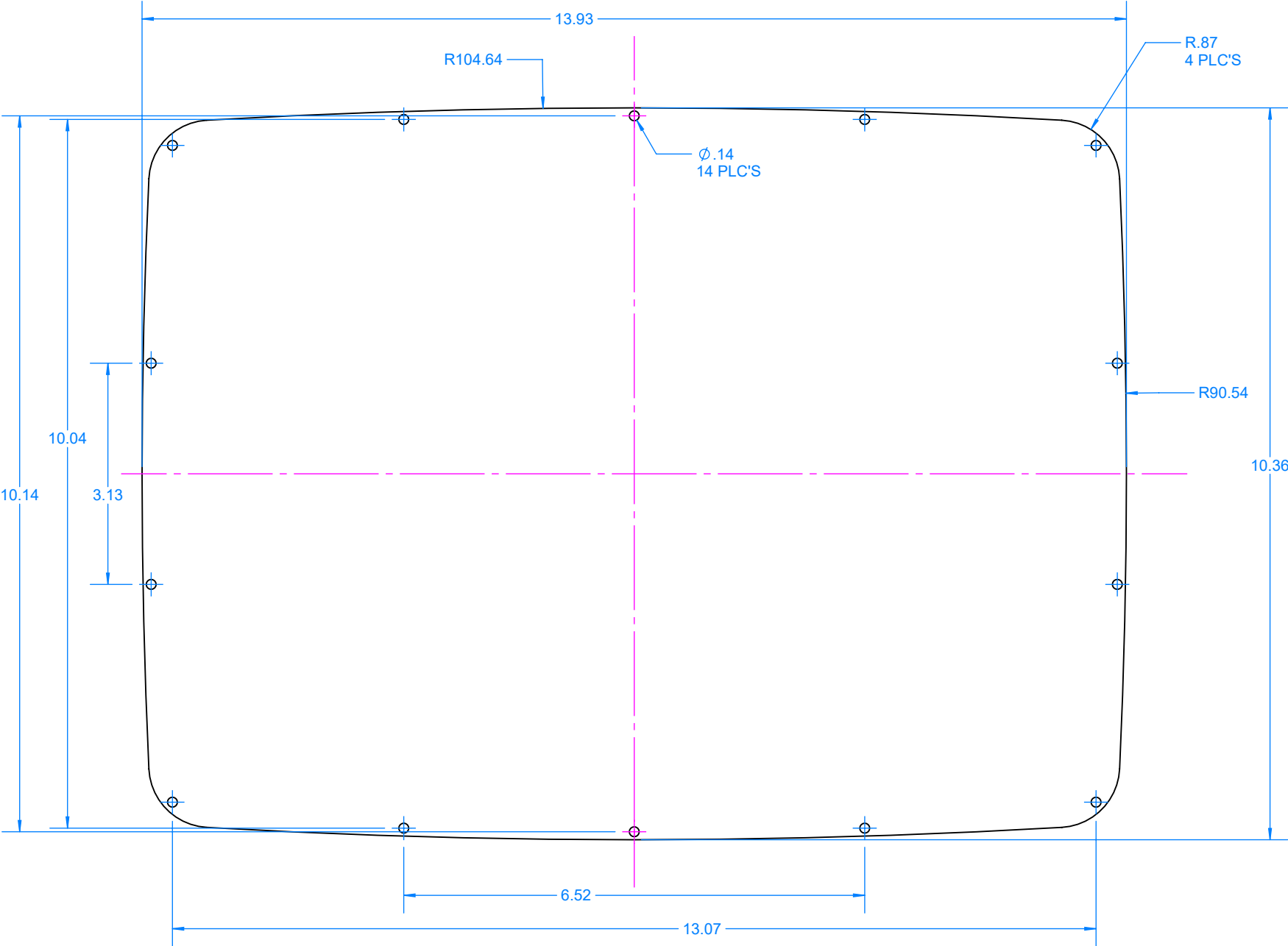


Bottom panel for SE540

SEAHORSE
PROTECTIVE EQUIPMENT CASES

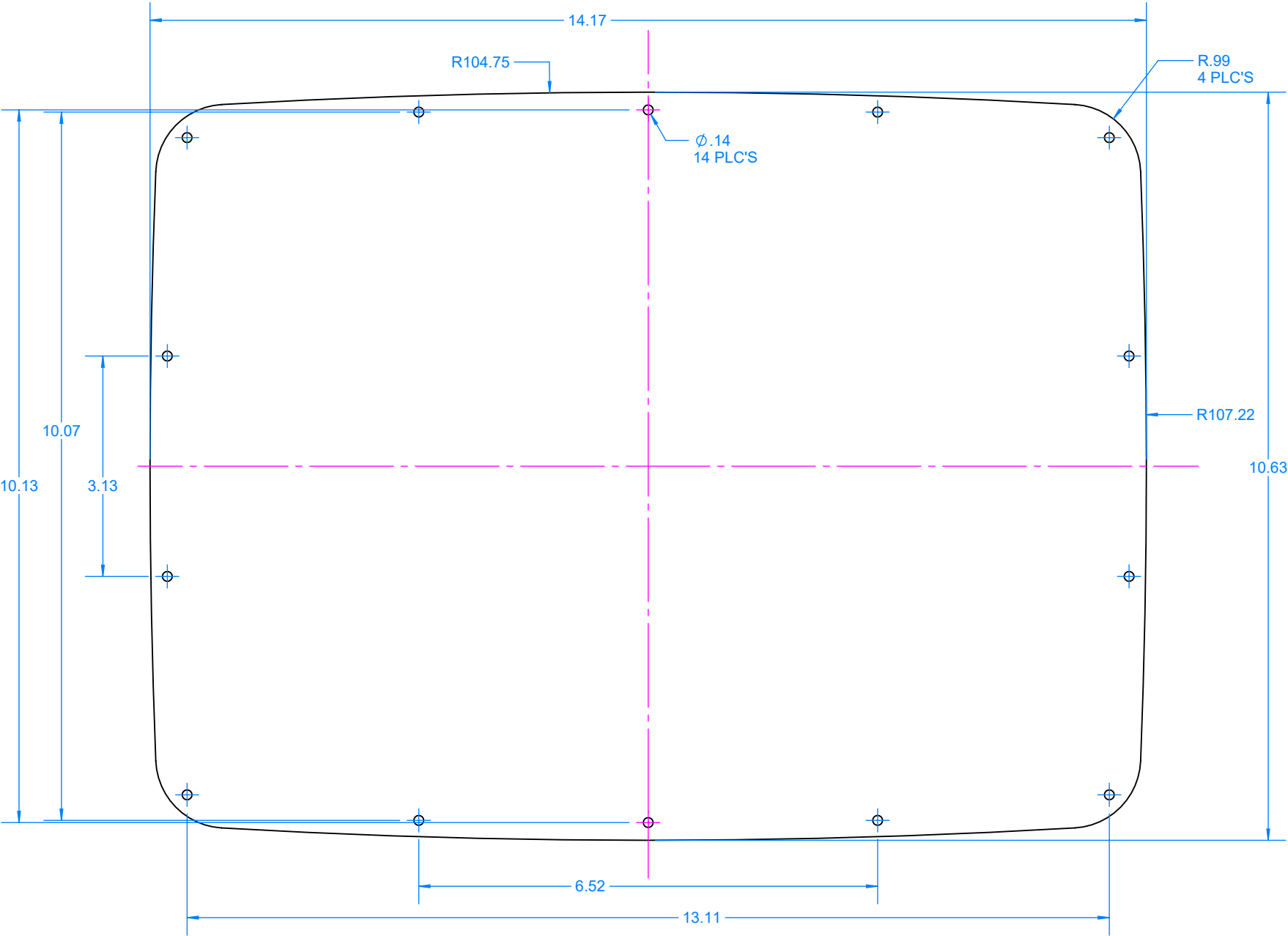


Top Mounting Plate for SE540

SEAHORSE
PROTECTIVE EQUIPMENT CASES

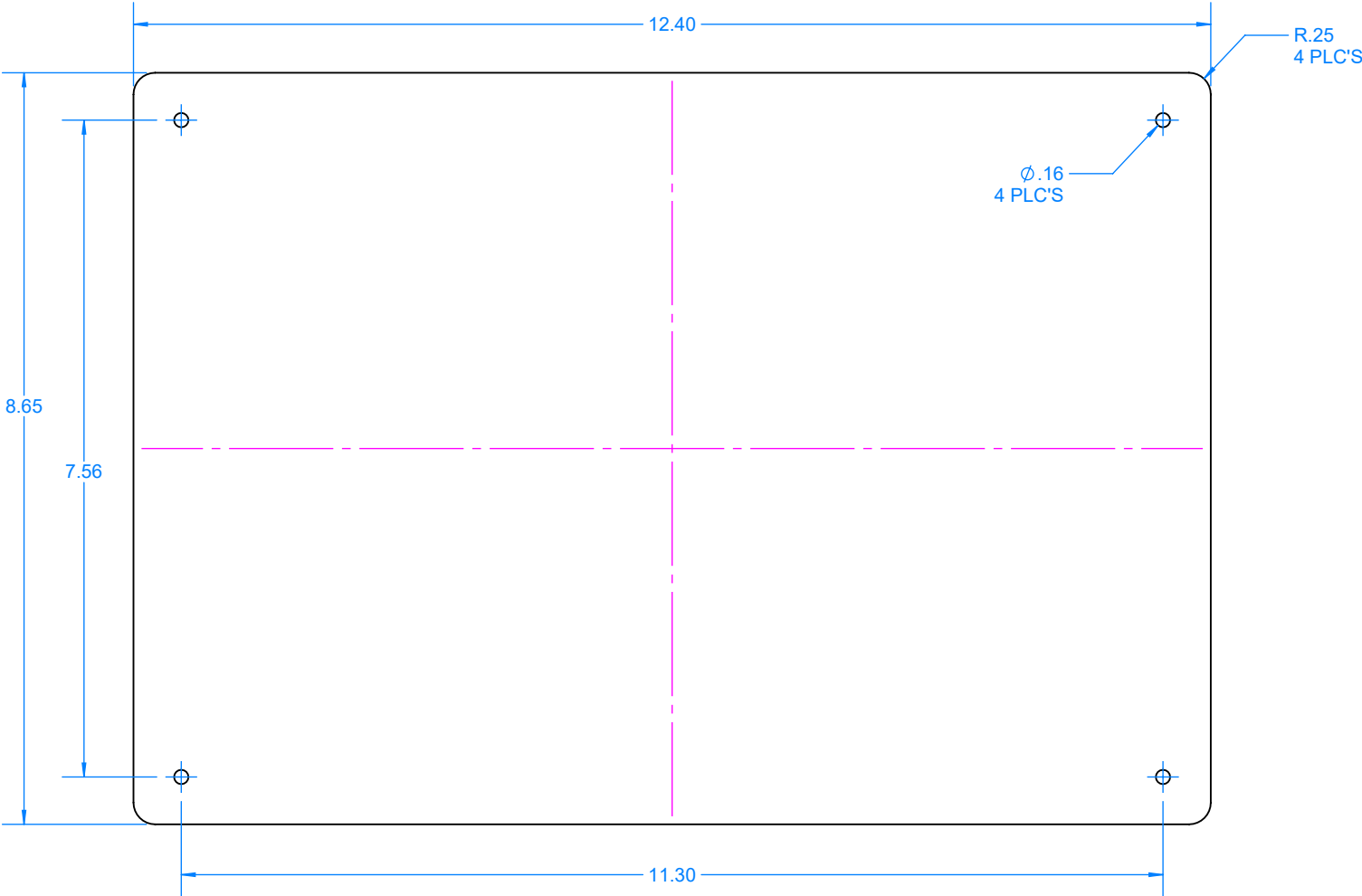

Top Mounting Plate for SE540

SEAHORSE
PROTECTIVE EQUIPMENT CASES

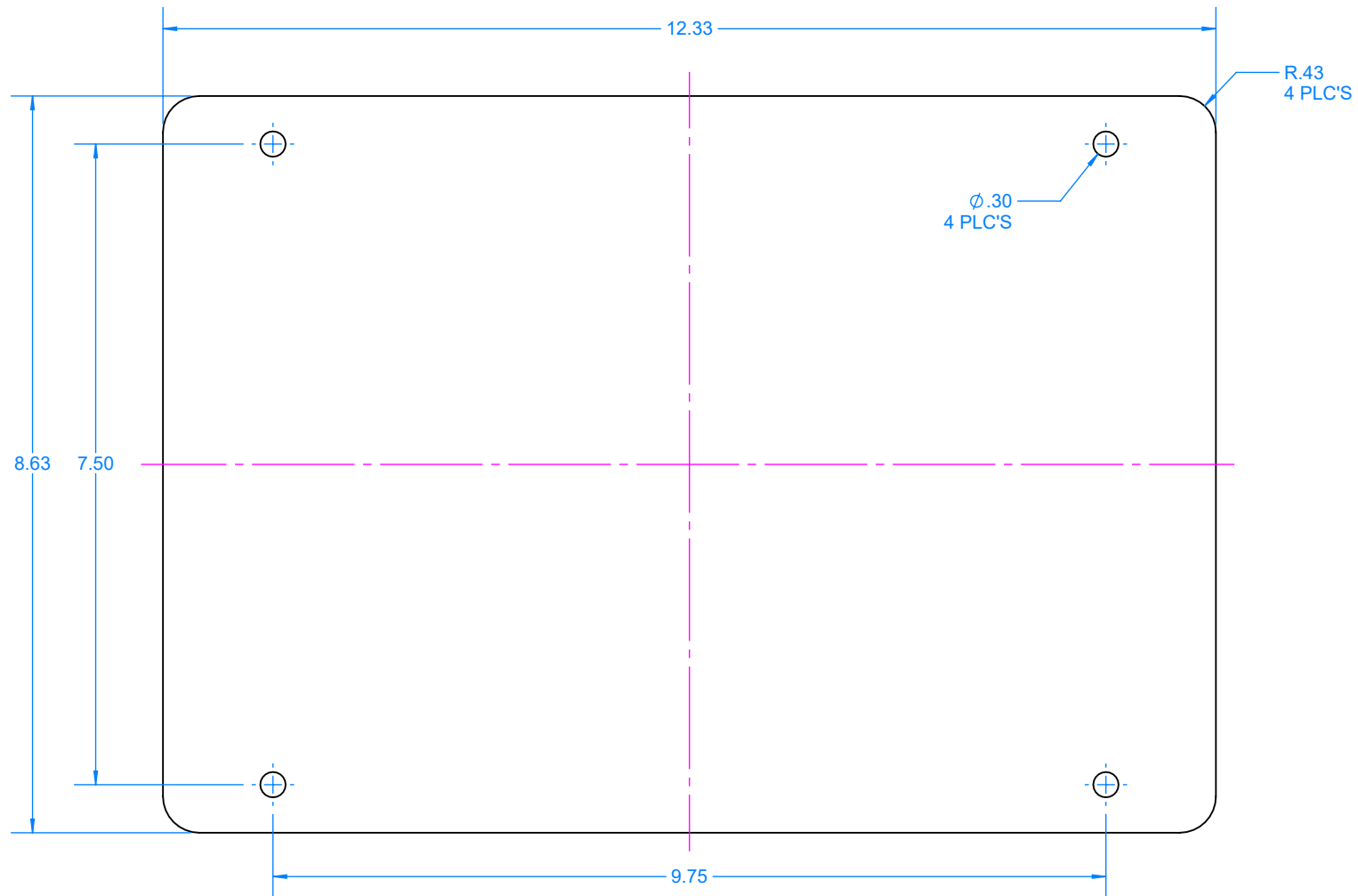

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SERPAC:](#)

[SE540,BK](#) [SE540,GM](#) [SE540,OR](#) [SE540,YL](#) [SE540F,BK](#) [SE540F,GM](#) [SE540F,OR](#) [SE540F,YL](#) [SE540D, BK](#)
[SE540D, GM](#) [SE540D, YL](#) [SE540DML, BK](#) [SE540DML, GM](#) [SE540DML, YL](#) [SE540DPL, BK](#) [SE540DPL, GM](#)
[SE540DPL, YL](#) [SE540FML, BK](#) [SE540FML, GM](#) [SE540FML, YL](#) [SE540FPL, BK](#) [SE540FPL, GM](#) [SE540FPL, YL](#)
[SE540ML, BK](#) [SE540ML, GM](#) [SE540ML, YL](#) [SE540PL, BK](#) [SE540PL, GM](#) [SE540PL, YL](#) [SE540D,BK](#) [SE540D,GM](#)
[SE540D,YL](#) [SE540DML,BK](#) [SE540DML,GM](#) [SE540DML,YL](#) [SE540DPL,BK](#) [SE540DPL,GM](#) [SE540DPL,YL](#)
[SE540FML,BK](#) [SE540FML,GM](#) [SE540FML,YL](#) [SE540FPL,BK](#) [SE540FPL,GM](#) [SE540FPL,YL](#) [SE540ML,BK](#)
[SE540ML,GM](#) [SE540ML,YL](#) [SE540PL,BK](#) [SE540PL,GM](#) [SE540PL,YL](#)