
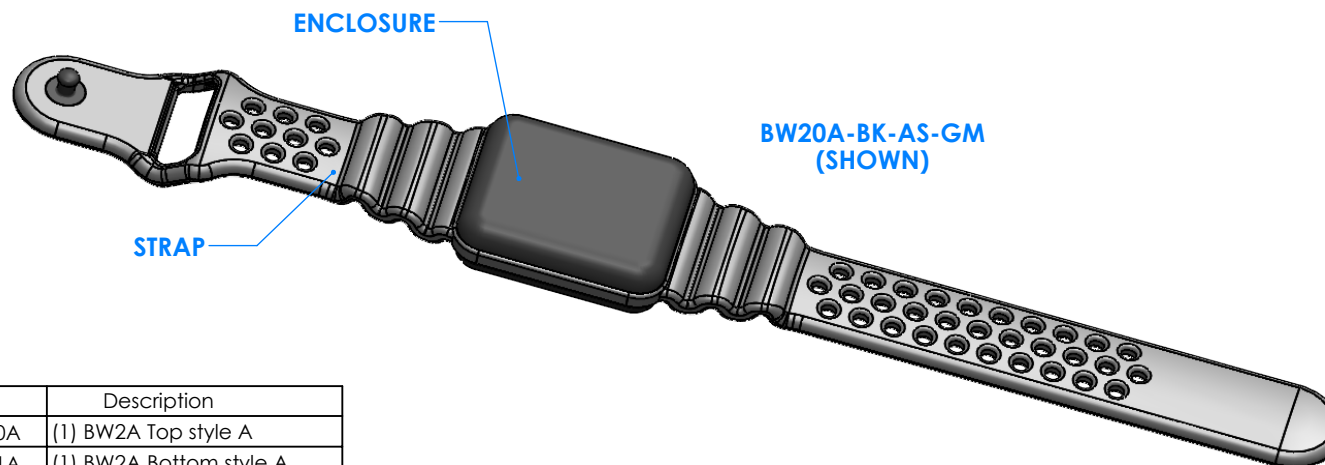
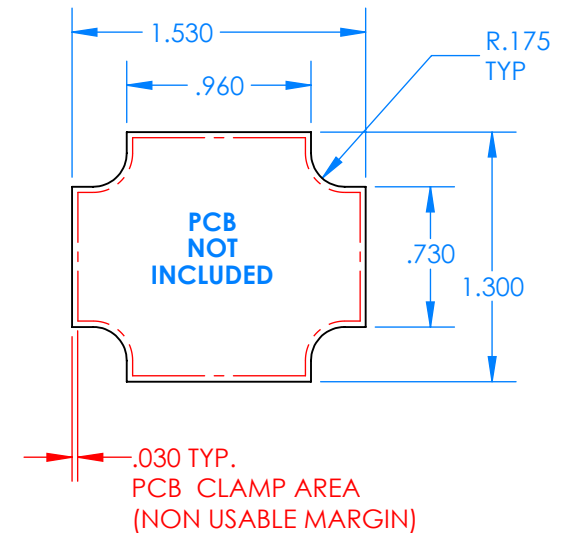
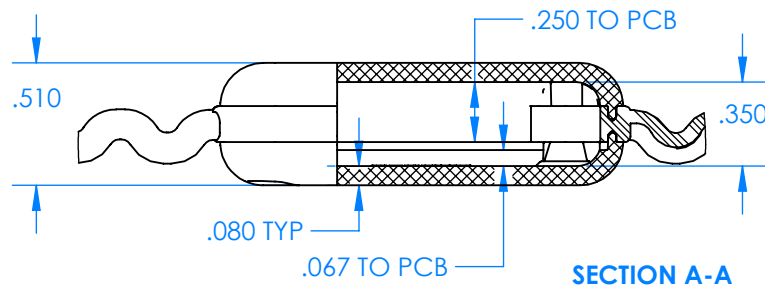


SERPAC BW20A-YY-AS-ZZ

 
Electronic Enclosures

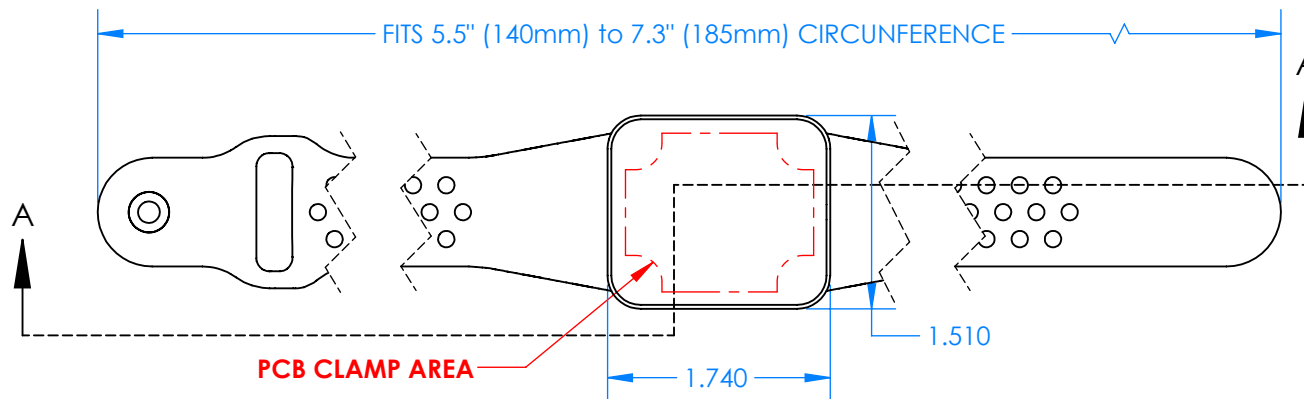

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red



Strap color (ZZ)

BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white

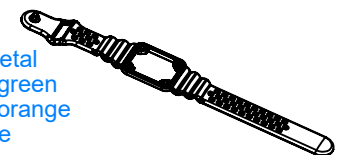

PN	Description
5510A	(1) BW2A Top style A
5511A	(1) BW2A Bottom style A
5517A	(1) BW2AS Small Strap style A
6002	(4) #2 X 3/8" PH HD screw. TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[BW20ABKASBK](#) [BW20ABKASBL](#) [BW20ABKASGM](#) [BW20ABKASNG](#) [BW20ABKASNO](#) [BW20ABKASOR](#)
[BW20ABKASYL](#) [BW20A-CLBK-AS-BK](#) [BW20A-CLBK-AS-BL](#) [BW20A-CLBK-AS-GM](#) [BW20A-CLBK-AS-NG](#) [BW20A-CLBK-AS-NO](#) [BW20A-CLBK-AS-OR](#) [BW20A-CLBK-AS-WH](#) [BW20A-CLBK-AS-YL](#)