
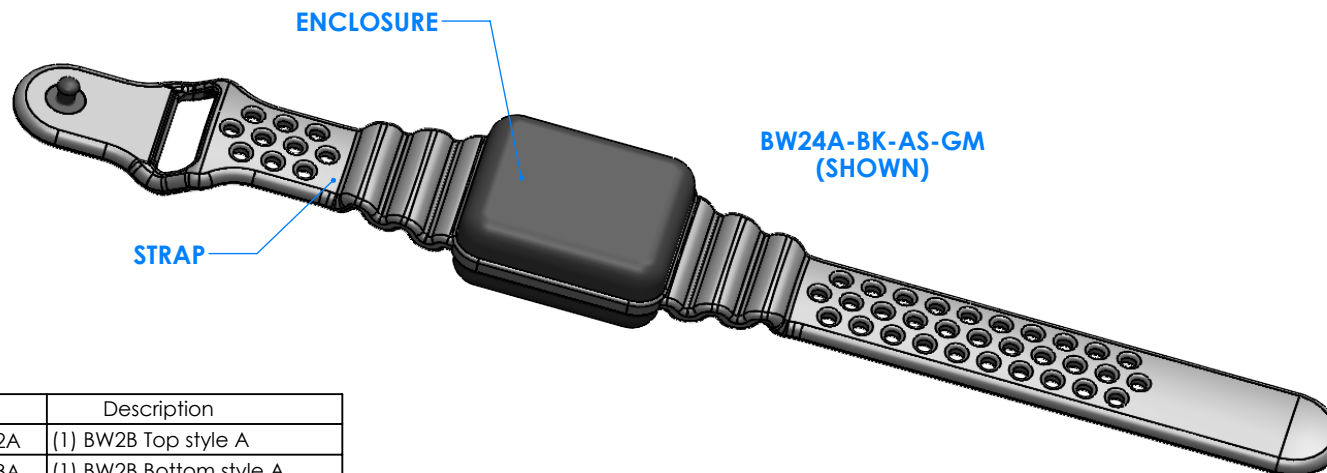
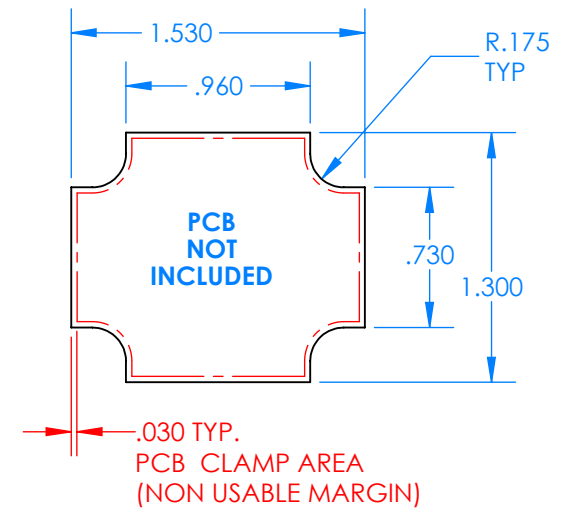
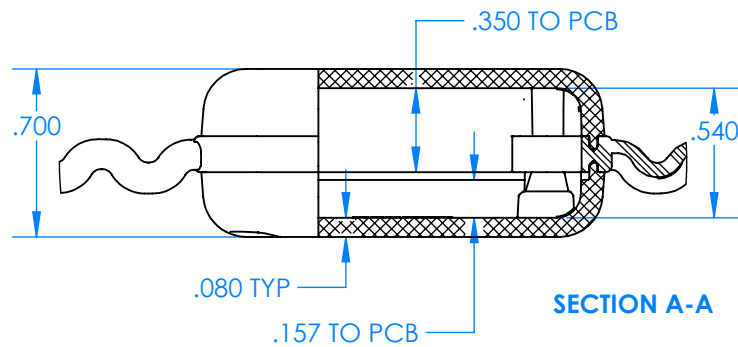


SERPAC BW24A-YY-AS-ZZ

 
Electronic Enclosures

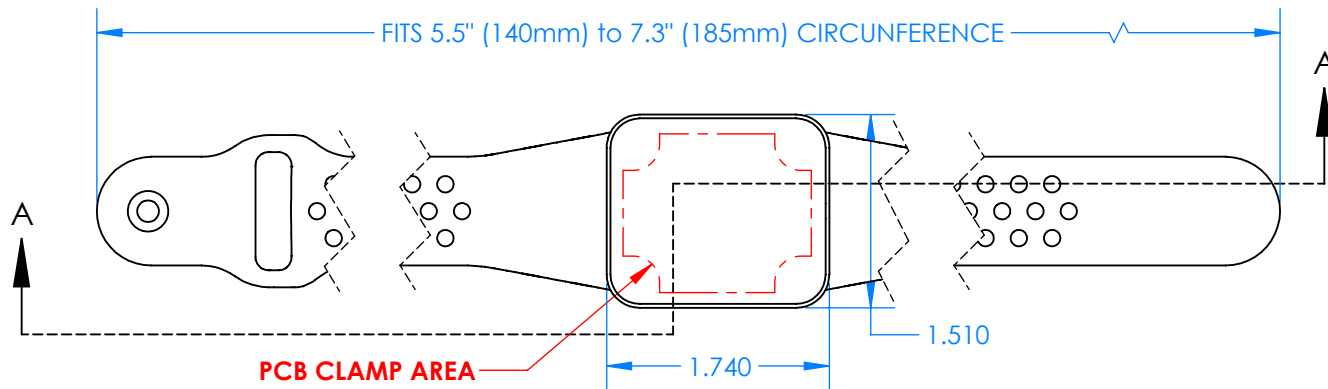

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red



Strap color (ZZ)

BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white

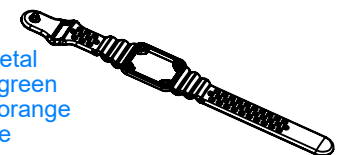

PN	Description
5512A	(1) BW2B Top style A
5513A	(1) BW2B Bottom style A
5517A	(1) BW2AS Small Strap style A
6002	(4) #2 X 3/8" PH HD screw. TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[BW24ABKASBK](#) [BW24ABKASBL](#) [BW24ABKASGM](#) [BW24ABKASNG](#) [BW24ABKASNO](#) [BW24ABKASOR](#)
[BW24ABKASYL](#) [BW24A-CLBK-AS-BK](#) [BW24A-CLBK-AS-BL](#) [BW24A-CLBK-AS-GM](#) [BW24A-CLBK-AS-NG](#) [BW24A-CLBK-AS-NO](#) [BW24A-CLBK-AS-OR](#) [BW24A-CLBK-AS-WH](#) [BW24A-CLBK-AS-YL](#)