
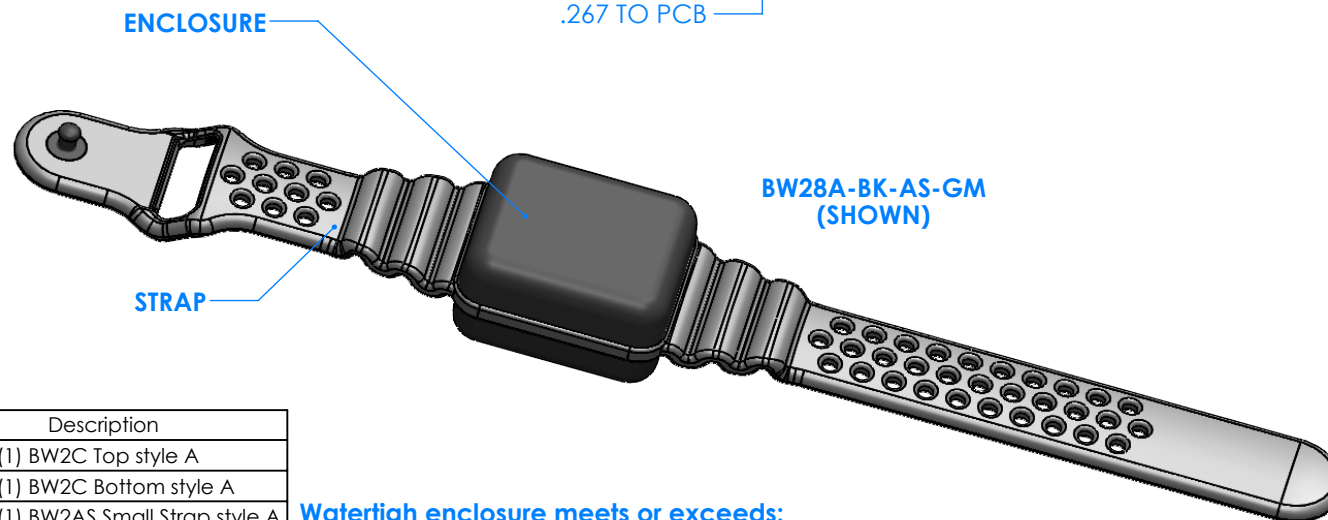
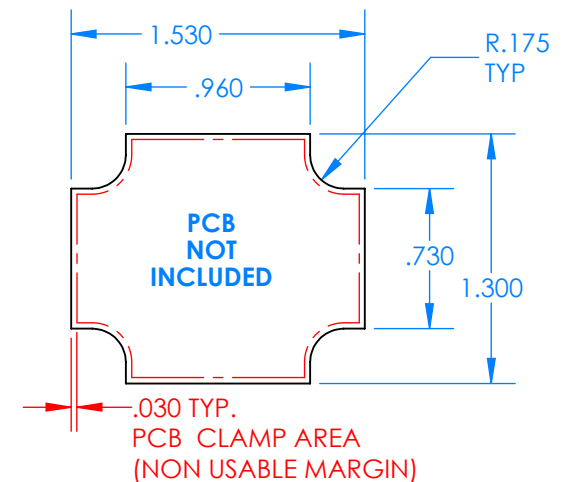
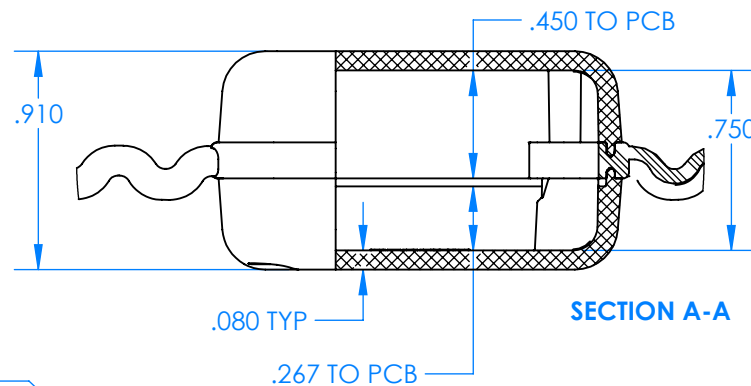


SERPAC BW28A-YY-AS-ZZ

 
Electronic Enclosures

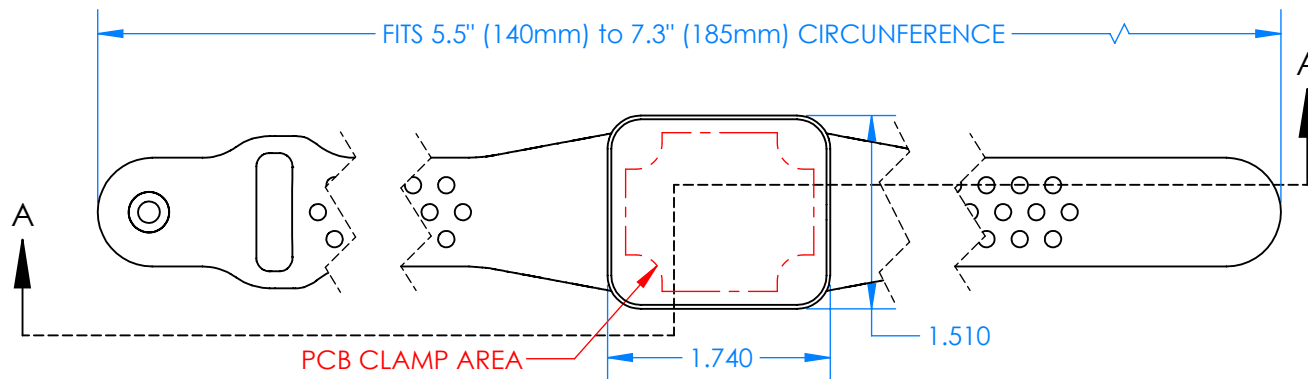

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red



Strap color (ZZ)

BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white

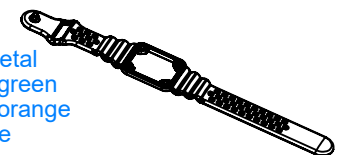

PN	Description
55140A	(1) BW2C Top style A
5515A	(1) BW2C Bottom style A
5517A	(1) BW2AS Small Strap style A
6002	(4) #2 X 3/8" PH HD screw. TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[BW28ABKASBK](#) [BW28ABKASBL](#) [BW28ABKASGM](#) [BW28ABKASNG](#) [BW28ABKASNO](#) [BW28ABKASOR](#)
[BW28ABKASYL](#) [BW28A-CLBK-AS-OR](#) [BW28A-CLBK-AS-WH](#) [BW28A-CLBK-AS-YL](#) [BW28A-CLBK-AS-BK](#) [BW28A-CLBK-AS-BL](#) [BW28A-CLBK-AS-GM](#) [BW28A-CLBK-AS-NG](#) [BW28A-CLBK-AS-NO](#)