
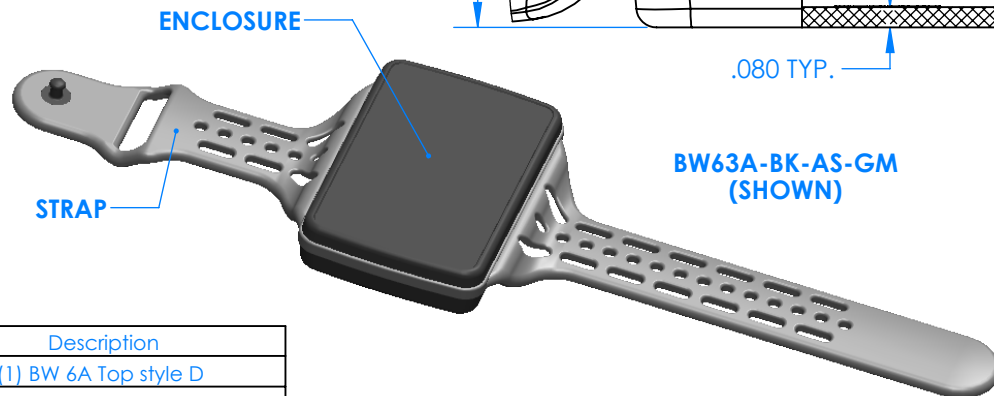
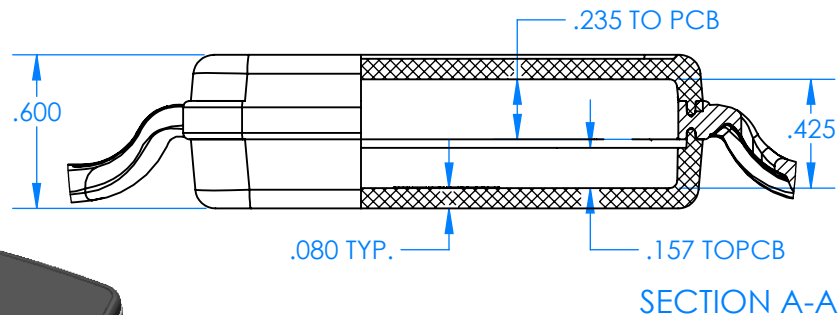


SERPAC BW63D-YY-CS-ZZ


Electronic Enclosures

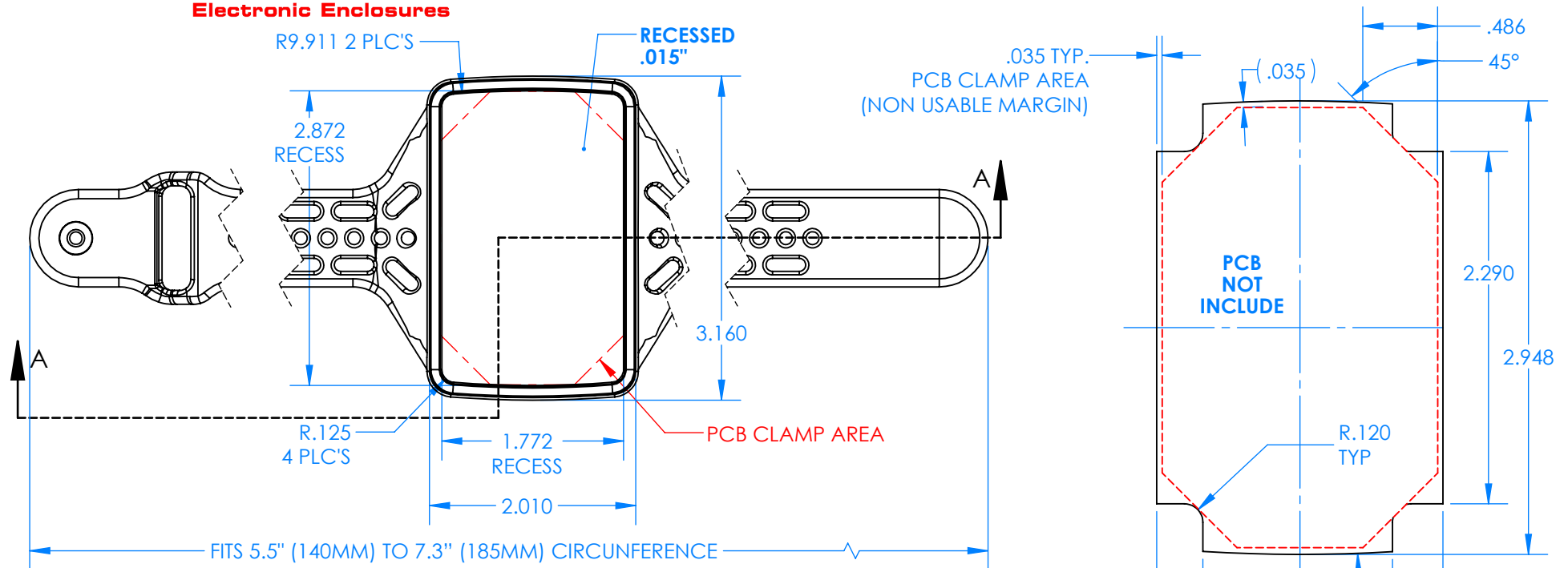

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

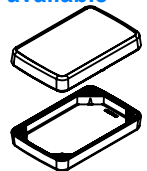

Strap color (ZZ)

BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white

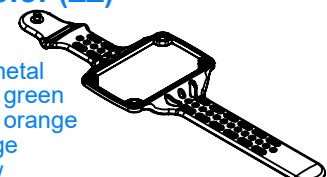

PN	Description
5531D	(1) BW 6A Top style D
5534D	(1) BW 6B Bottom style D
5538C	(1) BW 6C Small Strap style D
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz.

Watertight enclosure meets or exceeds:
IP67
NEMA 4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[BW63DBKCSBK](#) [BW63DBKCSBL](#) [BW63DBKCSGM](#) [BW63DBKCSNG](#) [BW63DBKCSNO](#) [BW63DBKCSOR](#)
[BW63DBKCSYL](#) [BW63DBKCSWH](#) [BW63D-CLBK-CS-BK](#) [BW63D-CLBK-CS-BL](#) [BW63D-CLBK-CS-GM](#) [BW63D-CLBK-CS-NG](#) [BW63D-CLBK-CS-NO](#) [BW63D-CLBK-CS-OR](#) [BW63D-CLBK-CS-WH](#) [BW63D-CLBK-CS-YL](#)