
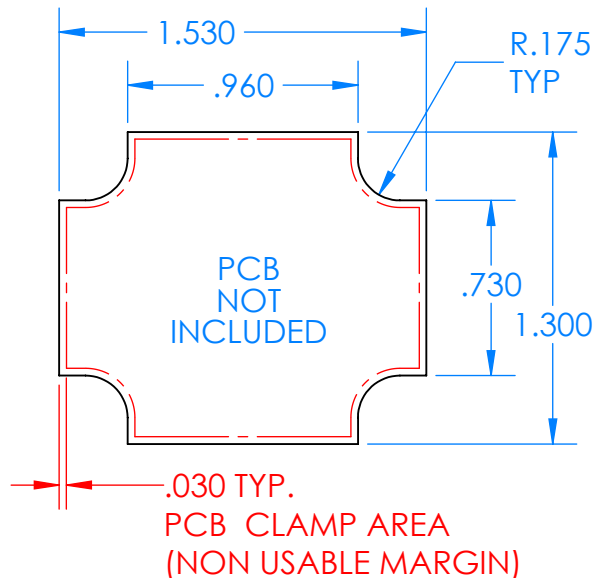
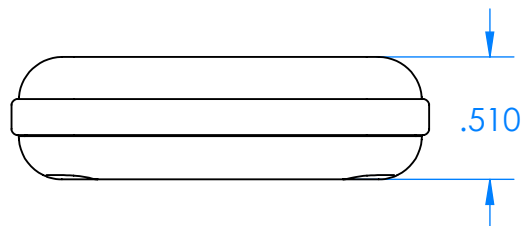
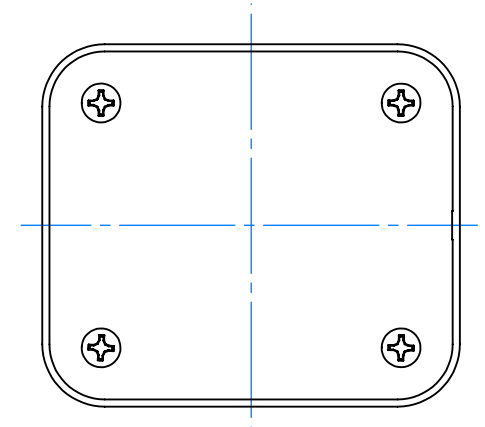
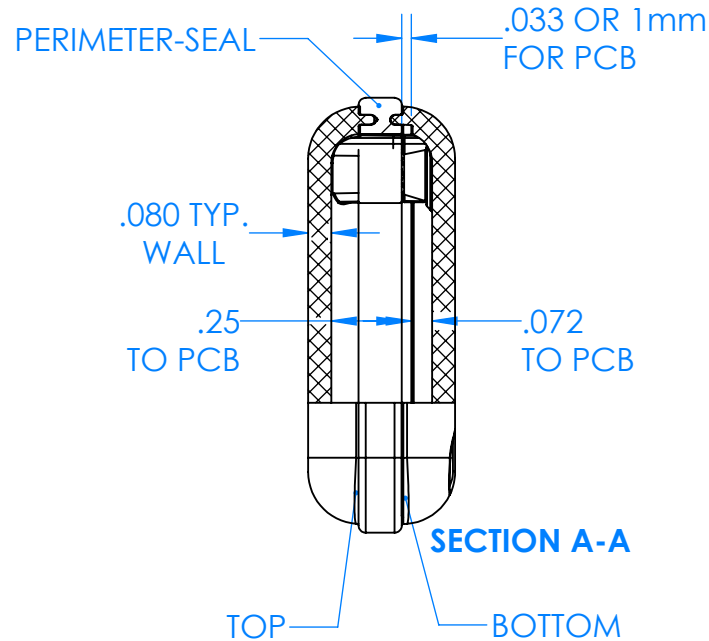


SERPAC CX20A-YY-A-ZZ


Electronic Enclosures

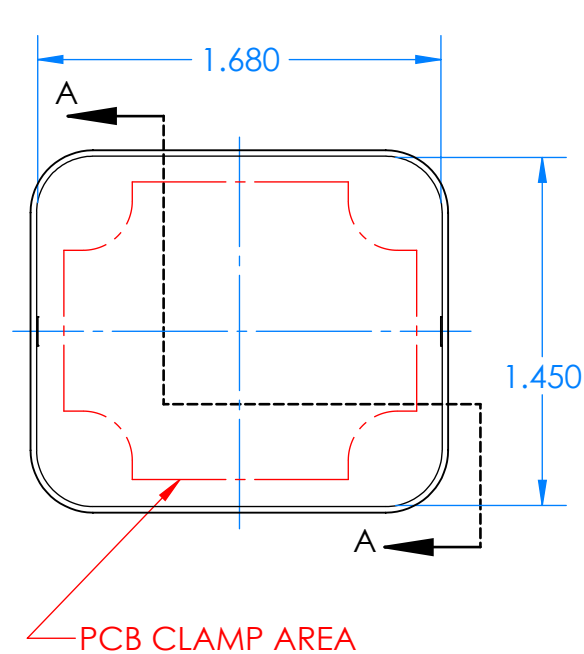

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

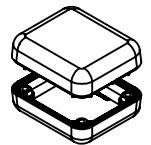

Seal color (ZZ)

 BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white



PN	Description
5510A,YY	(1) BW 2A Top,YY
5511A,YY	(1) BW 2A Bottom,YY
5521A,ZZ	(1) CX2 Perimeter Seal, ZZ
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[CX20ABKASBK](#) [CX20ABKASBL](#) [CX20ABKASGM](#) [CX20ABKASNG](#) [CX20ABKASNO](#) [CX20ABKASOR](#)
[CX20ABKASYL](#) [CX20ABKANO](#) [CX20ABKAOR](#) [CX20ABKAYL](#) [CX20ABKABK](#) [CX20ABKABL](#) [CX20ABKAGM](#)
[CX20ABKANG](#) [CX20A-CLBK-A-BK](#) [CX20A-CLBK-A-BL](#) [CX20A-CLBK-A-GM](#) [CX20A-CLBK-A-NG](#) [CX20A-CLBK-A-](#)
[NO](#) [CX20A-CLBK-A-OR](#) [CX20A-CLBK-A-WH](#) [CX20A-CLBK-A-YL](#)