
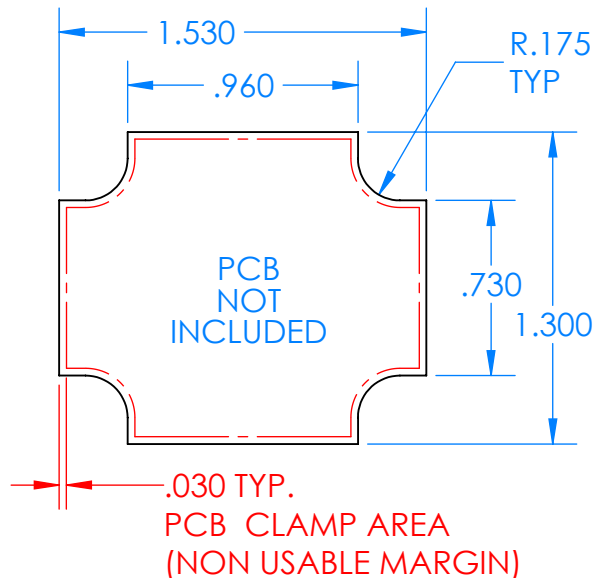


SERPAC CX24A-YY-A-ZZ


Electronic Enclosures

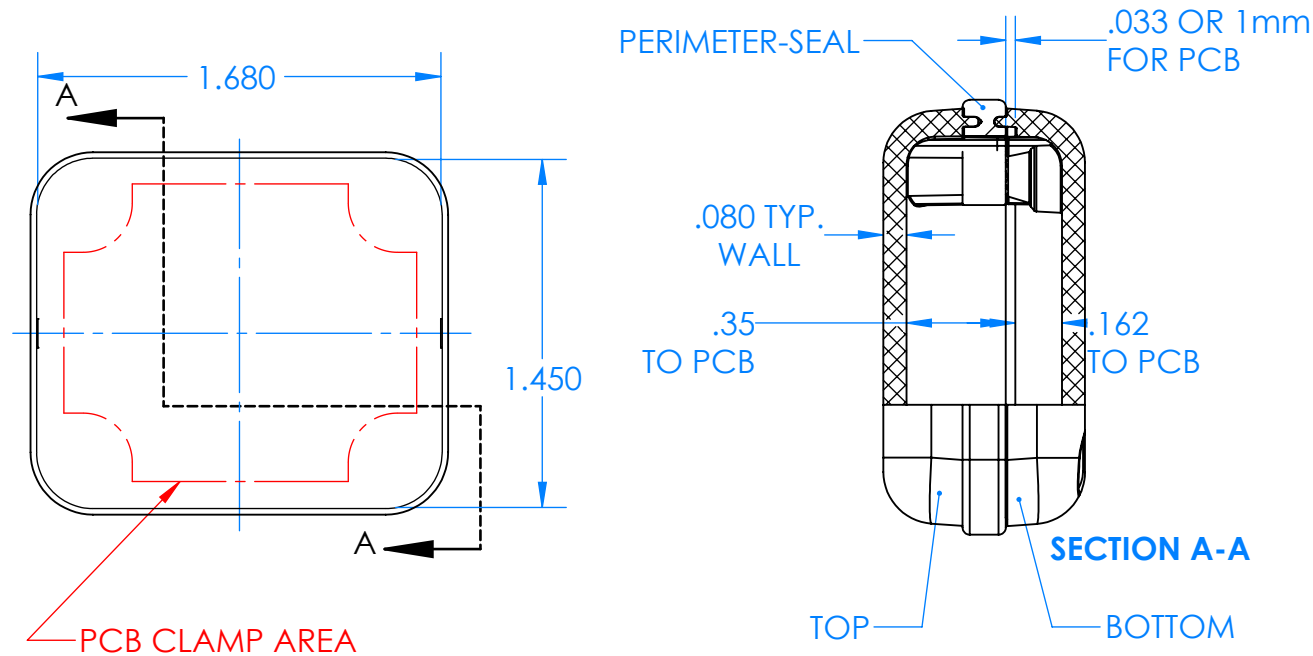

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

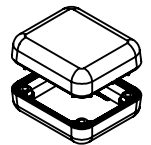

Seal color (ZZ)

 BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white



PN	Description
5512A,YY	(1) BW 2B Top,YY
5513A,YY	(1) BW 2B Bottom,YY
5521A,ZZ	(1) CX2 Perimeter Seal, ZZ
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[CX24ABKASBK](#) [CX24ABKASBL](#) [CX24ABKASGM](#) [CX24ABKASNG](#) [CX24ABKASNO](#) [CX24ABKASOR](#)
[CX24ABKASYL](#) [CX24ABKABK](#) [CX24ABKABL](#) [CX24ABKAGM](#) [CX24ABKANG](#) [CX24ABKANO](#) [CX24ABKAOR](#)
[CX24ABKAYL](#) [CX24A-CLBK-A-BK](#) [CX24A-CLBK-A-BL](#) [CX24A-CLBK-A-GM](#) [CX24A-CLBK-A-NG](#) [CX24A-CLBK-A-](#)
[NO](#) [CX24A-CLBK-A-OR](#) [CX24A-CLBK-A-WH](#) [CX24A-CLBK-A-YL](#)