
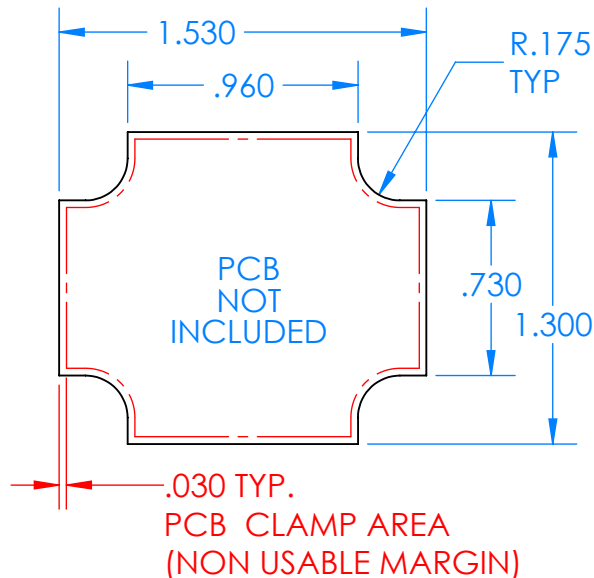
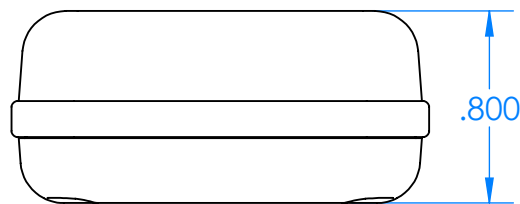
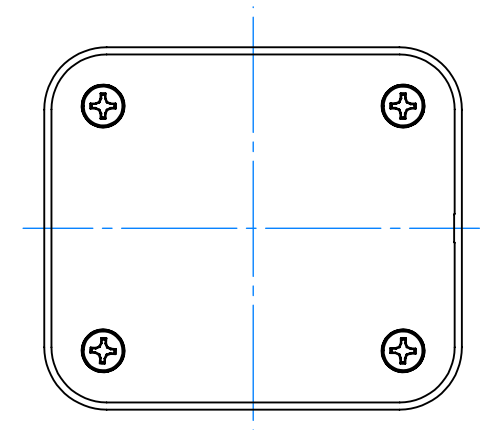
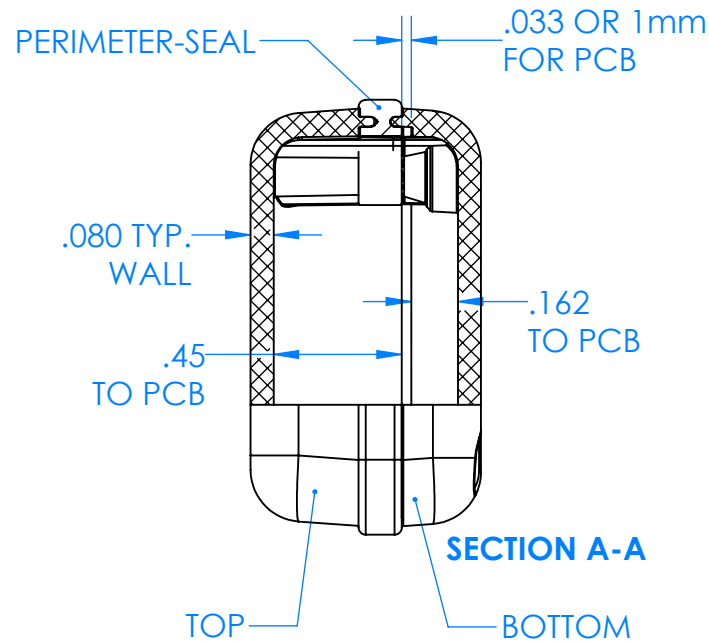


SERPAC CX25A-YY-A-ZZ


Electronic Enclosures

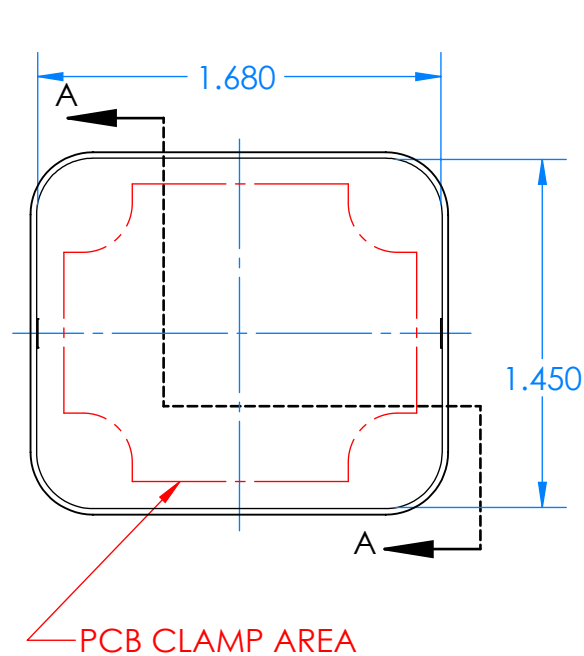

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

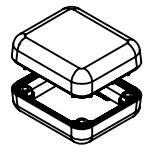

Seal color (ZZ)

 BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white



PN	Description
5514A,YY	(1) BW 2C Top,YY
5513A,YY	(1) BW 2B Bottom,YY
5521A,ZZ	(1) CX2 Perimeter Seal, ZZ
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[CX25ABKASBK](#) [CX25ABKASBL](#) [CX25ABKASGM](#) [CX25ABKASNG](#) [CX25ABKASNO](#) [CX25ABKASOR](#)
[CX25ABKASYL](#) [CX25ABKABK](#) [CX25ABKABL](#) [CX25ABKAGM](#) [CX25ABKANG](#) [CX25ABKANO](#) [CX25ABKAOR](#)
[CX25ABKAYL](#)