
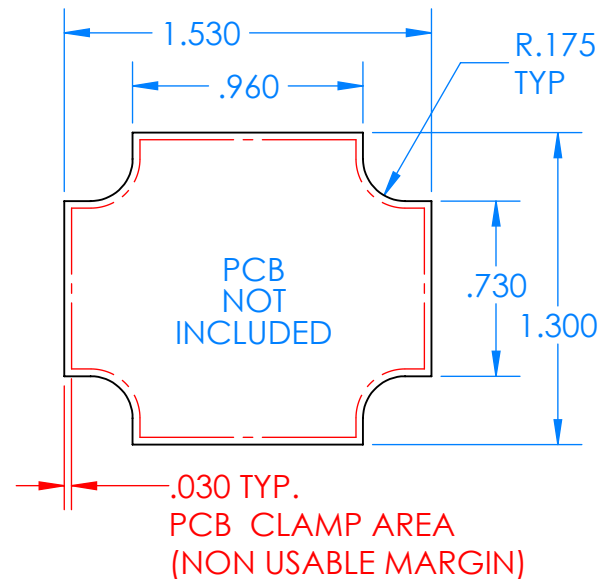
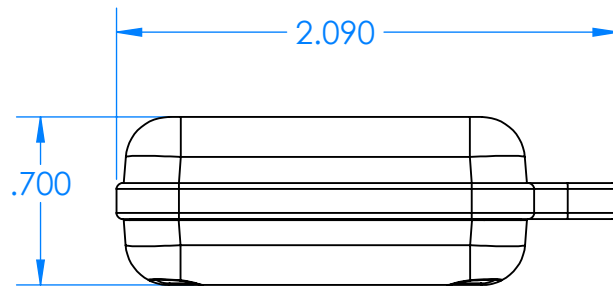
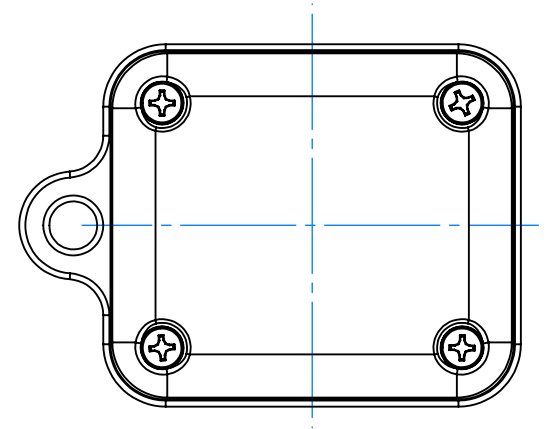


SERPAC CXL24A-YY-A-ZZ


Electronic Enclosures

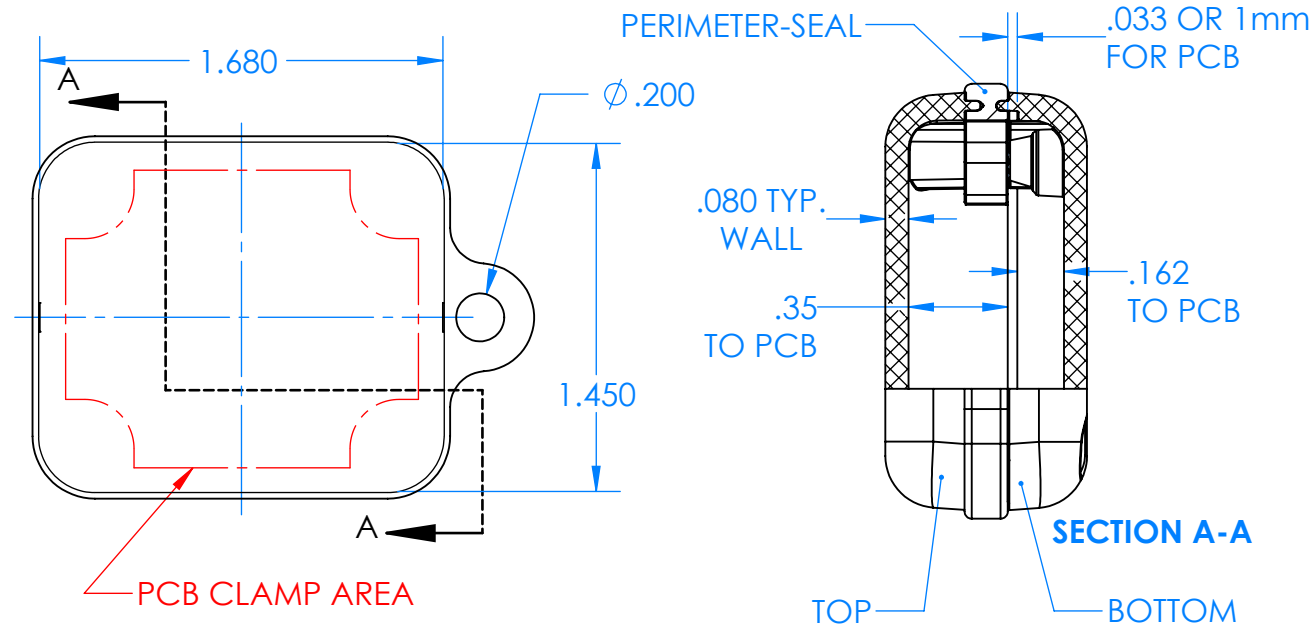

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

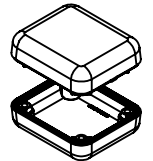

Seal color (ZZ)

 BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white



PN	Description
5512A	(1) BW 2B Top
5513A	(1) BW 2B Bottom
5522A	(1) CXL2 Perimeter Seal
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[CXL24ABKANO](#) [CXL24ABKABK](#) [CXL24ABKAYL](#) [CXL24ABKABL](#) [CXL24ABKAGM](#) [CXL24ABKAOR](#)
[CXL24ABKANG](#) [CXL24ABKAWH](#) [CXL24A-CLBK-A-BK](#) [CXL24A-CLBK-A-BL](#) [CXL24A-CLBK-A-GM](#) [CXL24A-CLBK-](#)
[A-NG](#) [CXL24A-CLBK-A-NO](#) [CXL24A-CLBK-A-OR](#) [CXL24A-CLBK-A-WH](#) [CXL24A-CLBK-A-YL](#)