
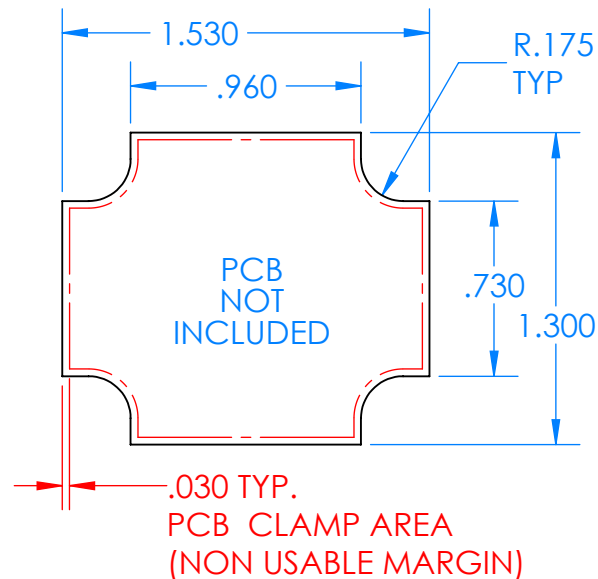
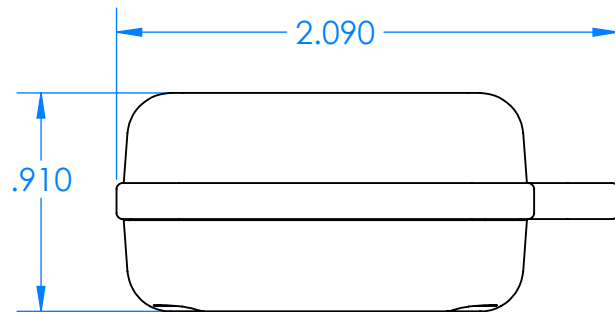


SERPAC CXL28A-YY-A-ZZ


Electronic Enclosures

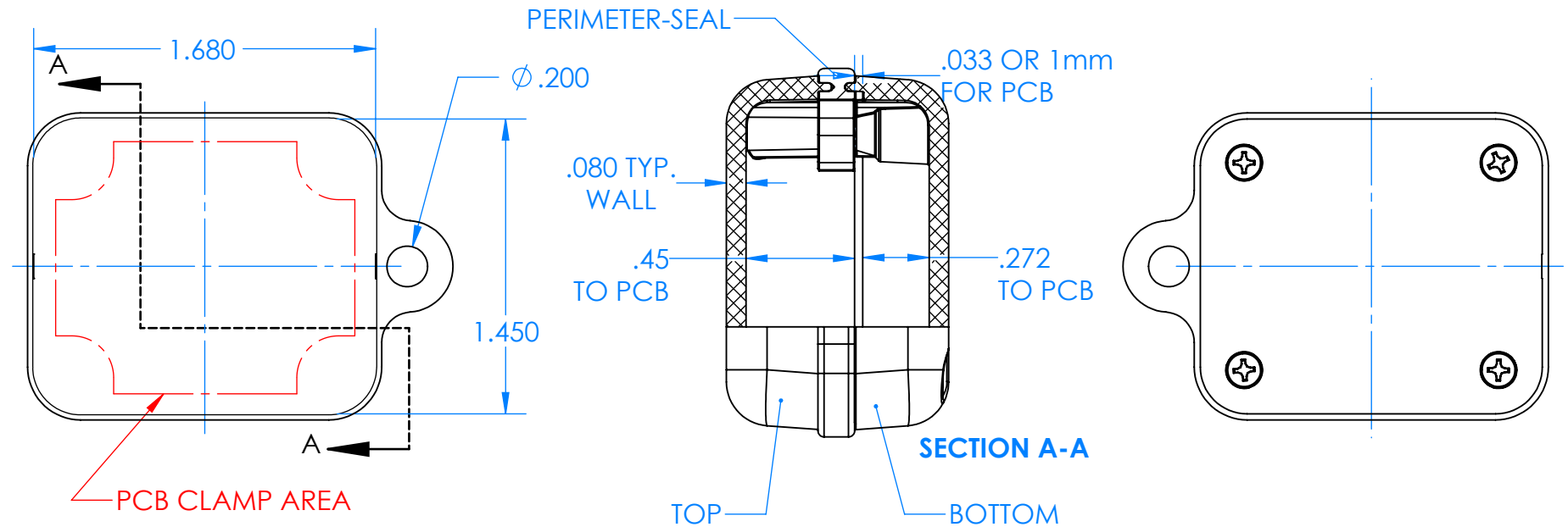

Enclosure color (YY)


Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

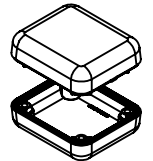

Seal color (ZZ)

 BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white



PN	Description
5514A	(1) BW 2C Top
5515A	(1) BW 2C Bottom
5522A	(1) CXL2 Perimeter Seal
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz

Watertight enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

ALL DIMENSIONS ARE $\pm .010"$
2009 Wright Ave. La Verne, CA 91750
Ph. (626) 331-0517 Fx. (626) 331-8584 serpac.com

9/4/2020

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[CXL28ABKABL](#) [CXL28ABKAYL](#) [CXL28ABKABK](#) [CXL28ABKANG](#) [CXL28ABKAOR](#) [CXL28ABKAGM](#)
[CXL28ABKANO](#) [CXL28ABKAWH](#) [CXL28A-CLBK-A-BK](#) [CXL28A-CLBK-A-BL](#) [CXL28A-CLBK-A-GM](#) [CXL28A-CLBK-](#)
[A-NG](#) [CXL28A-CLBK-A-NO](#) [CXL28A-CLBK-A-OR](#) [CXL28A-CLBK-A-WH](#) [CXL28A-CLBK-A-YL](#)