


SERPAC CXL63D-YY-A-ZZ


Electronic Enclosures

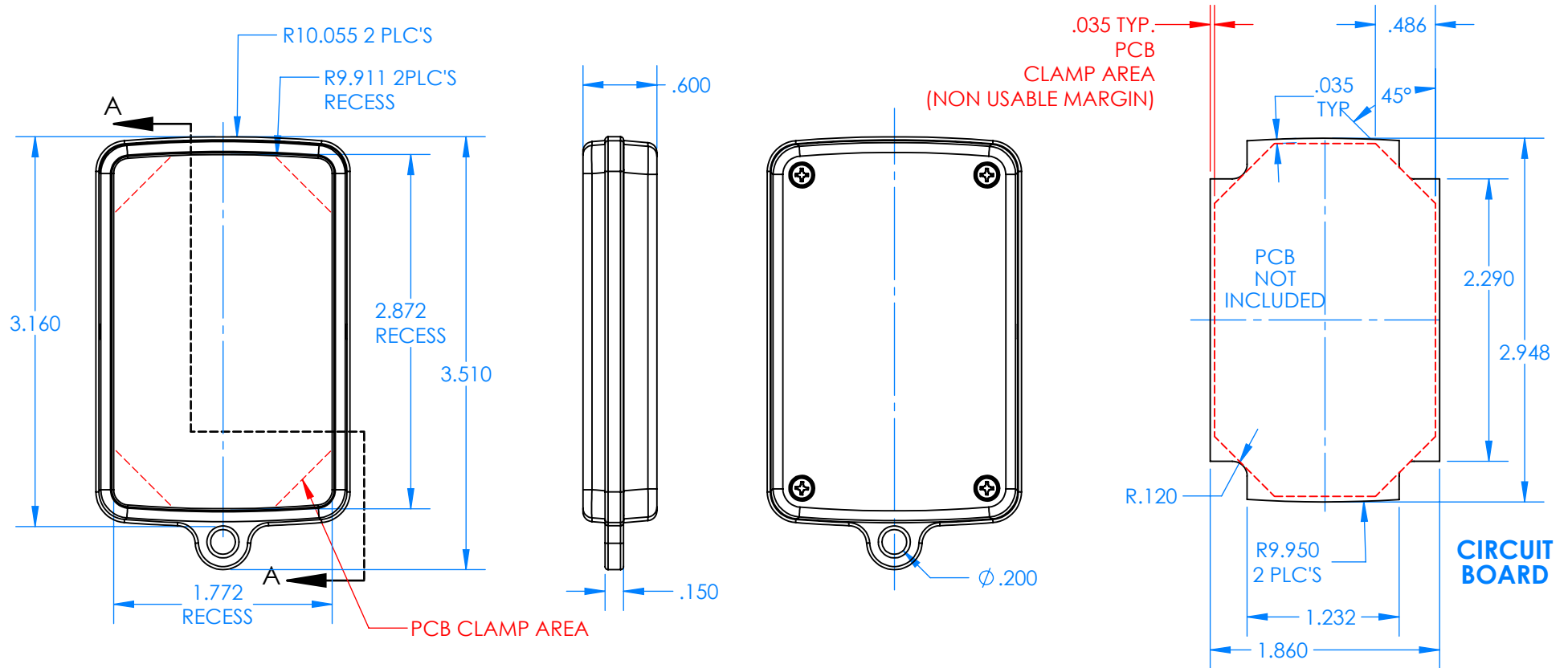

Enclosure color (YY)

Top-Bottom combinations available

BK=black
CL=clear
TRGY=translucent gray
TRRD=translucent red

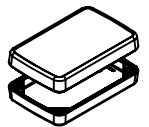

Seal color (ZZ)

BK=black
BL=blue
GM=gunmetal
NG=neon green
NO=neon orange
OR=orange
YL=yellow
WH=white



PN	Description
5531D	(1) BW 6A Top style D
5534D	(1) BW 6B Bottom style D.
5541A	(1) CXL6A Series perimeter seal style A
6002	(4) #2 X 3/8" PH HD screw TORQUE 35-60 in-oz.

Wateright enclosure meets or exceeds:
IP67
NEMA 4X, 12, 13

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[CXL63DBKAYL](#) [CXL63DBKABK](#) [CXL63DBKAGM](#) [CXL63DBKABL](#) [CXL63DBKANO](#) [CXL63DBKAOR](#)
[CXL63DBKANG](#) [CXL63DBKAWH](#) [CXL63D-CLBK-A-BK](#) [CXL63D-CLBK-A-BL](#) [CXL63D-CLBK-A-GM](#) [CXL63D-CLBK-](#)
[A-NG](#) [CXL63D-CLBK-A-NO](#) [CXL63D-CLBK-A-OR](#) [CXL63D-CLBK-A-WH](#) [CXL63D-CLBK-A-YL](#)