


# SERPAC P24

Electronic Enclosures

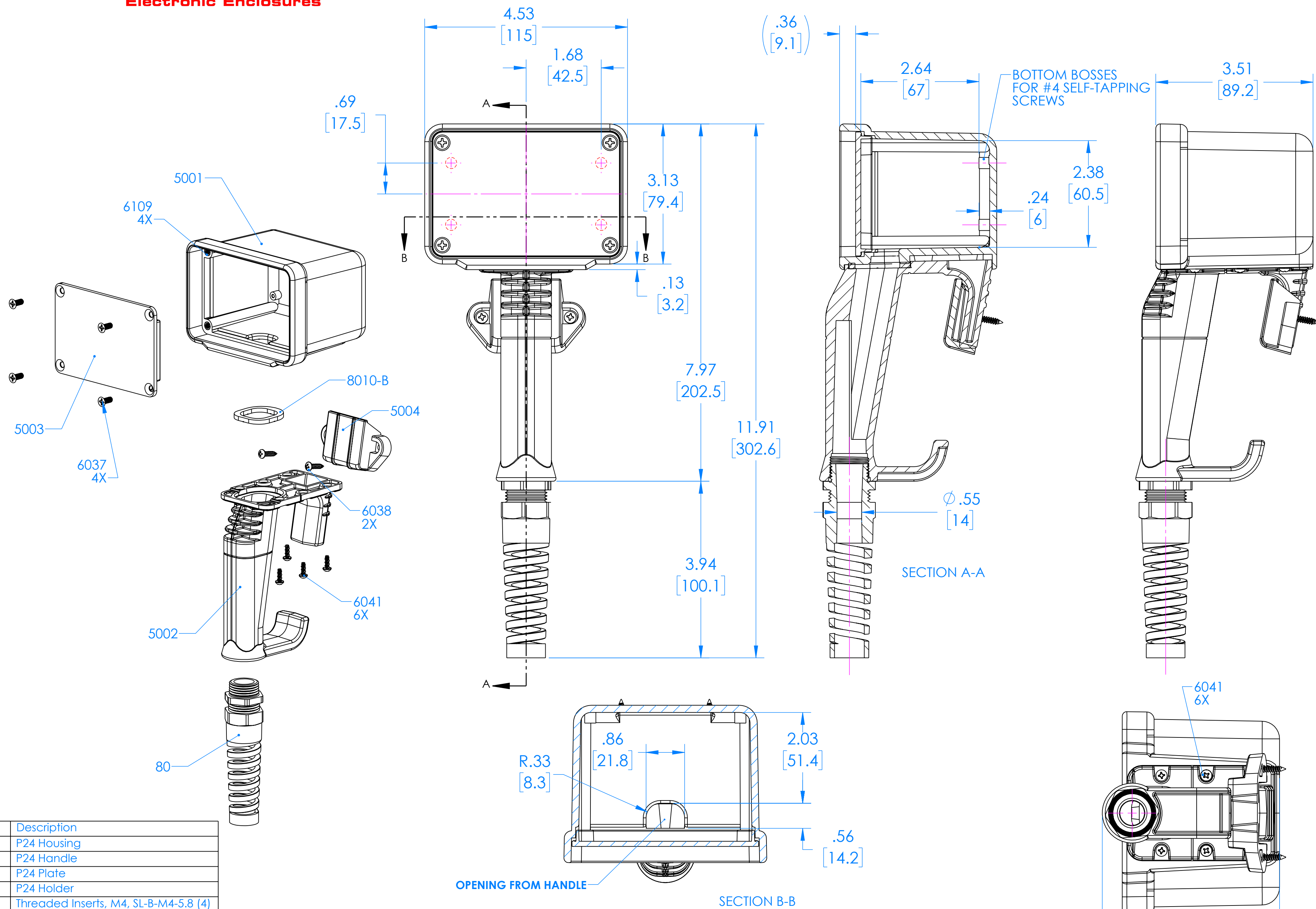


| PN     | Description                            |
|--------|----------------------------------------|
| 5001   | P24 Housing                            |
| 5002   | P24 Handle                             |
| 5003   | P24 Plate                              |
| 5004   | P24 Holder                             |
| 6109   | Threaded Inserts, M4, SL-B-M4-5.8 (4)  |
| 80     | PG-16 Pigtail                          |
| 6041   | SS Truss Hd, Hi-Lo Screw, #4 x 3/8 (6) |
| 6037   | SS Flat Hd. Screw M4 x 10mm (4)        |
| 6038   | SS Pan Hd Slotted head #6 X 5/8"(2X)   |
| 8010-A | P24 Plate Gasket                       |
| 8010-B | P24 Handle Gasket                      |

- Notes:
- Unit is shipped with Handle/Housing gasket installed. Plate to Housing gasket is user installed.
  - Dim's in Inch/[mm].
  - Standard Material is UL94 HB Polyester (Yellow or Black).
  - Watertight enclosure meets or exceeds Nema 4x / IP66.


# SERPAC Plate & Circuit Board for P24 and P26

Electronic Enclosures

PN 5003 P24 PLATE (INCLUDED)

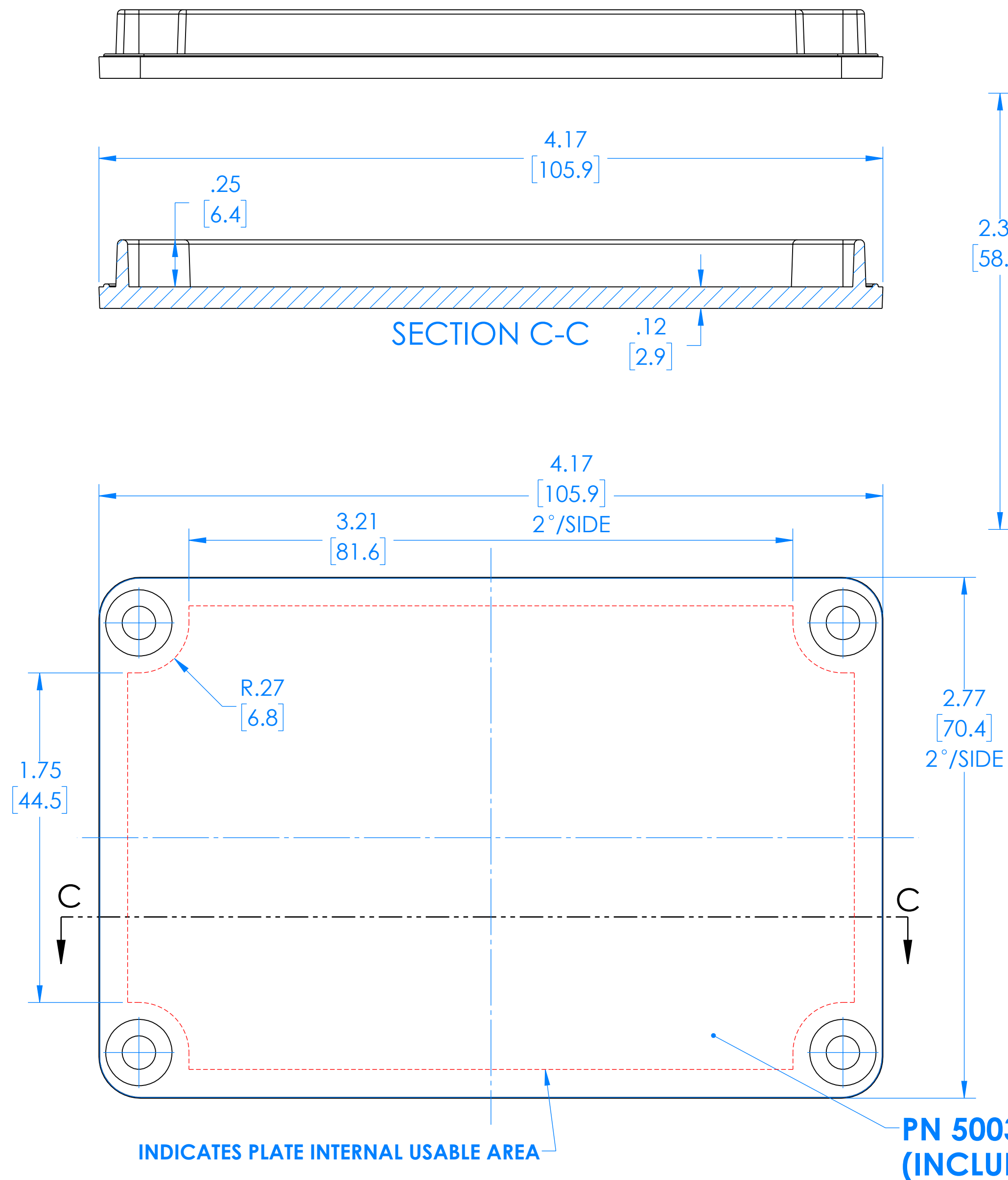

P24-P26 CIRCUIT BOARD (NOT INCLUDED)

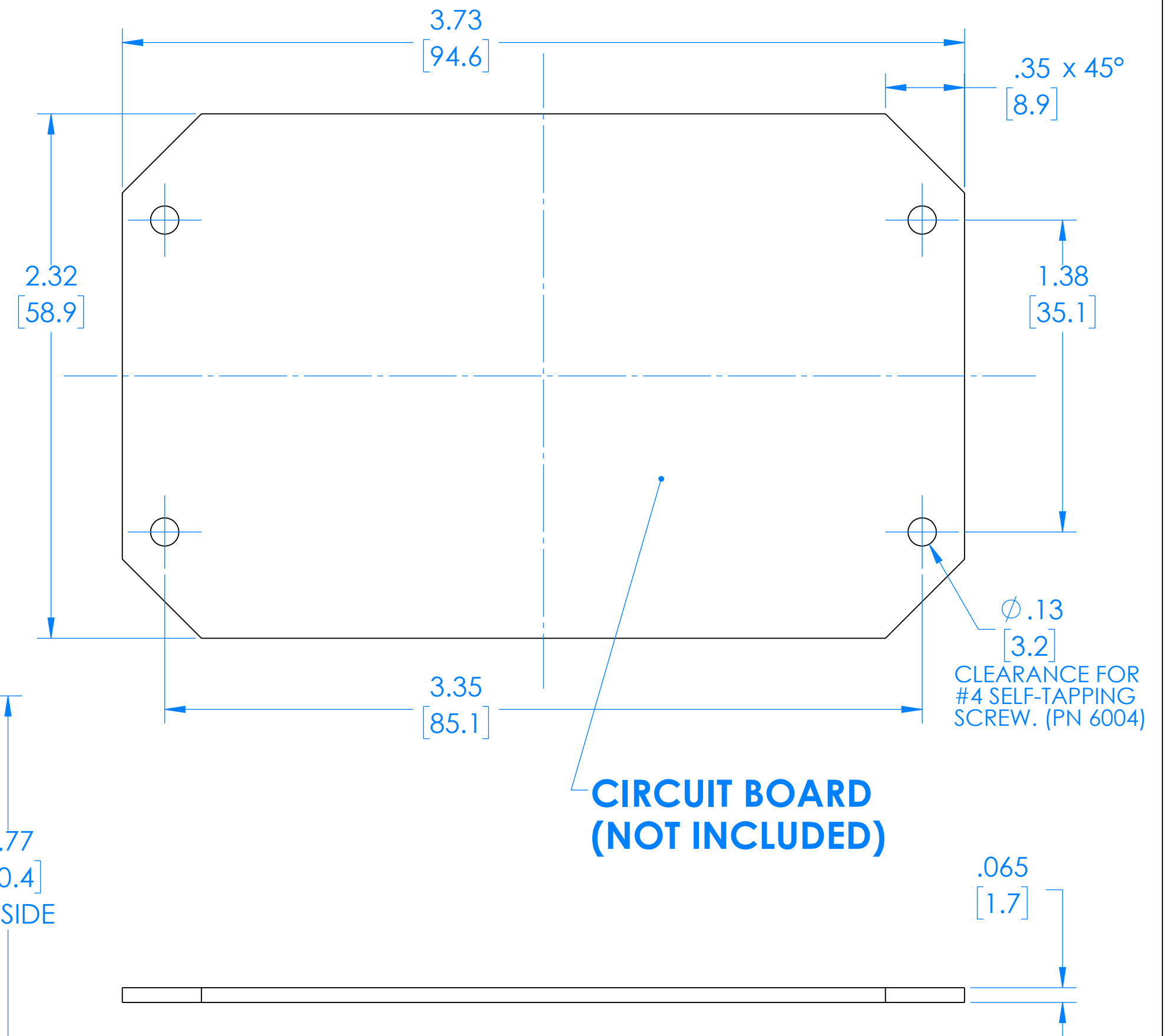

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

PC24BK PC24YL