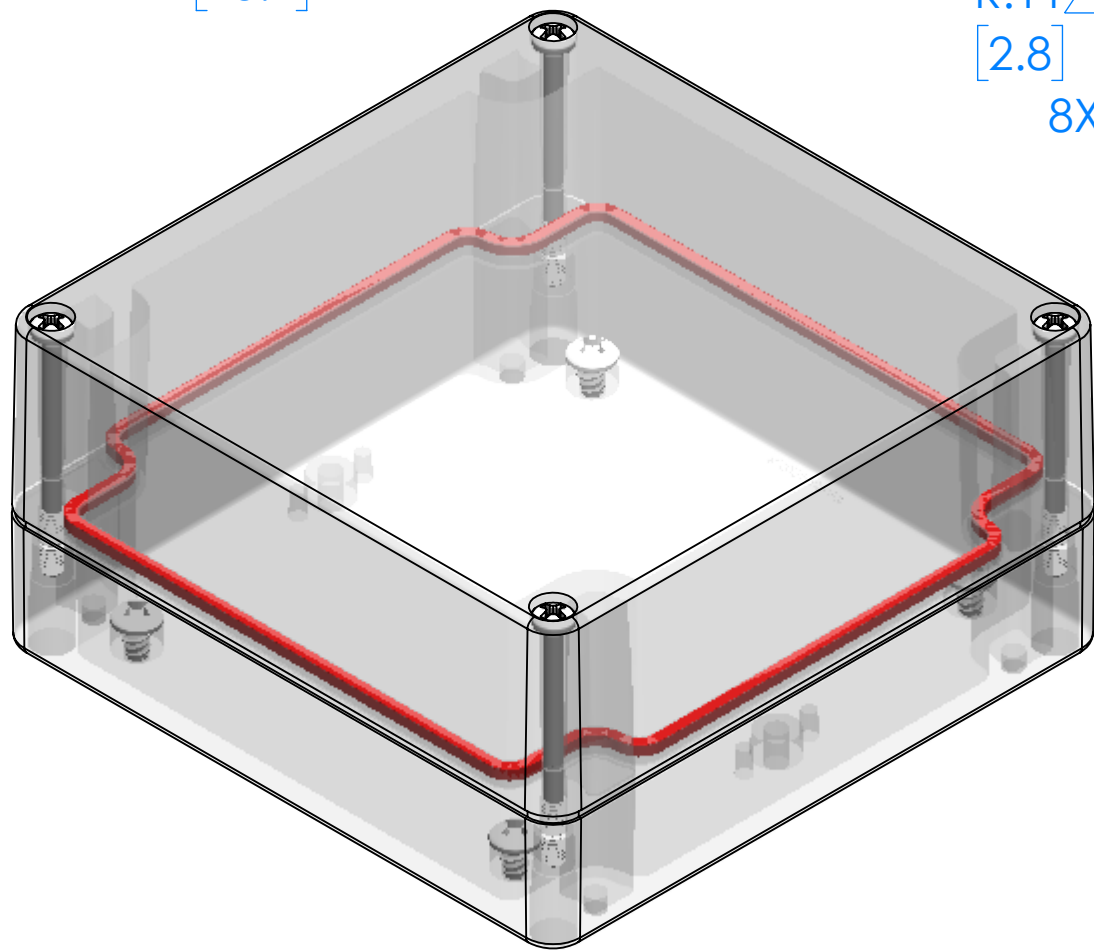
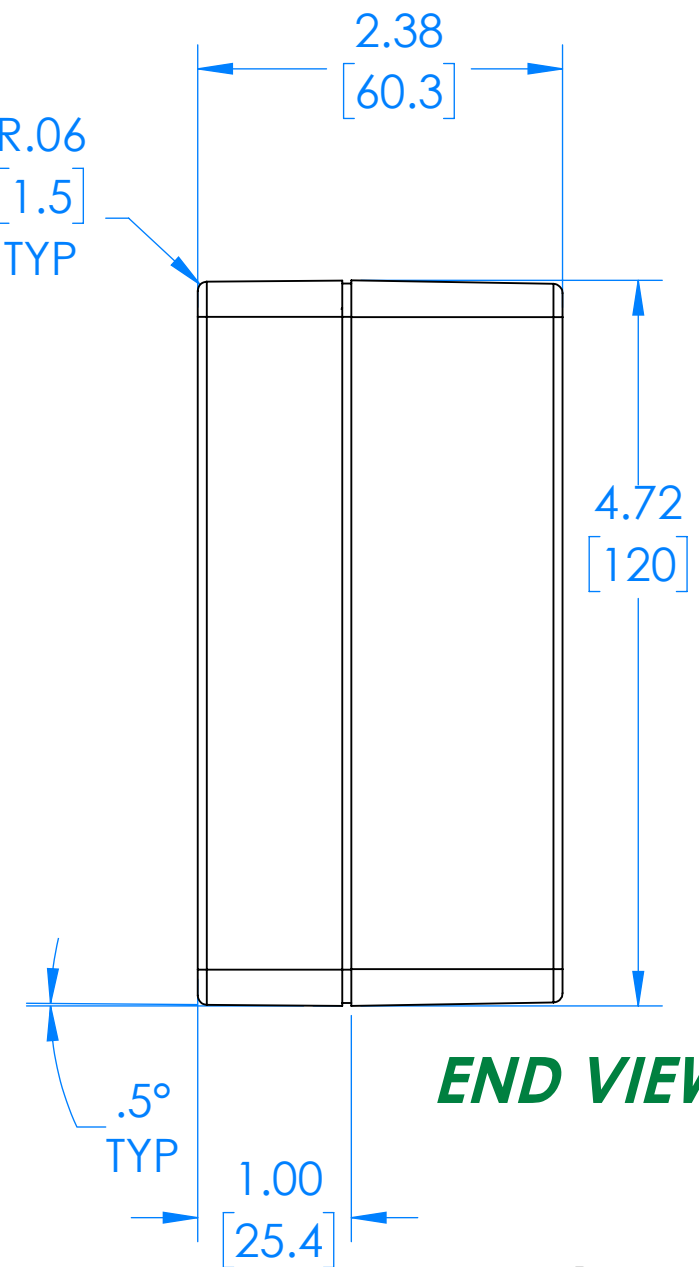


RB55X14C16C 

PN	Description
RB55-X14Y	(1) RB55X14Y, Top
RB55X10Y	(1) RB55X10Y, Bottom
8055	(1) RB55 O-Ring
6052	(4) #6-32 Combo Hd captive Screw
6022	(4) #10 High/Low Pan Hd x 1/4"
6113	(4) #6-32 Threaded Insert

1

2


-Wa

Dimensions represent Polycarbonate material.
Dim's in Inch
[mm]

ALL DIMENSIONS ARE $\pm .010"$ 8/04/2021
2009 Wright Street, La Verne, Ca. 91750
Ph. (626) 331-0517 Fx. (626) 331-8584 serpac.com

SERPAC
Electronic Enclosures

RB55 Circuit Board (Fits all Parts starting with RB55)

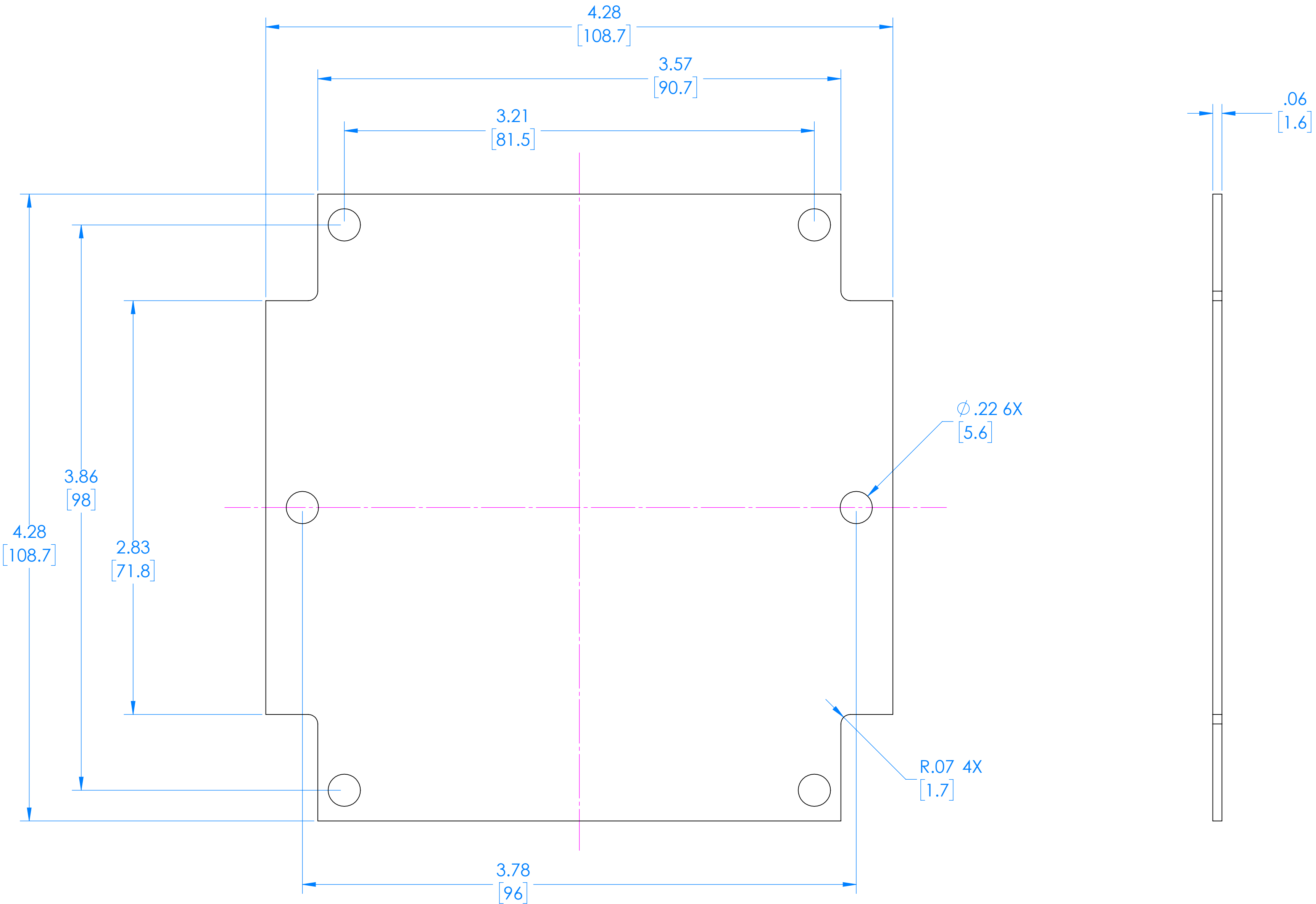

(REFERENCE ONLY)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[RB55-A14B28B](#) [RB55-A06G28C](#) [RB55-A14B28C](#) [RB55-P14G28C](#) [RB55-P14G28G](#) [RB55-A06G28G](#) [RB55-A14C28B](#) [RB55-A14C28G](#) [RB55-A14C28C](#) [RB55-P14B28C](#) [RB55-P14B28B](#) [RB55-P06C28C](#) [RB55-P06C28G](#) [RB55-P06C28B](#) [RB55-A06C28B](#) [RB55-P06G28C](#) [RB55-P14C28B](#) [RB55-A06B28B](#) [RB55-A06C28C](#) [RB55-A06C28G](#) [RB55-P14C28C](#) [RB55-P14C28G](#) [RB55-A06B28C](#) [RB55-A14G28C](#) [RB55-A14G28G](#) [RB55-P06B28C](#) [RB55-P06B28B](#) [RB55-P06G28G](#) [RB55-P06G10G](#) [RB55-P14B16C](#) [RB55-P14G16C](#) [RB55-P14G16G](#) [RB55-A14C16G](#) [RB55-A14C16C](#) [RB55-P06B10B](#) [RB55-P06B10C](#) [RB55-A14C16B](#) [RB55-A06B10C](#) [RB55-A06B10B](#) [RB55-P14B16B](#) [RB55-A06G10C](#) [RB55-A06C10B](#) [RB55-A06G10G](#) [RB55-P06C10G](#) [RB55-P06C10C](#) [RB55-A14G16G](#) [RB55-A14G16C](#) [RB55-P06C10B](#) [RB55-A14B16C](#) [RB55-A14B16B](#) [RB55-P14C16G](#) [RB55-P14C16C](#) [RB55-P14C16B](#) [RB55-P06G10C](#) [RB55-A06C10C](#) [RB55-A06C10G](#) [RB32-A04G10G](#) [RB55-P06C16B](#) [RB32-A04G10C](#) [RB32-A04B10C](#) [RB32-A04B10B](#) [RB55-P06C16C](#) [RB55-P06C16G](#) [RB55-A06G16C](#) [RB55-A06G16G](#) [RB32-A04C10B](#) [RB32-A04C10G](#) [RB32-A04C10C](#) [RB55-P06B16B](#) [RB32-P04G10G](#) [RB55-P06B16C](#) [RB32-P04G10C](#) [RB32-P04C10B](#) [RB55-A06C16B](#) [RB55-A06C16G](#) [RB32-P04C10G](#) [RB32-P04C10C](#) [RB55-A06C16C](#) [RB55-P06G16C](#) [RB55-P06G16G](#) [RB32-P04B10C](#) [RB55-A06B16C](#) [RB32-P04B10B](#) [RB55-A06B16B](#) [RB33-A06B16C](#) [RB33-P06C16G](#) [RB33-P06C16C](#) [RB33-A06B16B](#) [RB33-P06C16B](#) [RB33-A06G16C](#) [RB33-A06G16G](#) [RB33-P06B16C](#) [RB33-P06B16B](#) [RB33-A06C16G](#) [RB33-A06C16C](#) [RB33-A06C16B](#) [RB33-P06G16C](#) [RB33-P06G16G](#) [RB66-1TB1BC](#) [RB66-1TC1BG](#)