
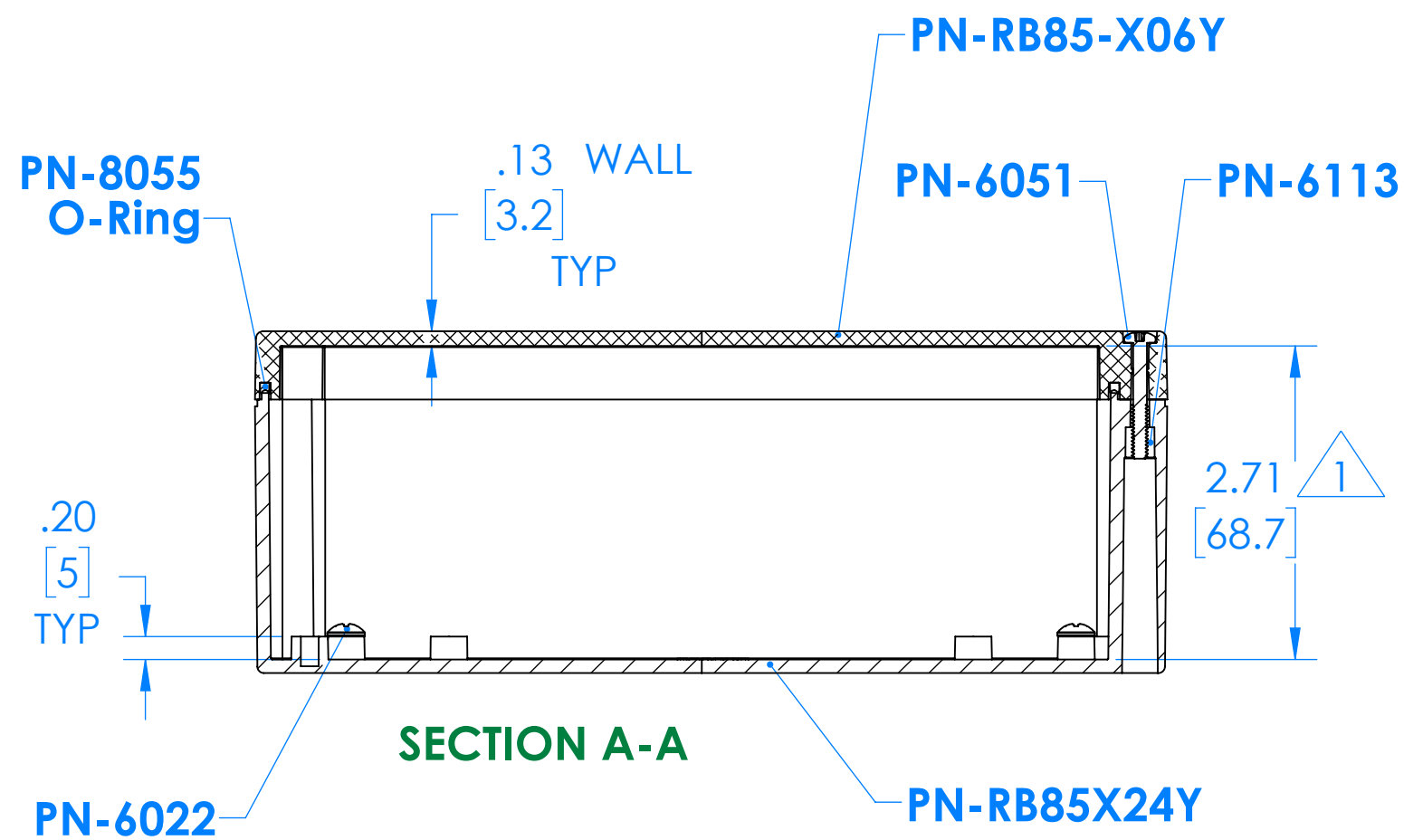
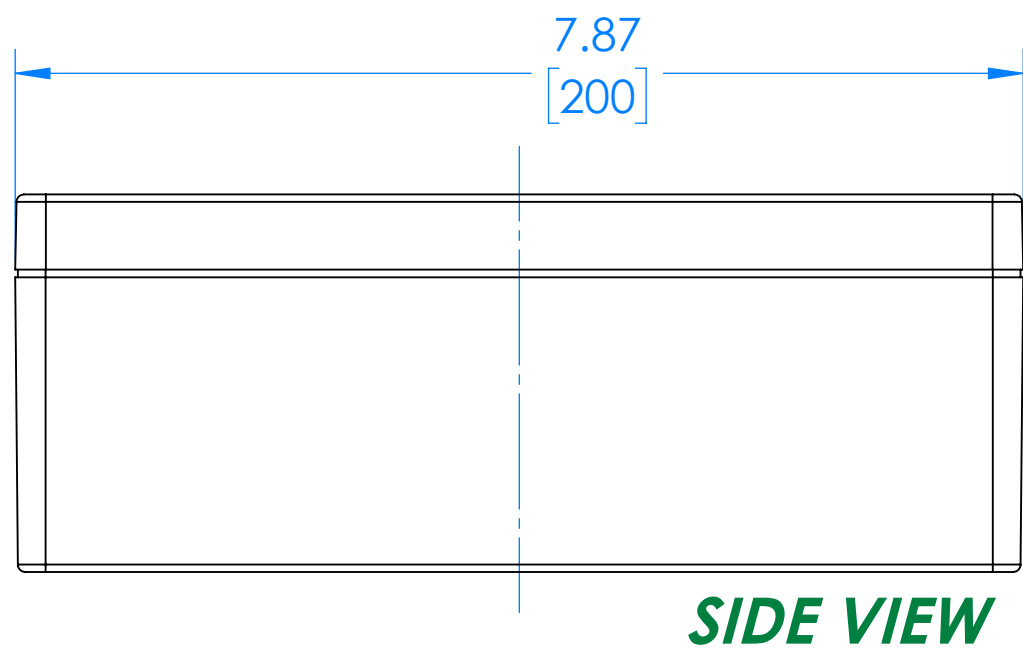
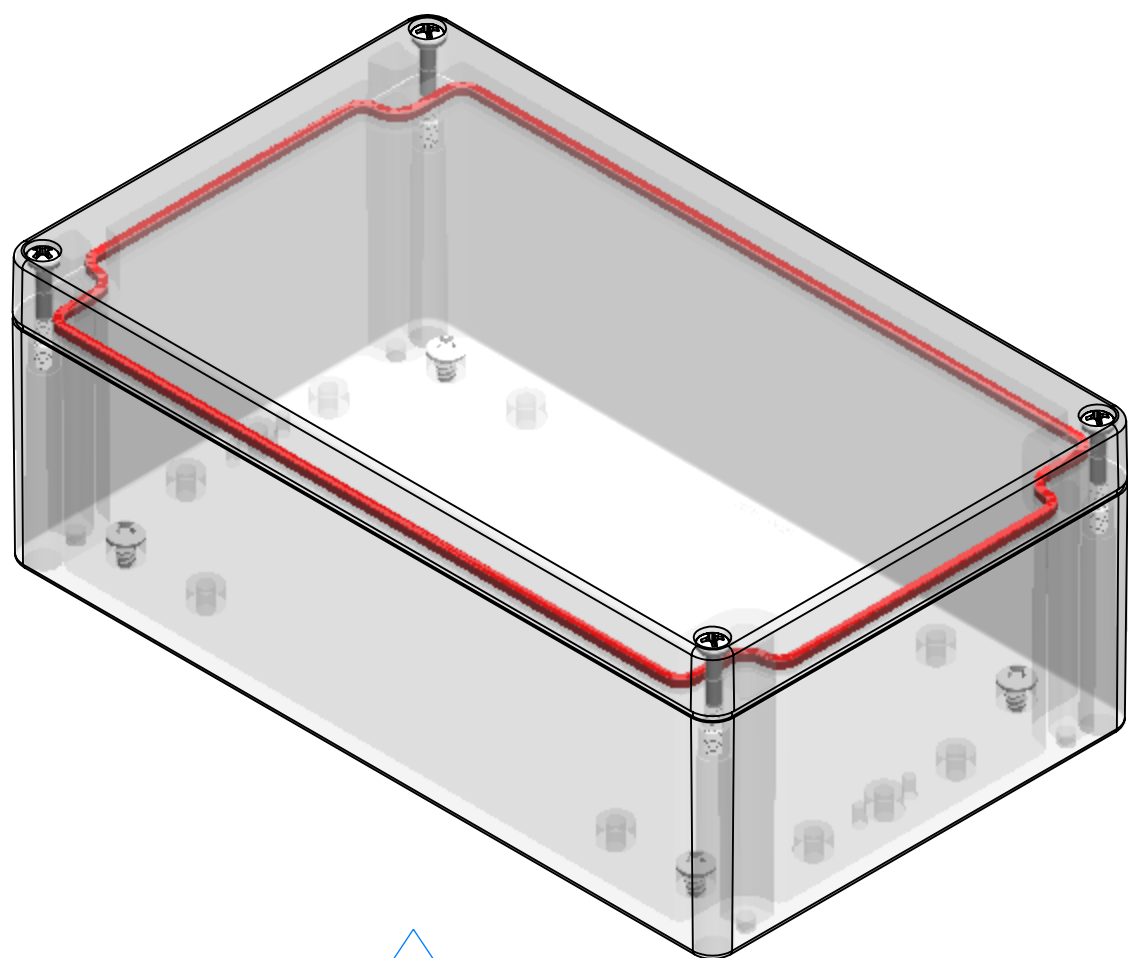


SERPAC RB85X06Y24Y

Electronic Enclosures

2

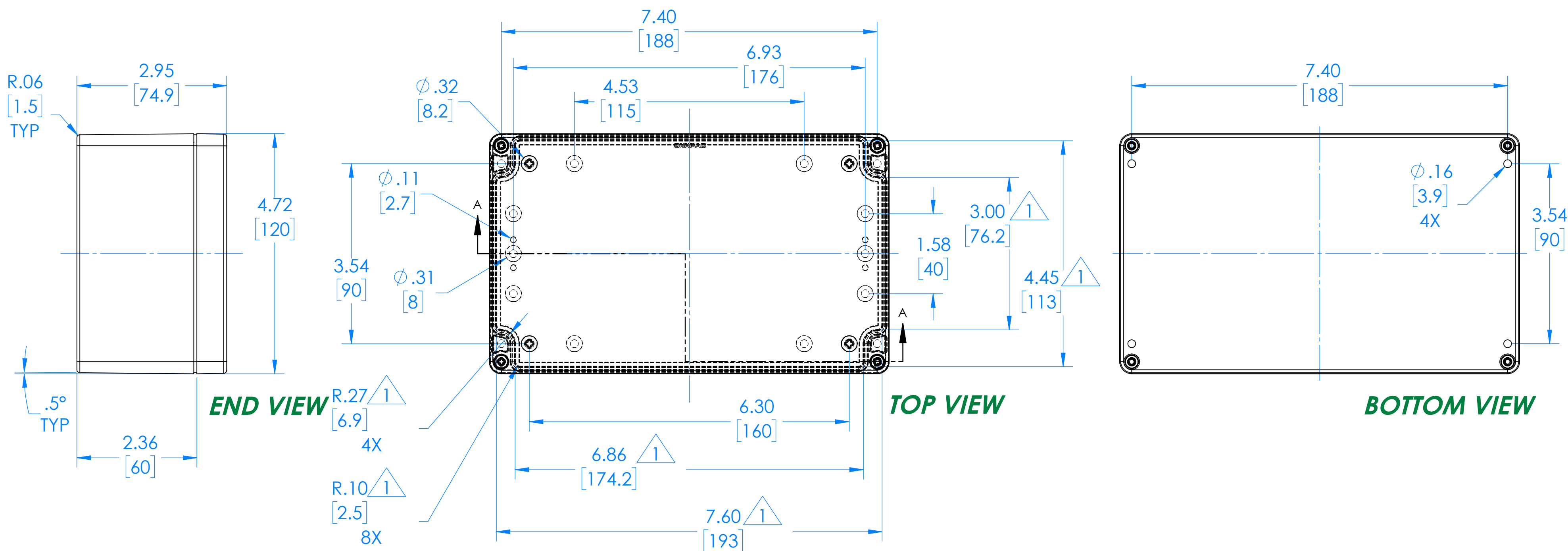

RB85X06C24C 2

(Part shown, no material (X) specified)

PN	Description
RB85-X06Y	(1) RB85-X06Y, Top
RB85X24Y	(1) RB85X24Y, Bottom
8085	(1) RB85 O-Ring
6051	(4) #6-32 Torx 10 Hd Captive Screw
6022	(4) #10 High/Low Pan Hd x 1/4"
6113	(4) #6-32 SS Threaded Insert


- 1 = INTERIOR DIMENSIONS (@ BOTTOM)
- 2 = STANDARD COLORS (Y) ARE: BLACK (B), CLEAR (C) AND GRAY (G)
TOPS AND BOTTOMS ALL POSSIBLE COMBINATIONS AVAILABLE
STANDARD MATERIALS (X) IS: POLYCARBONATE (P)

-Watertight enclosure meets or exceeds Nema 4 and or IP67.

DIMENSIONS in Inch [mm]

ALL DIMENSIONS ARE $\pm .010"$ 7/26/2021
2009 Wright Ave., La Verne, CA. 91750
Ph. (626) 331-0517 Fx. (626) 331-8584 serpac.com

RB85 Circuit Board (Fits all Parts starting with RB85)

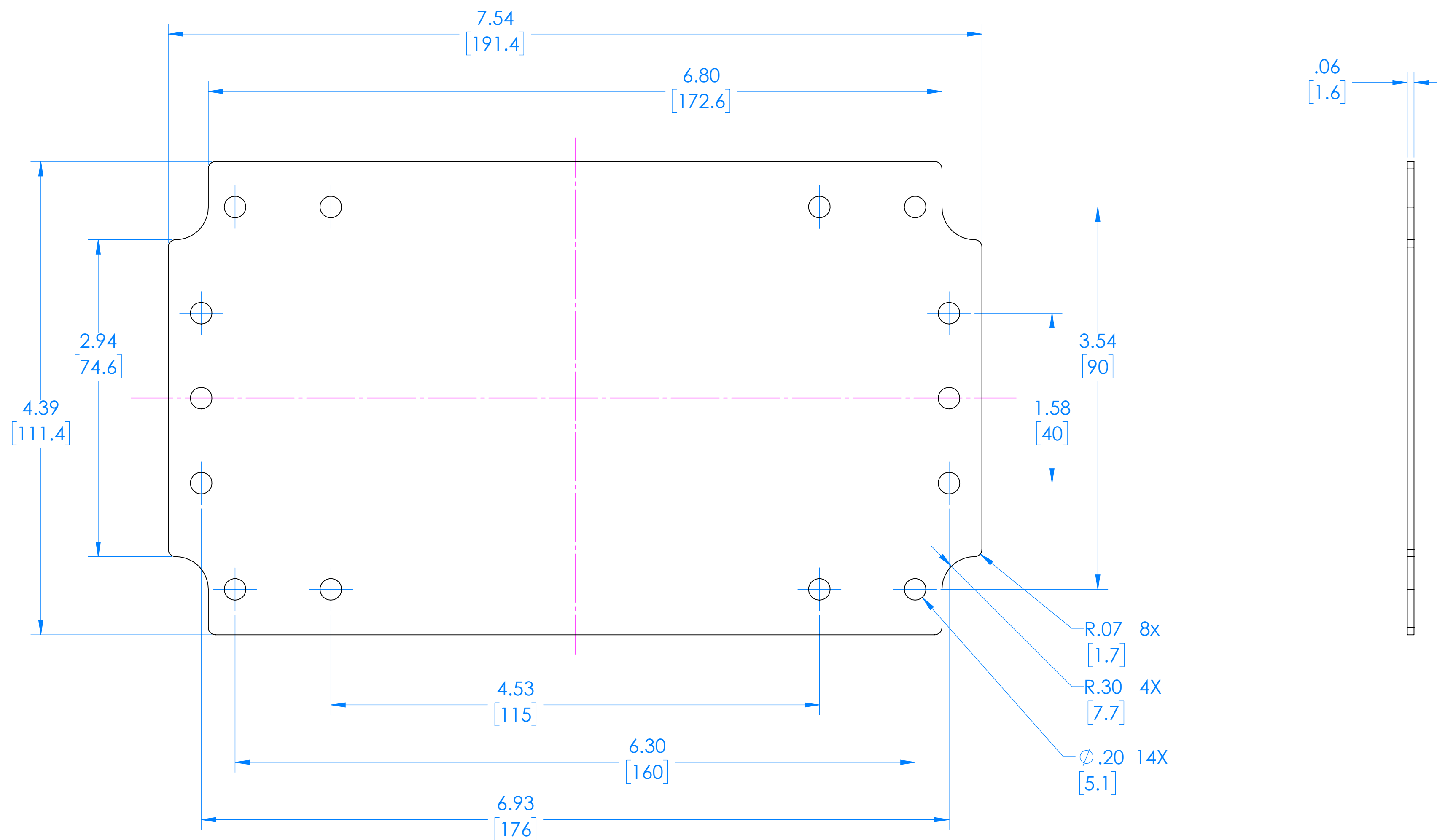

(REFERENCE ONLY)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[RB85-P06G24G](#) [RB85-P06G24C](#) [RB85-P06C24G](#) [RB85-P06C24B](#) [RB85-P06C24C](#) [RB85-A06G24G](#) [RB85-A06G24C](#) [RB85-A06C24C](#) [RB85-A06C24G](#) [RB85-A06B24C](#) [RB85-A06C24B](#) [RB85-A06B24B](#) [RB85-P06B24B](#)
[RB85-P06B24C](#)