


SERPAC RB85X12Y24Y

Electronic Enclosures

2

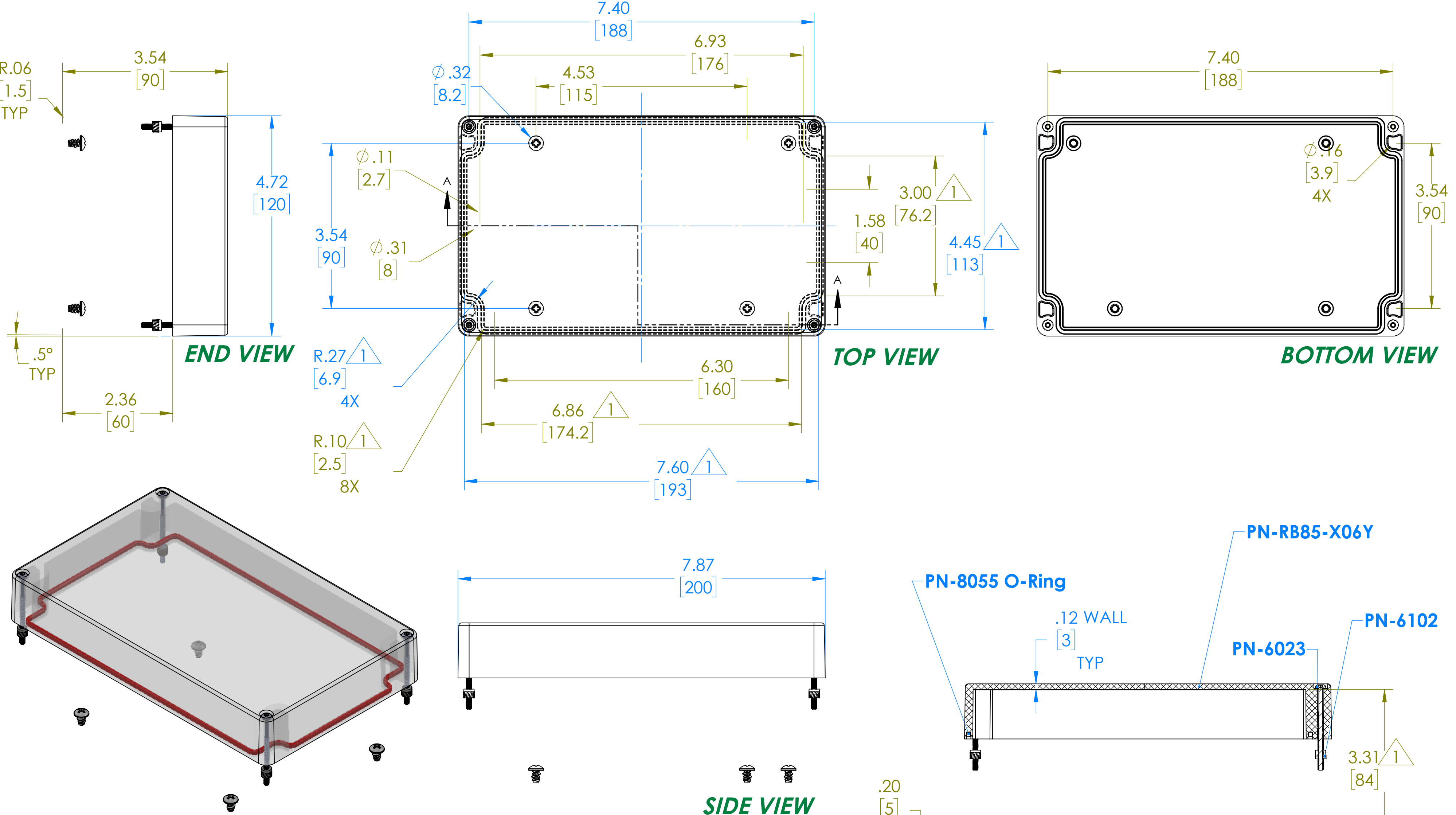


RB85X12C24C 2
(Part shown, no material (X) specified)

PN	Description
RB85-X12Y	(1) RB85-X12Y, Top
RB85X24Y	(1) RB85X24Y, Bottom
8085	(1) RB85 O-Ring
6032	(4) #4-40 X 1 3/4" Torx 10 Hd Screw
6022	(4) #10 High/Low Pan Hd x 1/4"
6102	(4) #4-40 Threaded Insert


- 1 = INTERIOR DIMENSIONS (@ BOTTOM)
- 2 = STANDARD COLORS (Y) ARE: BLACK (B), CLEAR (C) AND GRAY (G)
TOPS AND BOTTOMS ALL POSSIBLE COMBINATIONS AVAILABLE
STANDARD MATERIALS (X) IS: POLYCARBONATE (P)

-Watertight enclosure meets or exceed Nema 4 and or IP67.

DIMENSIONS in Inch
[mm]

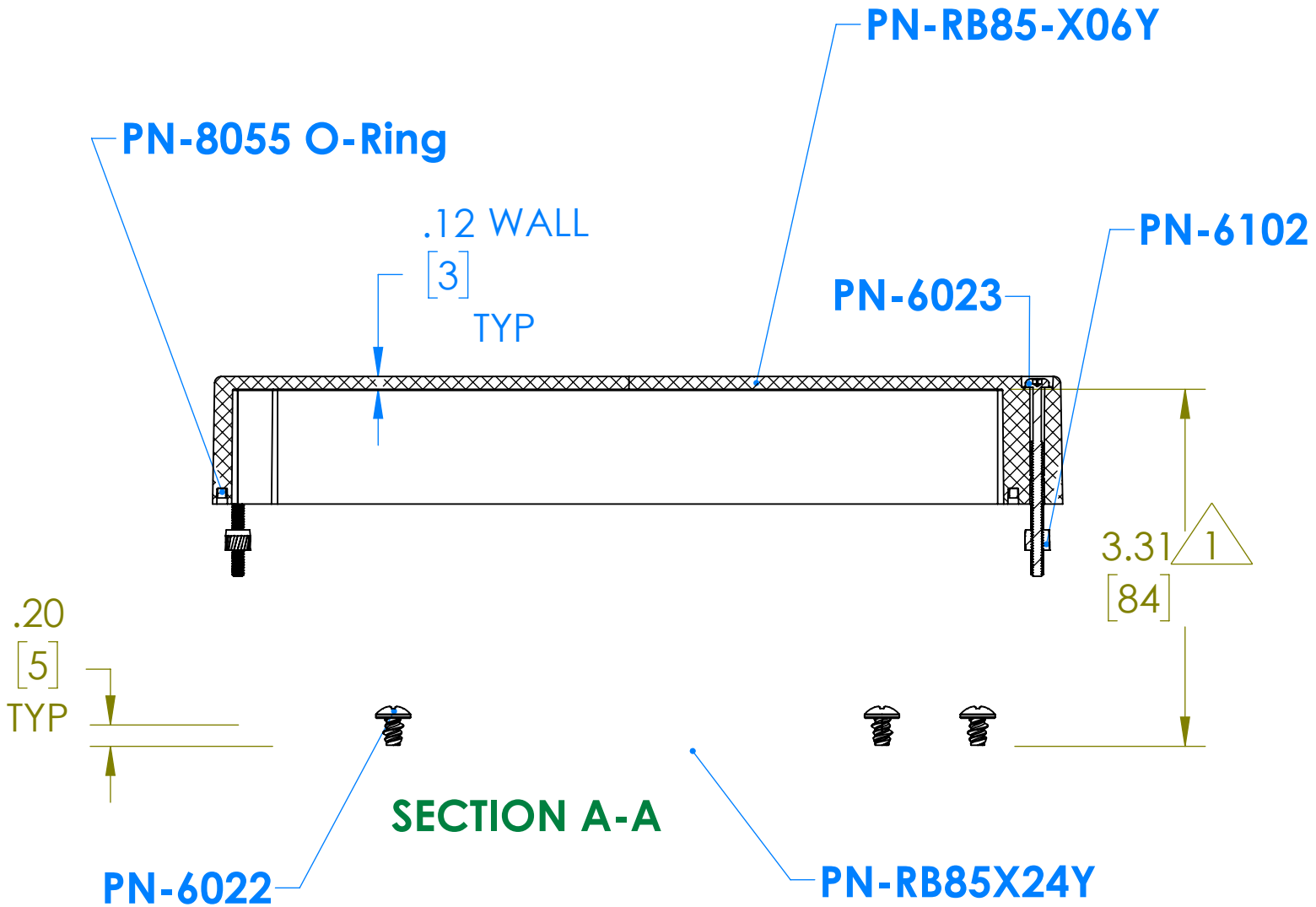

RB85 Circuit Board (Fits all Parts starting with RB85)

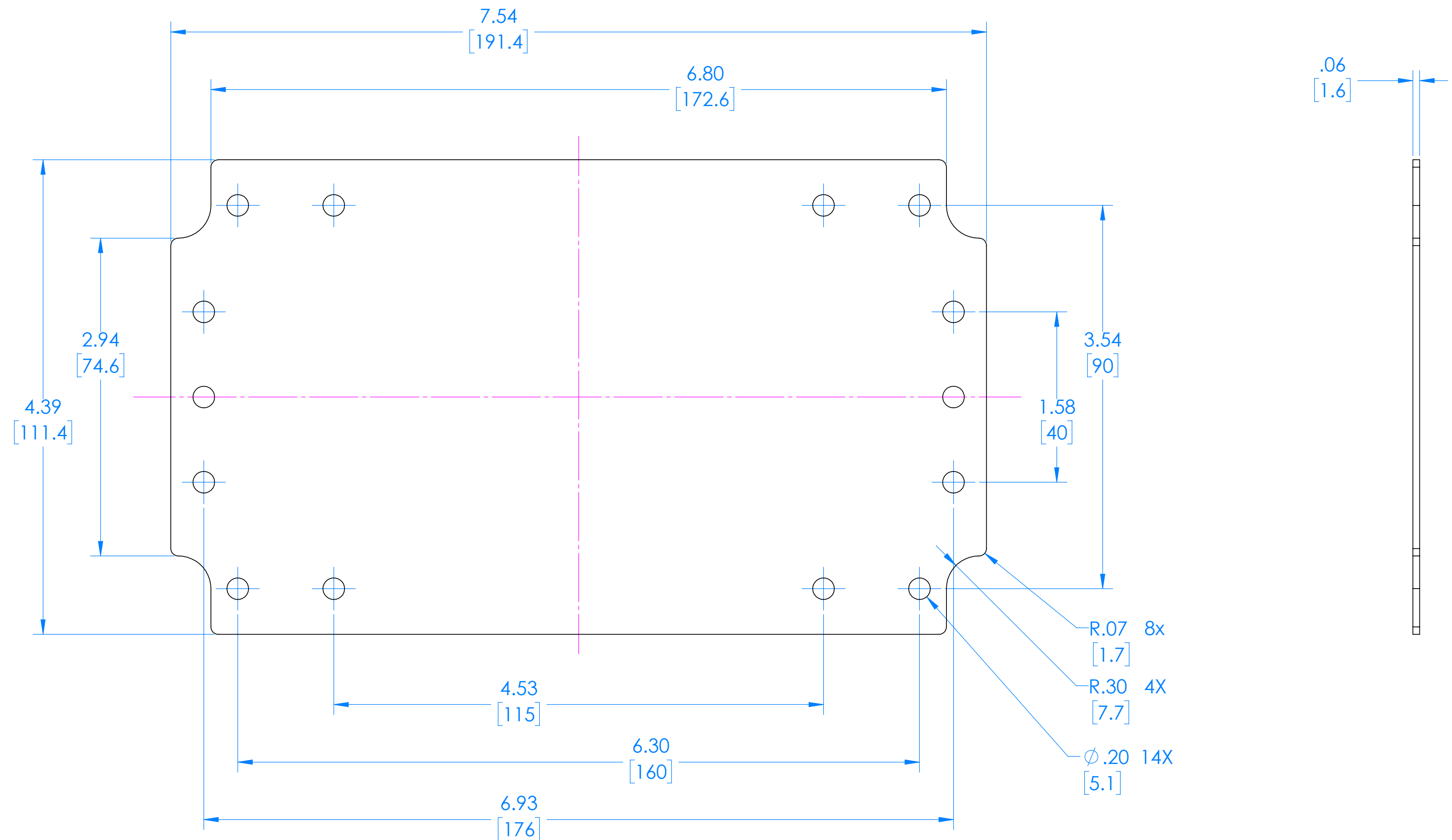

(REFERENCE ONLY)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SERPAC:

[RB85-P12B24B](#) [RB85-A12C24C](#) [RB85-A12C24G](#) [RB85-A12G24C](#) [RB85-A12G24G](#) [RB85-A12C24B](#) [RB85-P12B24C](#) [RB85-A12B24B](#) [RB85-A12B24C](#) [RB85-P12C24B](#) [RB85-P12C24G](#) [RB85-P12C24C](#) [RB85-P12G24C](#)
[RB85-P12G24G](#)