

Elapsed Time Meters

- Record “on” time of electrical equipment
- Choice of AC or DC Models
- No reset capability means virtually tamper proof
- 2 sizes and 6 different case styles

Model 112ET



CE

E236182

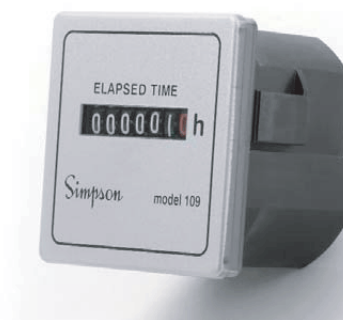
Model 1357ET / Wide-Vue



Model 55ET / Round



Model 109ET



CE

E171200

Model 2153ET / Century

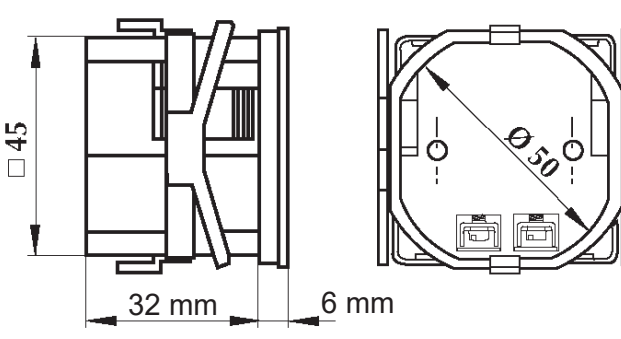
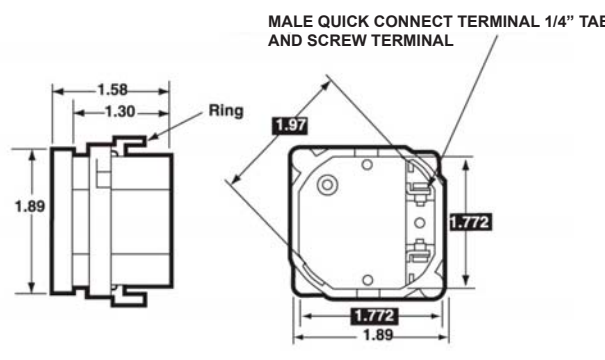
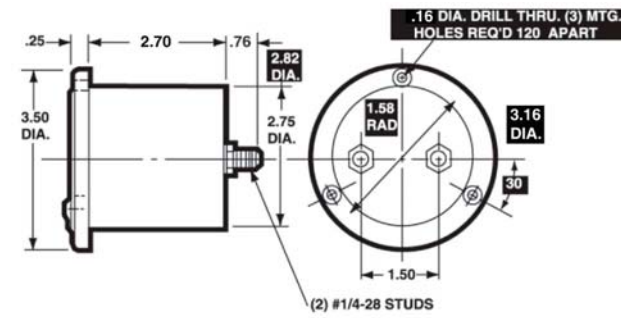
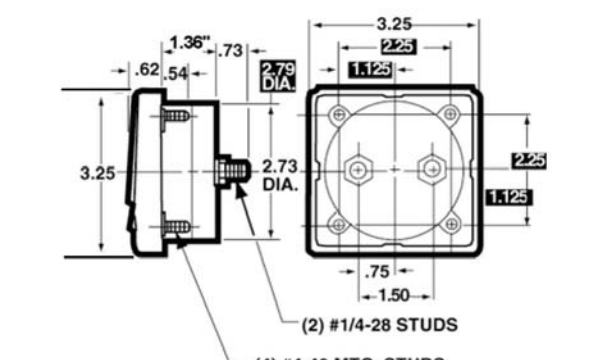
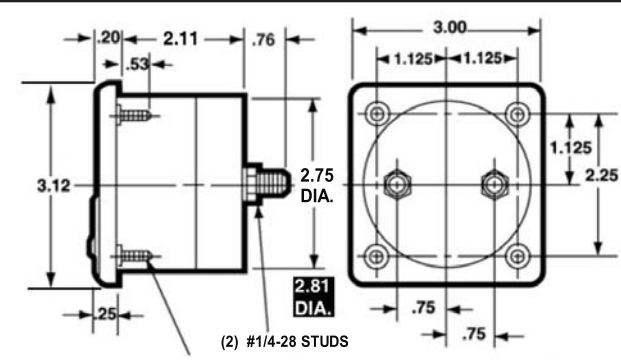
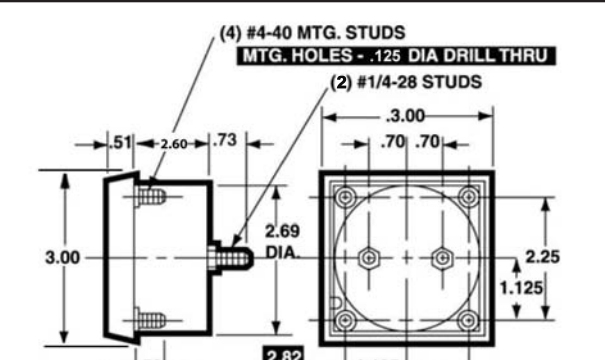


Model 57ET / Rectangular



Elapsed Time Meters

Dimensions

1 - 1/2" Model 109ET  Units in mm	1 - 1/2" Model 112ET  ■ = Panel Meter Cut-out Dimensions
3 - 1/2" Model 55ET  (2) #1/4-28 STUDS	3 - 1/2" Model 1357ET  (2) #1/4-28 STUDS (4) #4-40 MTG. STUDS MTG. HOLES - .125 DIA. DRILL THRU
3 - 1/2" Model 57ET  (2) #1/4-28 STUDS (4) #4-40 MTG. STUDS MTG. HOLES - .125 DIA. DRILL THRU	3 - 1/2" Model 2153ET  (4) #4-40 MTG. STUDS (2) #1/4-28 STUDS MTG. HOLES - .125 DIA. DRILL THRU

Elapsed Time Meters

Specifications

Accuracy	Models 109ET & 112ET: $\leq .01\%$ / 24 hrs
	Models 55ET, 57ET, 1357ET & 2153 ET: Synchronous with AC Power
Movement	Synchronous clock motor
Overload (1 sec.)	10 times F.S.
Maximum Indication	See ordering information
Power Consumption	Models 109ET, 112ET: .5 watts
	All other models: 2.5 watts
Case	Models 55ET, 57ET, 2153ET: high density plastic
	Models 109ET, 112ET, 1357ET: high density black acrylic
Operating Temperature	-4°F to +149°F (-20°C to +65°C)
Net Weight	Models 112ET, 109ET: 2.5 oz. (0.07kg)
	Models 55ET, 57ET: 12.5 oz. (0.35kg)
	Models 1357ET, 2153ET: 13 oz. (0.37kg)

Ordering Information

Operating Voltage	Maximum Indication (hours)	Power Consumption	Accuracy	Model Size	Model No	Catalog No.
10-80 DCV	999,999.9	.5 watt	$\leq .01\%$ / 24 hrs	1 - 1/2"	109ET	03618
120 VAC	99,999.99	.5 watt	$\leq .01\%$ / 24 hrs		112ET	03622
120 VAC 60 Hz	99,999.9	2.5 watts	synchronous	3 - 1/2"	55ET	03580
	99,999.9	2.5 watts	synchronous		57ET	03590
	99,999.9	2.5 watts	synchronous		1357ET	03595
	99,999.9	2.5 watts	synchronous		2153ET	17720
240 VAC 60 Hz	99,999.9	2.5 watts	synchronous	3 - 1/2"	55ET	03600
	99,999.9	2.5 watts	synchronous		57ET	03610
	99,999.9	2.5 watts	synchronous		1357ET	03615
	99,999.9	2.5 watts	synchronous		2153ET	17721

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Simpson:

[03622](#) [03610](#) [03618](#) [03600](#) [03615](#) [03595](#) [03580](#) [03590](#) [17720](#) [17721](#)