
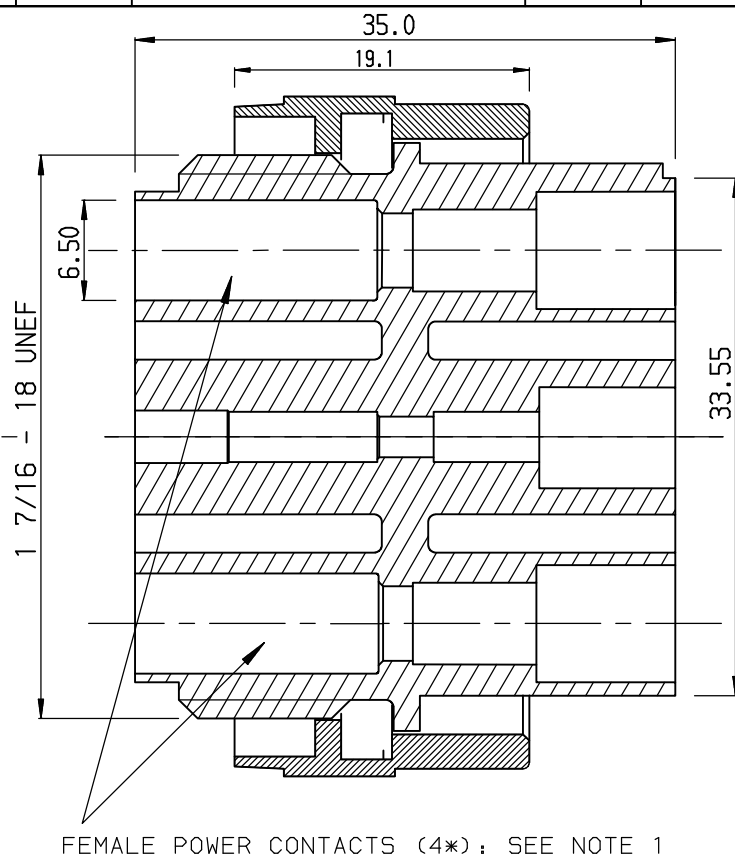


DIT IS ONZE EIGENDOM EN MAG NOCH NAGEMAakt, HERDRUKT, OVERGEMAakt AAN DERDEN, NOCH VOOR FABRIKATIE GEBRUIKT WORDEN, ZONDER ONZE SCHRIFTELIJKE TOELATING. BIJ NIET GEBRUIK IS DE TERUGZENDING VERPLICHT.

THIS IS OUR EXCLUSIVE PROPERTY. IT IS NOT TO BE COPIED, REPRINTED OR DISCLOSED TO A THIRD PARTY, NOR USED FOR MANUFACTURING WITHOUT OUR WRITTEN CONSENT, AND HAS TO BE RETURNED TO US IN CASE OF NO USAGE

REV.	DATE	DESCRIPTION	BY	C'K'D'
A	25/10/11	change bad front view	R Ch	

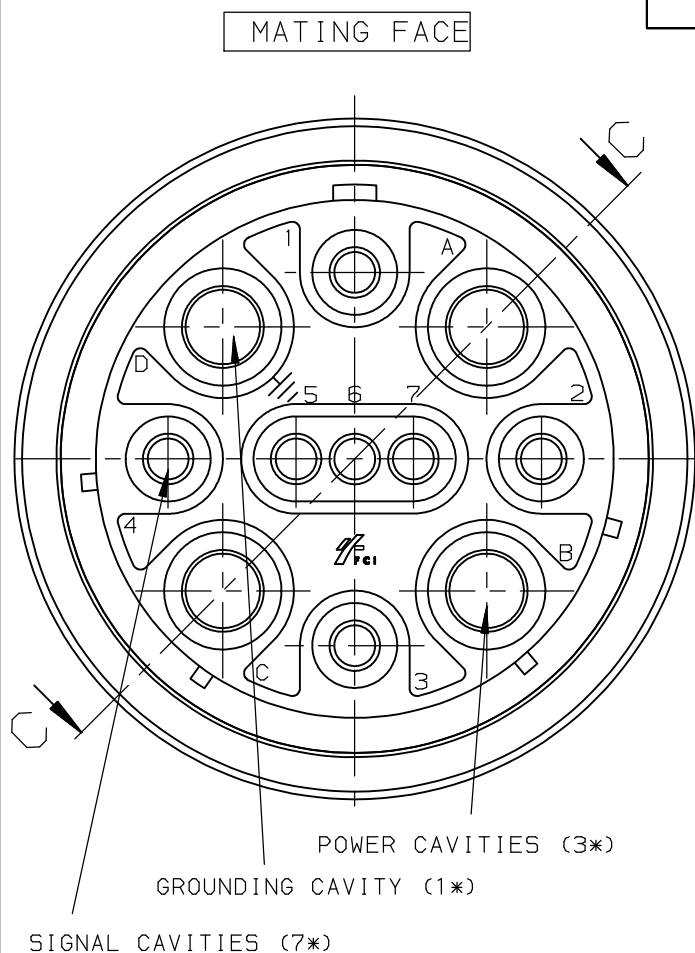

SECTION C-C

PERFORMANCE CHARACTERISTICS

- OPERATING TEMPERATURE : -55°C TO +125° C
- INSULATION RESISTANCE : 5000 MΩ MIN.
- TEST POTENTIAL : 2000 V EFF. (SIGNAL) - 4000 V EFF. (POWER)
- CONNECTOR AS PER VDE 0110 CLASSIII - POLLUTION DEGREE 3: 830V AC EFF. (POWER CONTACTS)

MATERIAL

- BODY : GLASS-FILLED POLYESTER UL94-V0.
COLOUR : BLACK.
- BAYONET COUPLING RING : HIGH STRENGTH CuZn ALLOY, NICKEL PLATED.
- COUPLING SPRING: SPRING STEEL

NOTES

1. CONTACTS TO BE ORDERED SEPARATELY
2. ACCEPTS Ø3.6MM MACHINED AND Ø1.6MM MACHINED OR STAMPED AND FORMED CONTACTS
3. CONNECTOR TO BE MATED WITH UTG02411P

GEN. ST.	01	02	03	04	05	06	07	08	0D	50	60	70	80	90																	
INT. ST.	10	11	12	13	14	18	20	31	32	33	34	38	39	40	42	43	44	45	46	48	56	70	72	73	75	76	81	82	83	84	88
1DEC ±0,2 1DEC 2DEC ±0,1 2DEC ANGLES ±1' HOEKEN		APPR.		DATE		SIGN.		FEMALE PLUG 4 POWER Ø3.6 CONTACTS																							
WE RESERVE THE RIGHT TO CHANGE DIMENSIONS OR REQUIREMENTS WITHOUT PRIOR NOTICE.		DRAFT		15-11-01		P BUYCKX		CAT.N°. UTG62411SN																							
		CHECKED						SOURIAU Route Nationale 23 72470 CHAMPAGNE																							
		PROD. MGR.																													
ALL DIMENSIONS IN MM		PR.ENG.MGR.						SCALE																							
		PR.MGT.MGR.																													
ALLE AFMETINGEN IN MM		REFERENCES														BS-A-203024-000 NOT EXPORT CONTROLLED															
DRAWING NR.														CUSTOMER DRAWING REVISION																	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Souriau:](#)

[UTG62411SN](#)