

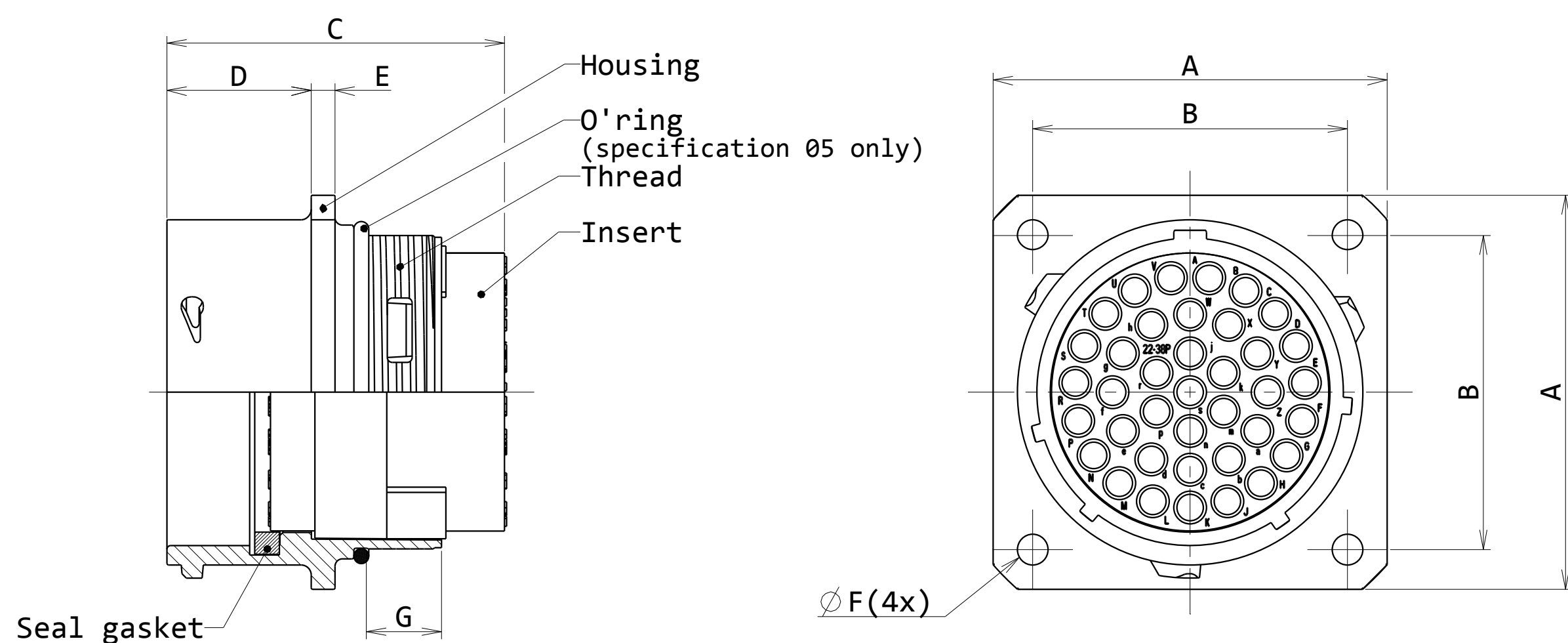


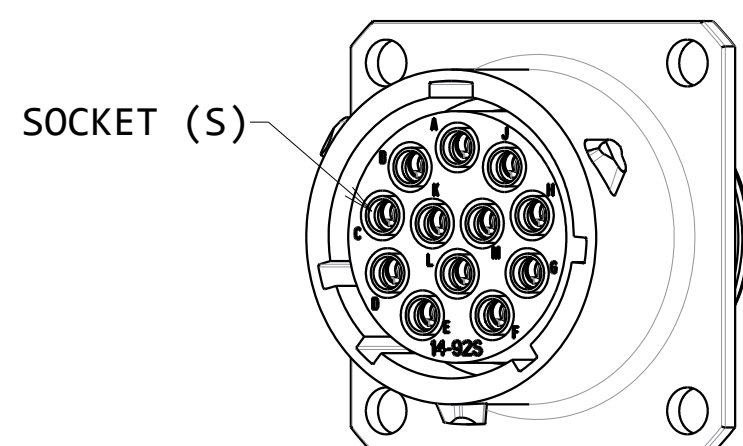

Part Number (Note 8)	Thread (for information)	A ±0.3	B ±0.2	C Max		D ±0.2	E ±0.35	F ±0.15	G ±0.2
				Male	Female				
UT00102W2--H-	9/16-24 UNEF Class 2A	23.85	18.26	33.20	31.50	11.35	1.60	3.10	7.50
UT00103W3--H-					25.50				
UT00103--H-									
UT00104--H-									
UT001044--H-									
UT00124--H-	11/16-24 UNEF Class 2A	26.20	20.62						
UT00128--H-									
UT00142G1--H-	13/16-20 UNEF Class 2A	28.60	23.01	36.00	32.50				
UT00147--H-				33.20	25.50				
UT00148--H-					31.50				
UT001412--H-					25.50				
UT001492--H-									
UT001619--H-	15/16-20 UNEF Class 2A	31.05	24.61						
UT001823--H-	1" 1/16-18 UNEF Class 2A	33.35	26.97						
UT002028--H-	1" 3/16-18 UNEF Class 2A	36.55	29.36	34.70	29.30				
UT002030--H-									
UT002235--H-	1" 5/16-18 UNEF Class 2A	39.80	31.75			15.35			
UT002238--H-									
UT002448--H-	1" 7/16-18 UNEF Class 2A	42.90	34.92						

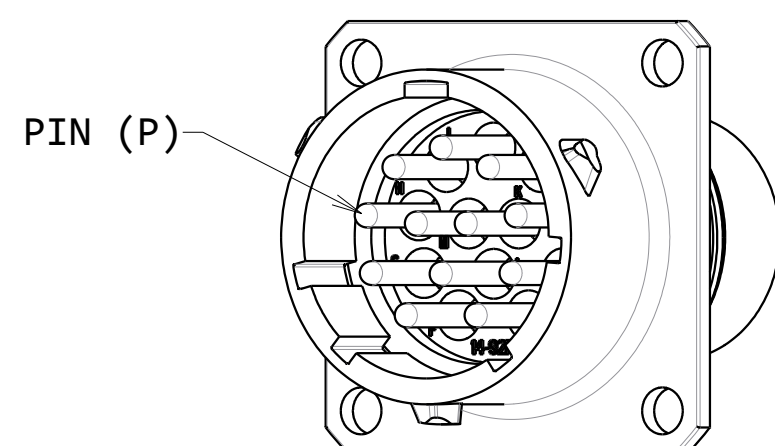

MATERIAL :

Housing : Zinc alloy nickel plated
Insert : PA 66 UL94 V0
Mating gasket : sealing IP67:Nitril
 sealing IP68:Silicone
O'ring : nitril

PERFORMANCE CHARACTERISTICS :

Operating temperature : -40°C up to 105°C
Insulation resistance : 5000 MΩ min
Withstanding voltage: 2000Vrms
(1500 Vrms for 102w2 and 103w3 layouts)

 
Corrosion salt spray : 96 hours
Durability : 500 matings and unmatings
Sealing IP67 / IP68 3 bar/30min as per IEC60529
Sealing IP69K as per DIN40050
ROHS compliant

NOTES :

NOTES :


- 1- Contact identification and orientation of connector, refer to:
UT0-CONTACT-L-C01 (Male)
UT0-CONTACT-L-C02 (Female)
- 3- Contact to be ordered separately refer to : UT0 catalog
- 4- Dimension $\varnothing P$ for front panel mounting (see to panel cut out)
- 5- Dimension $\varnothing R$ for rear panel mounting (see to panel cut out)
- 6- To achieved Sealing condition : Add UTFD-- Sealing Gasket
- 7- Insert arrangement refer to : UT0-DHP-001-C01 (Male)
UT0-DHP-002-C01 (Female)
- 8- This drawing covers p/n termination : -H / -H6 / -H05 / -H605
- 9- Packaging: connector is individually packed in a plastic bag

UT00	14	2G1	P	W	H6	05
Receptacle UT0 : <i>Type 0</i>						
Shell size :						
Insert arrangement : <i>See Note 7</i>						
Contact : <i>P : Male</i> <i>S : Female</i>						
Insert polarisation : <i>No letter : Standard version</i> <i>W, X, Y, Z : Differents orientation</i>						
Sealing version : <i>H : IP67 version</i> <i>H6 : IP68 version</i>						
Specification : <i>No letter : Standard version</i> <i>05 : O'ring rear on the receptacle</i>						

A	20/04/2015	_CREATION OF THE DRAWING		24021
		_Cancel & replace UT00-C01		
ISS	DATE	Latest modification - by:	COUTY L.	MOD N°
Designed by:		COUTY L.	Date : 20/04/2015	CUSTOMER DRAWING
TITLE		RECEPTACLE UT0 CONNECTOR		
Scale 2/1		General linear Tolerances: ± 0.1	NPRDS / PROJECT UT0	
SOURIAU		WWW.SOURIAU.COM		This document is the property of SOURIAU It must not be reproduced or communicated without permission
FORMAT A2	SOURIAU DRG N° C001-UT00-A			SHEET 1 / 2

A.8; Validé

In case the connectors are equipped with dipsolder contacts

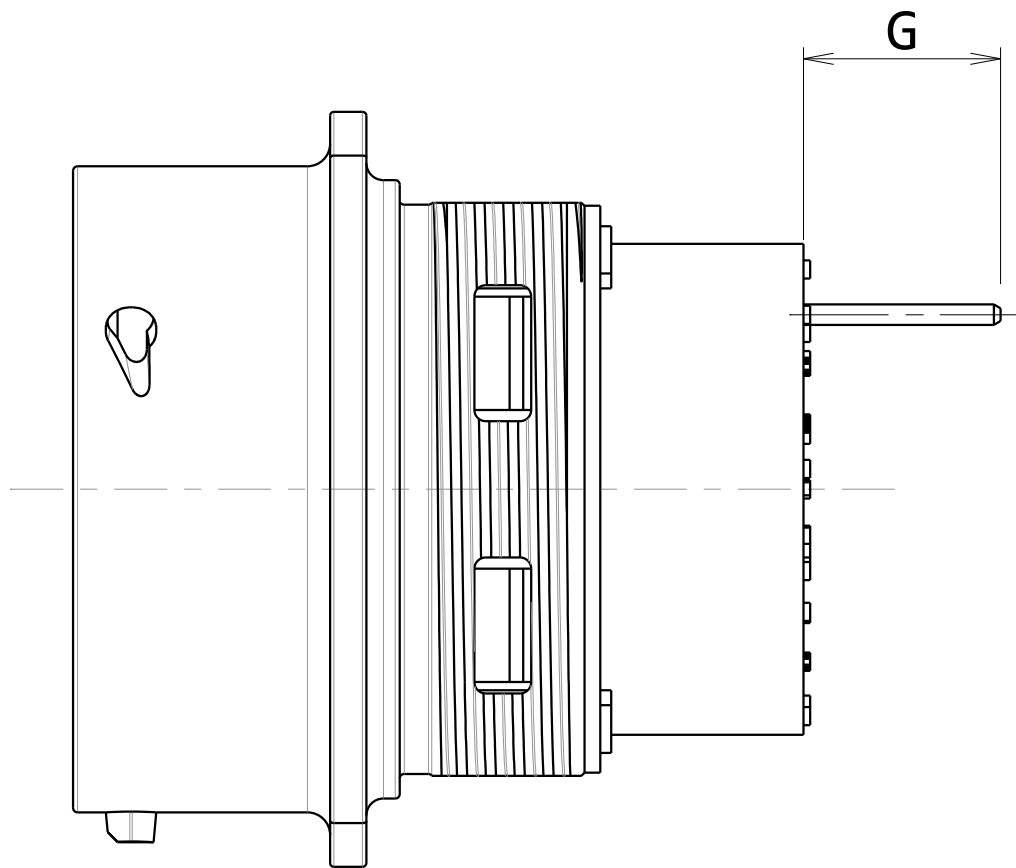


CONTACT RM20M12E83x (Male)
or RC20M12E83x (Female)

Contacts to be ordered separately

MALE CONTACTS		
Part Number	G	
	min	max
UT00104P-H-	8.1	10.3
UT001044P-H-		
UT00124P-H-		
UT00128P-H-		
UT001412P-H-		
UT001492P-H-		
UT001619P-H-		
UT001823P-H-		
UT002028P-H-		
UT002030P-H-		
UT002235P-H-		
UT002238P-H-		
UT002448P-H-		

 
FEMALE CONTACTS		
Part Number	G	
	min	max
UT00104S-H-	7.5	9.2
UT001044S-H-		
UT00128S-H-		
UT001412S-H-		
UT001492S-H-		
UT001619S-H-		
UT001823S-H-	5.3	7.1
UT002028S-H-		
UT002030S-H-		
UT002235S-H-		
UT002238S-H-		
UT002448S-H-		

Panel Cut Out

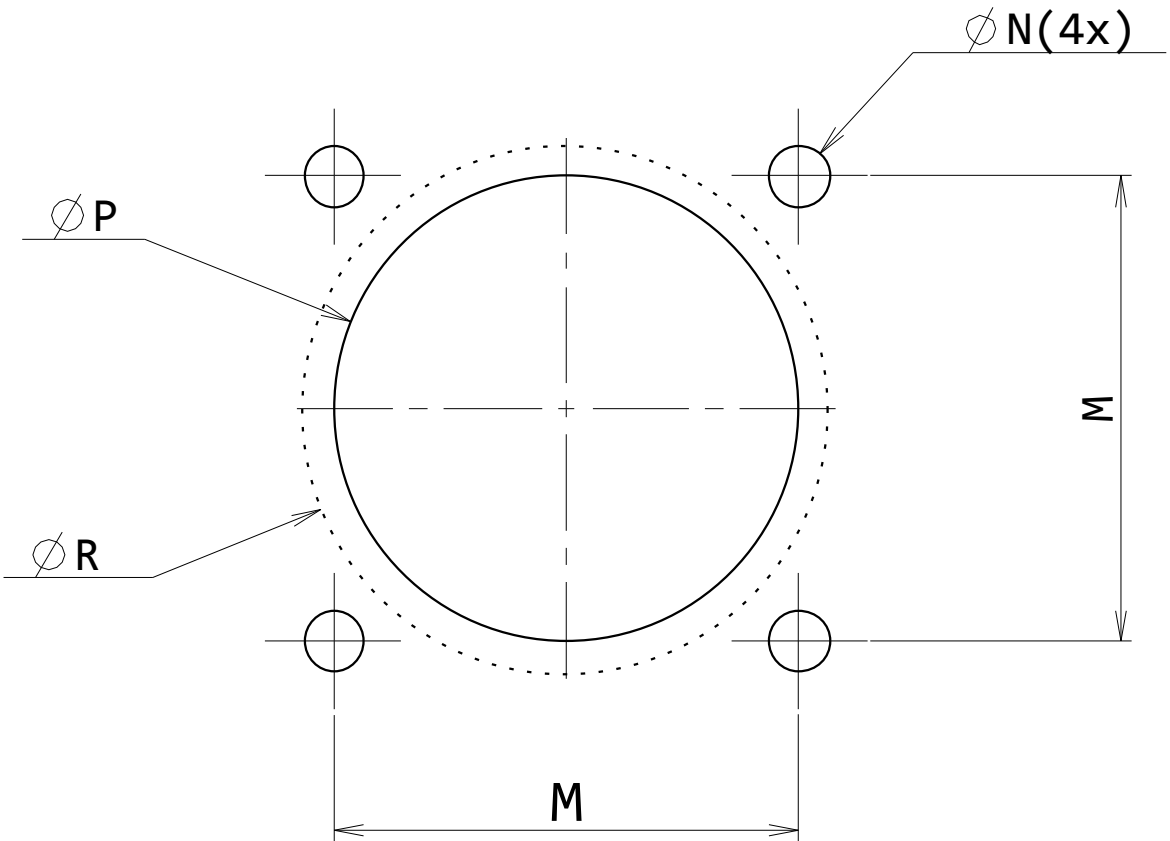

Part Number	M ±0.2	Ø N ±0.1	Ø P ±0.1	Ø R ±0.1
UT00102W2--H-	18.26	3.20	14.20	17.30
UT00103W3--H-				
UT00103--H-				
UT00104--H-				
UT001044--H-				
UT00124--H-	20.62	3.20	18.40	21.85
UT00128--H-				
UT00142G1--H-	23.01	3.20	21.50	25.00
UT00147--H-				
UT00148--H-				
UT001412--H-				
UT001492--H-	24.61	3.20	24.60	28.10
UT001619--H-				
UT001823--H-				
UT002028--H-	29.36	3.20	30.95	34.50
UT002030--H-				
UT002235--H-	31.75	3.20	34.10	37.70
UT002238--H-				
UT002448--H-	34.92	3.90	37.30	40.90

-Dimension Ø P for front panel mounting (see to panel cut out)
-Dimension Ø R for rear panel mounting (see to panel cut out)

A	04/11/2014	_ CREATION OF THE DRAWING		24021
		_ Cancel & replace UT00-C01		
ISS	DATE	Latest modification - by: COUTY L.		MOD N°
Designed by:		COUTY L.	Date : 04/11/2014	CUSTOMER DRAWING
TITLE		RECEPTACLE UT0 CONNECTOR		
Scale		General linear Tolerances: ± 0.1	NPRDS / PROJECT UT0	
3/1				
SOURIAU		WWW.SOURIAU.COM		This document is the property of SOURIAU It must not be reproduced or communicated without permission
FORMAT	SOURIAU DRG N° C001-UT00-A			
A2				SHEET 2 / 2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Souriau:

[UT002448PH](#) [UT001412SH](#) [UT001619PH6](#) [UT001412PH](#) [UT00142G1SH](#) [UT00147SH](#) [UT00104SH6](#)
[UT002448SWH](#) [UT002448PWH](#) [UT002028PYH](#) [UT002235PH](#) [UT00142G1PH](#) [UT002028PWH](#) [UT002028SH6](#)
[UT00147SH6](#) [UT002448PH6](#) [UT002448PWH6](#) [UT00128PH6](#) [UT00128PH](#) [UT002448SYH](#) [UT002235PH6](#)
[UT00147PH](#) [UT00128SH](#) [UT001823SH](#) [UT00104PH](#) [UT002448PYH6](#) [UT001823SH6](#) [UT002448SXH](#)
[UT002448PYH](#) [UT001412PH6](#) [UT002448PXH6](#) [UT001619SH](#) [UT00128SH6](#) [UT002028SH](#) [UT001823PH](#)
[UT002448PZH](#) [UT00147PH6](#) [UT001412SH6](#) [UT001619PH](#) [UT001823PH6](#) [UT00142G1PH6](#) [UT002028PH6](#)
[UT001619SWH](#) [UT002448SH6](#) [UT001619SH6](#) [UT002448PXH](#) [UT00104SH](#) [UT001619PXH](#) [UT001619SXH](#)
[UT002235SH6](#) [UT002448SH](#) [UT002235SH](#) [UT00142G1SH6](#) [UT002028PH](#) [UT00103SH](#) [UT002235SZH](#)
[UT00103W3PH6](#) [UT00102W2SH6](#) [UT00102W2PH](#) [UT001823SZH](#) [UT002235PZH](#) [UT002235PWH](#) [UT00124SH6](#)
[UT00103PH](#) [UT002030SH](#) [UT002238PH](#) [UT002448SZH](#) [UT00148PH6](#) [UT001619PWH](#) [UT001823PZH](#)
[UT002028SYH](#) [UT001619PZH](#) [UT001412SWH](#) [UT002235PXH](#) [UT001492SH](#) [UT00104PWH](#) [UT00104SWH](#)
[UT00148PH](#) [UT00148SH6](#) [UT001619SZH](#) [UT00103W3SH](#) [UT001412PWH](#) [UT002235SXH](#) [UT002235SYH](#)
[UT00103W3SH6](#) [UT00124SH](#) [UT00124PH6](#) [UT001823PXH](#) [UT001823SXH](#) [UT002235PYH](#) [UT00102W2SH](#)
[UT00103W3PH](#) [UT00124PH](#) [UT00148SH](#) [UT002028SWH](#) [UT00128PWH](#) [UT002235SWH](#) [UT00103PH6](#)
[UT00103SH6](#) [UT00102W2PH6](#)