
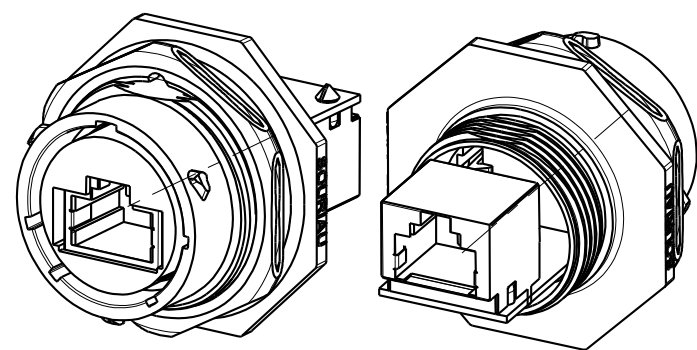


**POLARIZATION  
ALTERNATIVE KEY WAY POSITIONS**

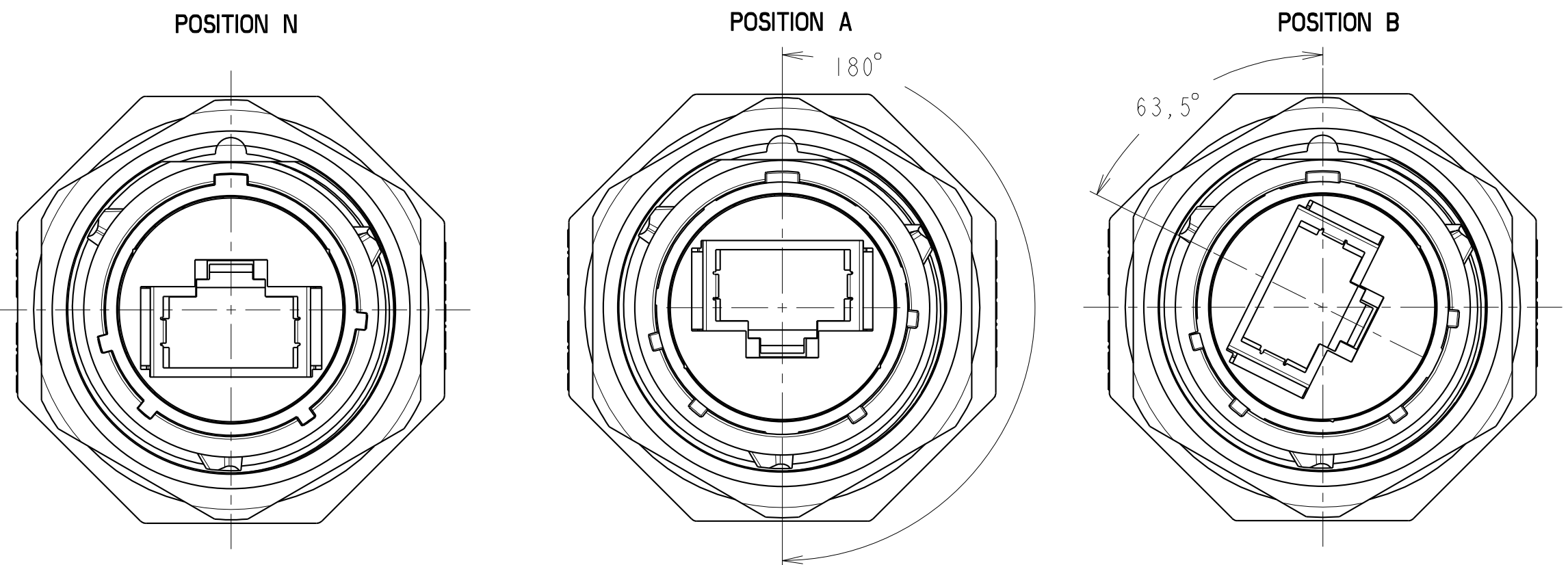

**MATERIAL:**

Shell: PA 66 UL94 V0  
Insert:PA 66 UL94 V0  
Seal gasket:Silicone

**PERFORMANCE CHARACTERISTICS :**

Operating temperature:-40°C up to 85°C  
Corrosion salt spray: 500 hours salt spray  
Durability:250 matings and unmatings  
Sealing : IP67  
RJ45 component : Cat 5 E

**NOTES**

UTS7 18 RJ F \*

Receptacle UTS

Shell size

Insert arrangement

Feedthru

Insert polarisation:  
N ::standard version  
A,B:Differents orientations

q	06/05/08	First issue		--
ISS	DATE	Latest modification - by:		MOD N°
		M. RAGINE Date:05/05/08		
Designed by:		CUSTOMER DRAWING		
TITLE		CONNECTOR UTS RJ 45 CAT5 EQUIPMENT		
Scale	1/1	General linear Tolerances: ±0.2	NPRDS / PROJECT UTS1	
FORMAT		SOURIAU DRG N° UTS718RJF-X-C		SHEET
A2				NOT EXPORT CONTROLLED

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Souriau:

UTS718RJFN