


F ; 2+ ; Valide

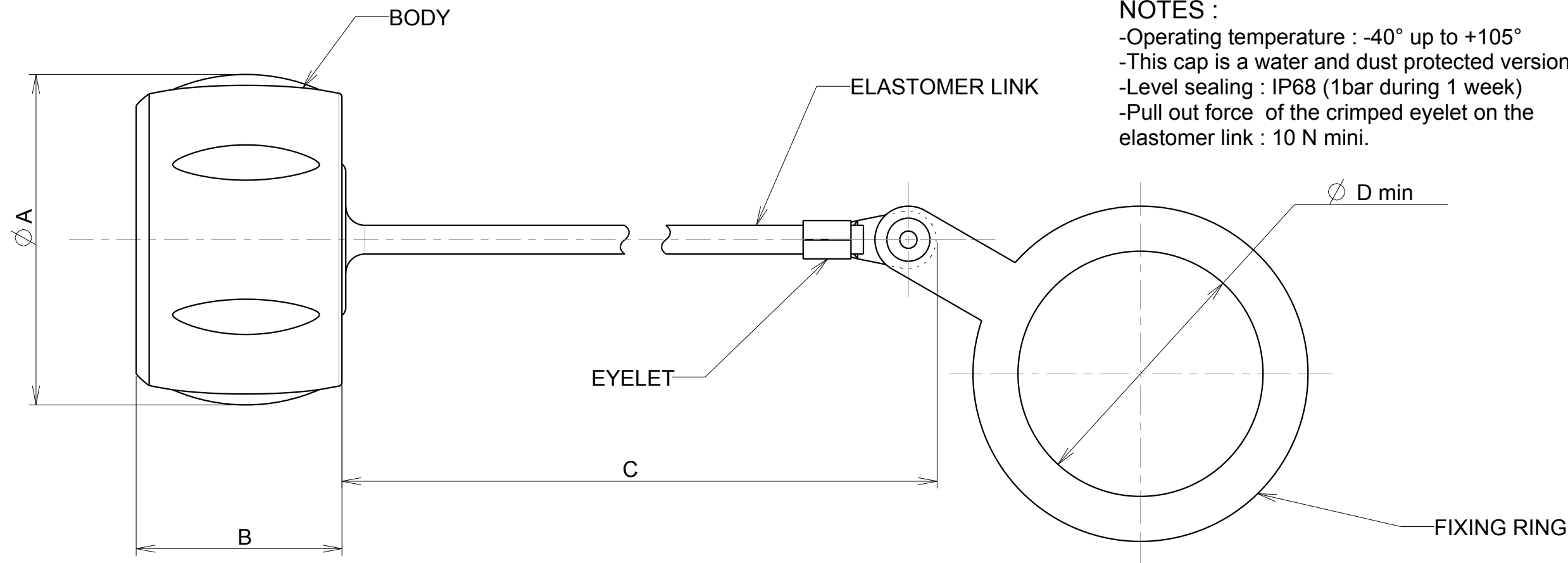


 
MATERIAL:
Body : Polyamid UL94 V-0
Elastomer link: Elastomer
Eyelet : brass tin plated
Fixing ring : stainless steel
NOTES :
-Operating temperature : -40° up to +105°
-This cap is a water and dust protected version.
-Level sealing : IP68 (1bar during 1 week)
-Pull out force of the crimped eyelet on the elastomer link : 10 N mini.

PART NUMBER	Ø A	B	C ⁺⁰ ₋₆	Ø D mini
UTS8DCGR	22.50	16.50	89	14.5
UTS10DCGR	26.20	18.40	108	17.6
UTS12DCGR	29.70	19.60	108	22.4
UTS14DCGR	34.60	21.50	105	25.6
UTS18DCGR	42	23	105	31.9

Country	Jurisdiction & Control List
FR	NOT LISTED

P/N : UTSXXDCGR

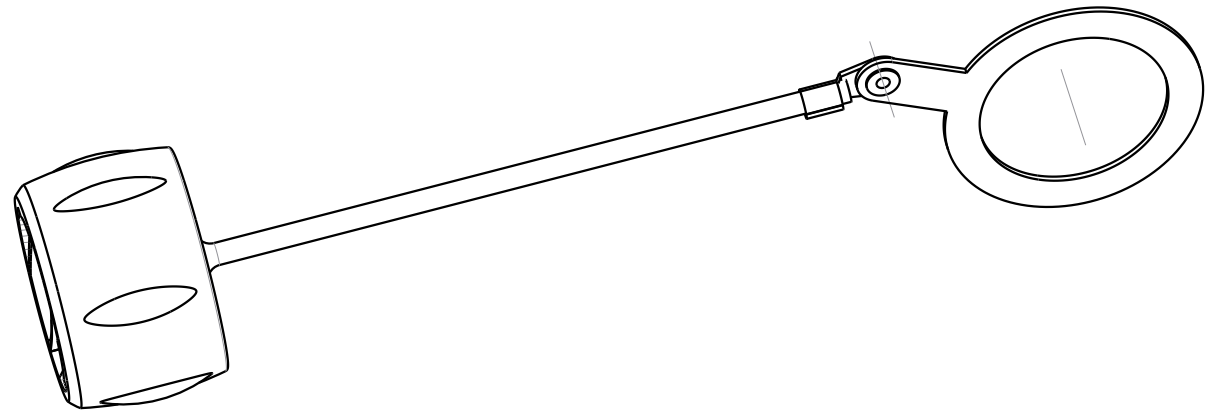

F	19/03/2018	Change dimension C		--
ISS	DATE	Latest modification - by: ROUILLARD Ch		MOD N°
Designed by:		ROUILLARD	Date: 26/01/09	CUSTOMER DRAWING
TITLE		UTS RECEPTACLE SEALING CAP WITH FIXING RING FOR JUM NUT RECEPTACLE		
Scale 2/1		General linear Tolerances: ± 0.4	NPRDS / PROJECT UTS1	
SOURIAU		WWW.SOURIAU.COM		This document is the property of SOURIAU It must not be reproduced or communicated without permission
FORMAT A3	SOURIAU DRG N° C076-UTS1-A			SHEET 1 / 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Souriau:

[UTS12DCGR](#) [UTS14DCGR](#) [UTS18DCGR](#)