


NOTES:

1. MATERIAL - .005 ±.002 THK. ALLOY 25 (CA172) 1/2 HARD BERYLLIUM COPPER.
2. FINISH-STRIP STOCK TO BE A MINIMUM OF 30 MICROINCHES OF GOLD IN ACCORDANCE WITH MIL-G45204 TYPE 1 OR 2, GRADE C OVER 50 MICROINCHES MINIMUM OF NICKEL PER QQ-N-290, OVER A FLASH OF COPPER IN ACCORDANCE WITH MIL-C-14550.
3. .200 PITCH TO REMAIN CONSTANT. NO. OF PITCHES VARIES WITH LENGTH DIMENSION "A".
4. ALL LETTER DIMENSIONS TO BE SYMMETRICAL TO DATUMS A & B WITHIN .006 T.I.R.

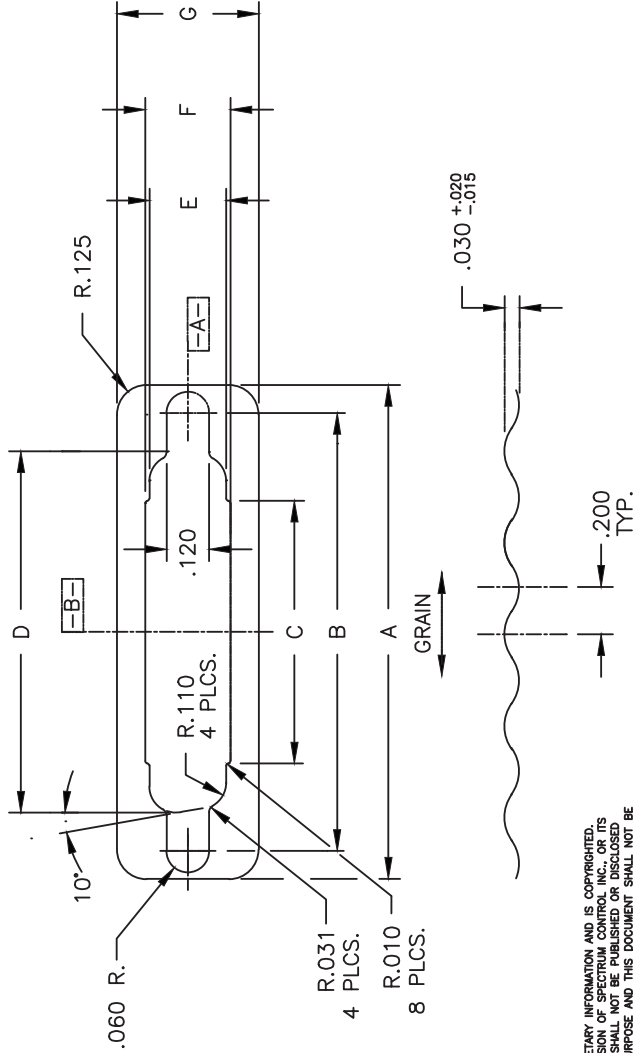


THIS DOCUMENT CONTAINS PROPRIETARY INFORMATION AND IS COPYRIGHTED. EXCEPT WITH THE WRITTEN PERMISSION OF SPECTRUM CONTROL INC., OR ITS SUBSIDIARIES, SUCH INFORMATION SHALL NOT BE PUBLISHED OR DISCLOSED TO OTHERS OR USED FOR ANY PURPOSE AND THIS DOCUMENT SHALL NOT BE DUPLICATED IN WHOLE OR IN PART.

UNLESS OTHERWISE SPECIFIED DIMENSIONS ARE IN INCHES.										TOLERANCES UNLESS OTHERWISE SPECIFIED		FAIRVIEW PENNSYLVANIA	
DO NOT SCALE.										Fractions ± 1/64	Dec. .xxx ±	SPECTRUM CONTROL INC.	
CHANGE NOTICE										DLSP2	DLSP2	Dwn. G. SLAGLE	Description
SEE SHEET 1										Dec. .xxx ± .003	Angles ± 0° 30'	Date 6-15-11	WAVY GASKET-GOLD
										CODE IDENT. NO.		Appl. HANAS	572019-0010X-AU
										Sheet 2 of 2			

Quality Products From The Specialists In Electro-Magnetic Compatibility

1. MATERIAL - .005 ±.002 THK. ALLOY 25 (CA172) 1/2 HARD BERYLLIUM COPPER.

2. FINISH-STRIP STOCK TO BE A MINIMUM OF 30 MICROINCHES OF GOLD IN ACCORDANCE WITH MIL-G45204 TYPE 1 OR 2, GRADE C OVER 50 MICROINCHES MINIMUM OF NICKEL PER QQ-N-290, OVER A FLASH OF COPPER IN ACCORDANCE WITH MIL-C-14550.
3. .200 PITCH TO REMAIN CONSTANT. NO. OF PITCHES VARIES WITH LENGTH DIMENSION "A".
4. ALL LETTER DIMENSIONS TO BE SYMMETRICAL TO DATUMS A & B WITHIN .006 T.I.R.

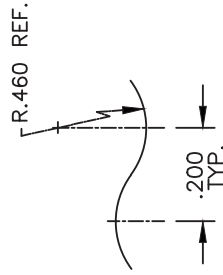

TYP. FOR EACH PITCH

THIS DOCUMENT CONTAINS PROPRIETARY INFORMATION AND IS COPYRIGHTED. EXCEPT WITH THE WRITTEN PERMISSION OF SPECTRUM CONTROL INC., OR ITS SUBSIDIARIES, SUCH INFORMATION SHALL NOT BE PUBLISHED OR DISCLOSED TO OTHERS OR USED FOR ANY PURPOSE AND THIS DOCUMENT SHALL NOT BE DUPLICATED IN WHOLE OR IN PART.

[illegible]

Quality Products From The Specialists In Electro-Magnetic Compatibility

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Spectrum Control:](#)

[572019-00107-AU](#)