 


LEAD FINISH: GOLD	
CASING FINISH: GOLD	
CAPACITANCE	15nF +100%-0%
TEMP. RANGE	-55°C TO 125°C
CURRENT	5 AMP MAX.
WORKING VOLTAGE	125°C 50VDC MAX.
D.C. RESISTANCE	.01ohms MAX.

#### SCHEMATIC




#### MARKING:

NONE

#### PACKING:

BAG: SCIF-9925-153  
DATE CODE  
LOT NO.  
QTY./BAG (200 MAX.)

00	REV. NO.	TOLERANCES UNLESS OTHERWISE SPECIFIED
CN 55649-ENG	CHANGE NOTICE	Fractions $\pm$ 1/64
		Dec. .xx $\pm$
		Dec. .xxx $\pm$ .005
		Angles $\pm$ 0° 30'
		CODE IDENT. NO. DLSP2

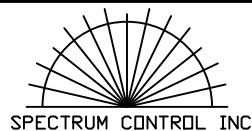

SPECTRUM CONTROL INC.

FAIRVIEW  
PENNSYLVANIA

Dwn. KAUFFMAN

Date 9-28-10

Engr. B. DEVINE

Scale NONE

Description

FEEDTHRU FILTER

SCIF-9925-153

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[API Technologies:](#)

[SCIF-9925-153](#)