

37 Series 700


Socket Contact & Pin/Socket Adapter

Shell Size




Solderless Wire Wrap

Spectrum Part Number <i>Select one</i>				EMI Filter	
	L .500	L .375	L .250	Filter Desig.**	Cap. Value
* 56-733	-006	-016	* -011	A	310 pF Pi
56-733	-007	-017	-012	B	1000 pF C
56-733	-008	-018	-013	C	1000 pF Pi
56-733	-009	-019	-014	D	5000 pF C
56-733	-010	-020	-015	E	4000 pF Pi
56-733	-030	-027	-024	F	830 pF C
56-733	-031	-028	-025	J	100 pF Pi
56-733	-032	-029	-026	K	2500 pF Pi
56-733	-038	-037	-036	N	375 pF C

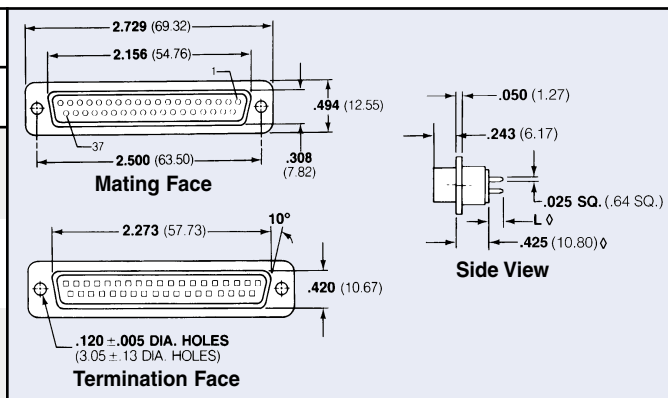


Solder Cup Termination

Spectrum Part Number	EMI Filter	
	Filter Designation**	Cap. Value
* 56-736-001	A	310 pF Pi
56-736-002	B	1000 pF C
* 56-736-003	C	1000 pF Pi
56-736-004	D	5000 pF C
* 56-736-005	E	4000 pF Pi
56-736-006	F	830 pF C
56-736-007	J	100 pF Pi
* 56-736-008	K	2500 pF Pi
56-736-009	N	375 pF C
56-736-015	L	500 pF C

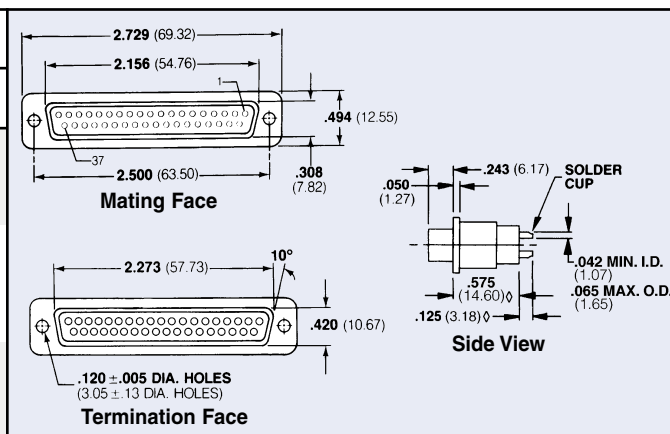

Pin/Socket Adapter

Spectrum Part Number	EMI Filter	
	Filter Designation**	Cap. Value
* 56-735-001	A	310 pF Pi
56-735-002	B	1000 pF C
* 56-735-003 €	C	1000 pF Pi
56-735-004	D	5000 pF C
* 56-735-005 €	E	4000 pF Pi
* 56-735-008	F	830 pF C
56-735-009	J	100 pF Pi
56-735-010	K	2500 pF Pi
56-735-025	N	375 pF C
56-735-034	L	500 pF C

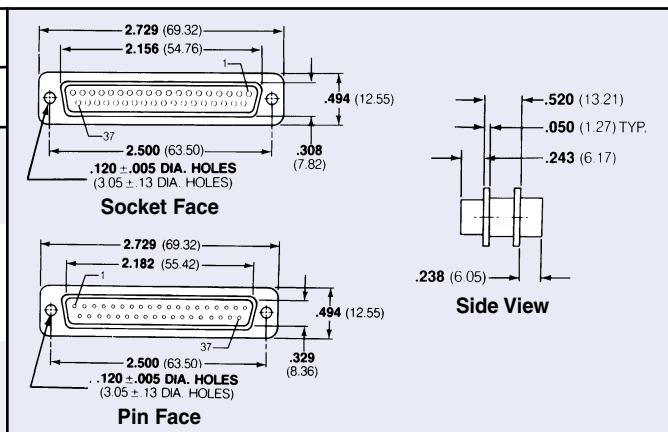

€ Also available through Spectrum Control's authorized European distributors/agents.

* May be available from distributor stock.

** See page 146 for filter performance.

Standard Tolerance = ±.005 except where noted, Ø = ±.015

Dimensions in inches (mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[API Technologies:](#)

[56-735-003](#) [56-735-001](#) [56-735-008](#) [56-735-010](#)