


# AVERY DENNISON MARKETING SPECIFICATION

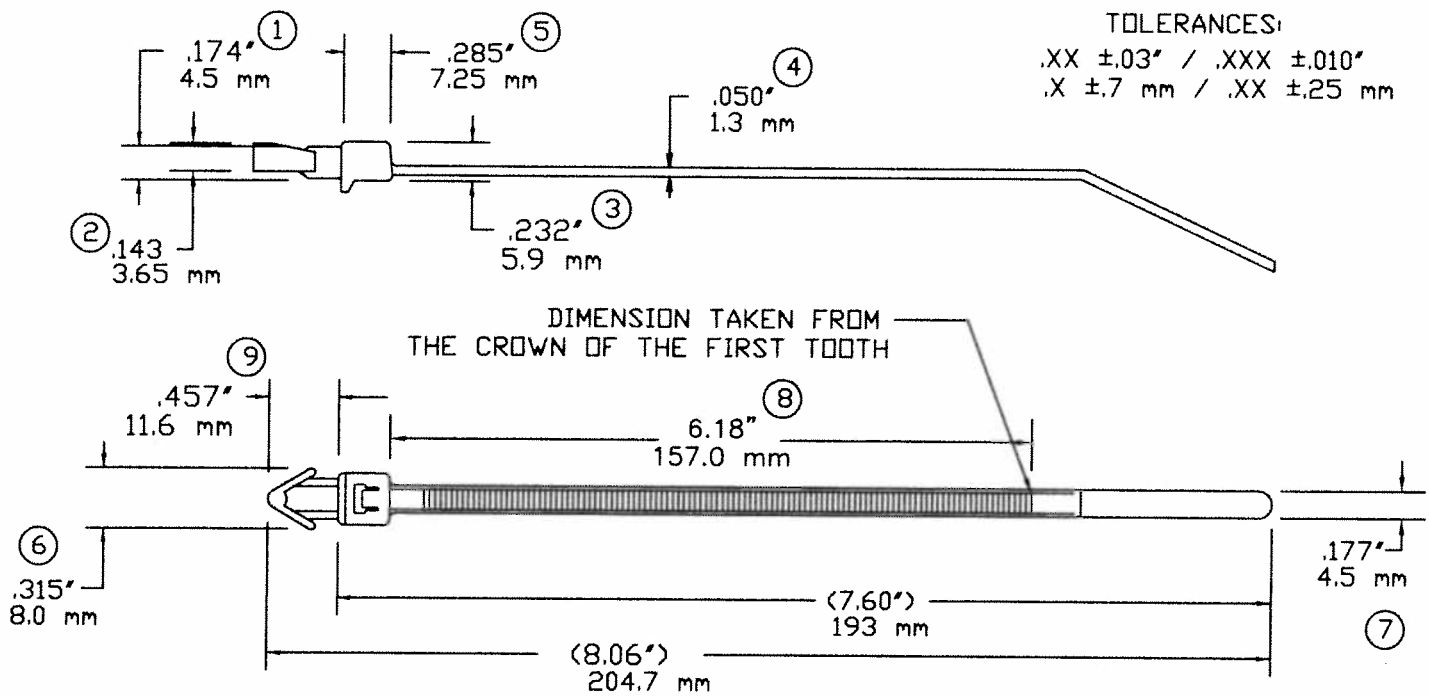

**NOT TO SCALE**

|                            |                                                                    |
|----------------------------|--------------------------------------------------------------------|
| LOOPED TENSILE STRENGTH:   | 50 LBF. / 220N MIN. PER AS-23190                                   |
| MATERIAL:                  | NYLON 6/6 - NATURAL                                                |
| OPERATING TEMPERATURE:     | -40°F (-40°C) TO 185°F (85°C)                                      |
| MINIMUM INSTALLATION TEMP: | 32°F (0°C)                                                         |
| WEIGHT:                    | .04540 oz. / 1.31 grams                                            |
| BUNDLE DIAMETER:           | 1.59mm - 44mm                                                      |
| MOUNTING:                  | 1/4" DIA.HOLE IN 1/8" MAX.THICK PANEL                              |
| TOOLS:                     | 12001 - HAND INSTALLATION TOOL<br>12500 - PNEUM. INSTALLATION TOOL |
| TOOL TENSION SETTING:      | 6-8                                                                |
| PACKAGED IN:               | 1000/BAG, 5000/CASE                                                |



**AVERY  
DENNISON**

FASTENER DIVISION  
 FITCHBURG, MA 01420 U.S.A.  
 TEL 1-800-225-5913  
 MA 978-353-8157

NOTE: THESE CABLE TIES ARE  
 PLENUM RATED AND HAVE A  
 FLAMMABILITY RATING OF V-2



LISTED  
 POSITIONING DEVICE  
 E57800  
 TYPE 21

DESCRIPTION:

**7.5" CABLE TIE, STANDARD,  
 PUSH MOUNT**

APPROVAL:

Q.A.:

*Linda Boyle 10/20/17*

STOCK NO.

**08414-0**

REV  
**L**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Avery Dennison:](#)

[08414-0](#)