


# AVERY DENNISON PRODUCT SPECIFICATION

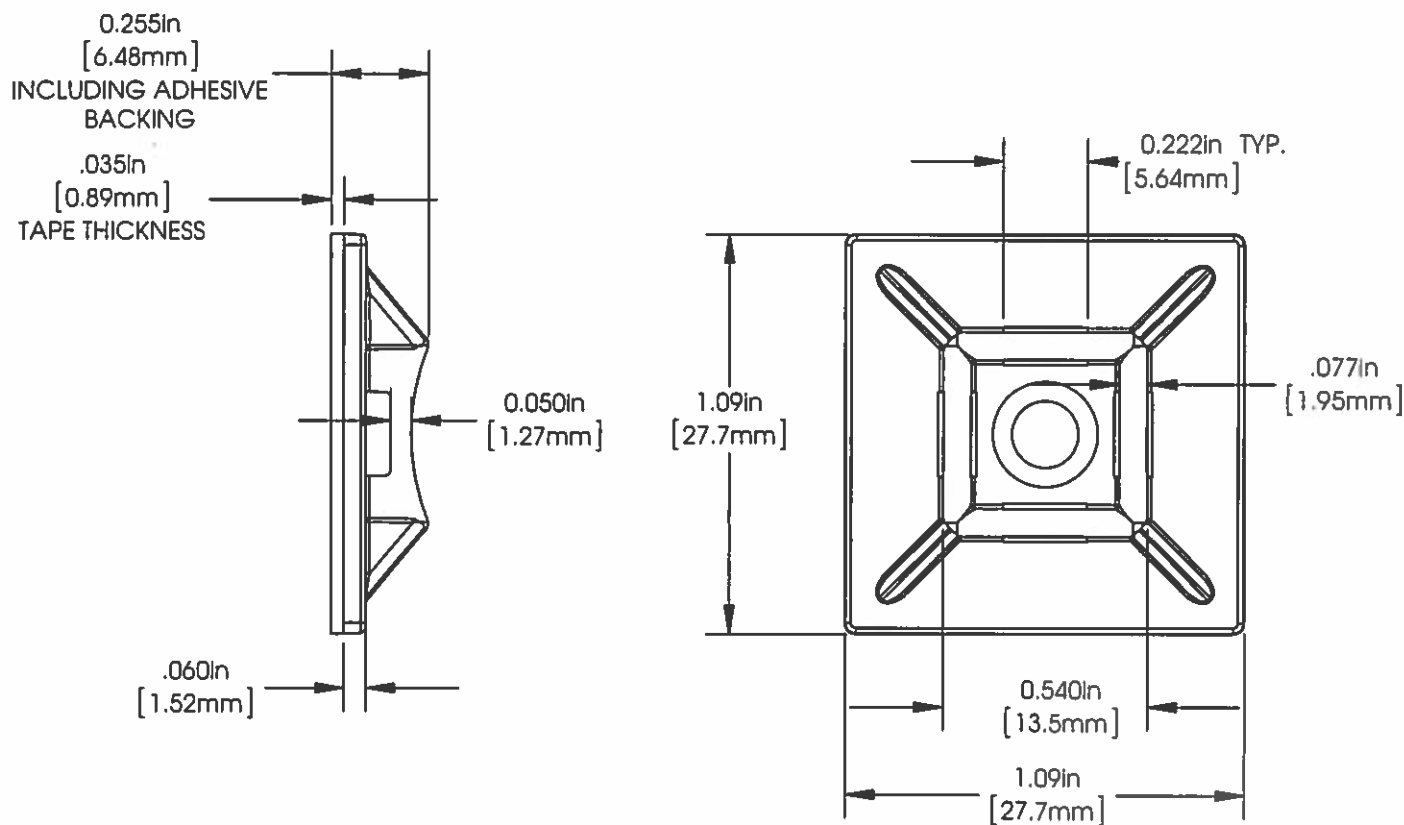

NOT TO SCALE

UNLESS OTHERWISE SPECIFIED:  
TOLERANCES:  $\pm 10\%$

|                            |                               |
|----------------------------|-------------------------------|
| MATERIAL:                  | NYLON 6 NATURAL               |
| WEIGHT:                    | .054 oz. / 1.54 g             |
| MOUNTING:                  | ADHESIVE MOUNTING             |
| PACKAGING:                 | 100 PER BAG / 10 BAGS PER BOX |
| OPERATING TEMP RANGE:      | -20°C (-4°F) TO 70°C (158°F)  |
| LOOP TENSILE STRENGTH:     | 50lbf 220N MINIMUM            |
| MINIMUM INSTALLATION TEMP: | 32°C (0°F)                    |

### NOTES:

1. THESE MOUNTS HAVE A FLAMMABILITY RATING OF V-2
2. UL APPLICATIONS REQUIRE USE WITHIN ENCLOSURES.



10030-0

1" CABLE TIE MOUNT, RUBBER ADHESIVE

APPROVER

*UBoyle 4/22/15*

REV  
J



**Avery Dennison**

Fastener Division

USA

Phone - 1-800-225-5913 Fax - 1-800-848-2169

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Avery Dennison:](#)

[10030](#) [10030-0](#)