

APPROVED: _____
DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	12/15/21	
A		ADDED SPEC.	8/11/22	LH/TW

SPECIFICATIONS:

Material:

SMA	SMA-M	Gold
Noumenon	ABS	Black

Electrical:


Standards	868MHz&915MHz&2.4G WiFi&BT		
Frequency range(MHz)	868	915	2400~2500
Peak Gain	2.5	3.4	2.0~2.7
Average Gain(dB)	-1.5	-1.4	-2.7~-2.3
VSWR	1.7	1.7	<2.0
Return Loss	-11.4	-11.1	<-10.0
Efficiency (%)	70.6	72.3	54.0~60.0
Polarization mode	Linear		
Radiation pattern	Omni-Directional		
Output impedance	50		
Max.Input Power(W)	25		

Mechanical:

Mounting Type	Connector Mount
Connector Type	SMA-Male Standard (Raight-Angle)
Antenna size(mm)	48.6Xø8mm
Material	ABS
Operating Temperature	-40°C~+85°C
Storage Temperature	-40°C~+85°C

Environmental:

Lead free, RoHS compliant.

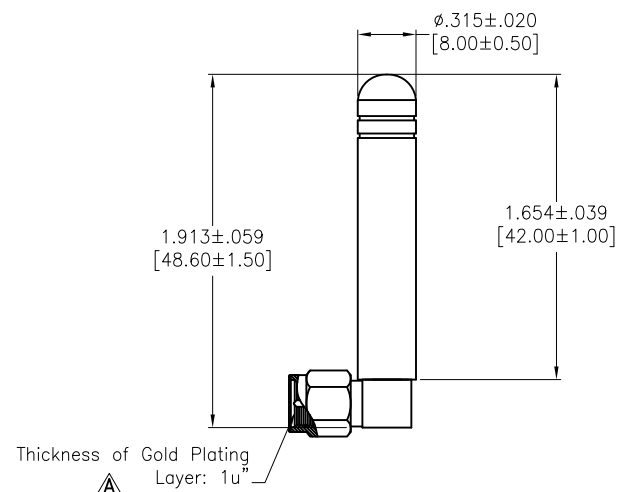

UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM]. TOLERANCES: EXCEPT AS NOTED

INCHES	HOLES
.X ±.10	ØX ±.10
.XX ±.020	ØXX ±.015
.XXX ±.015	ØXXX ±.010

DRAWN	WX	12/15/21
CHECKED	RC	12/15/21
APPROVED		

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY AND SHOULD NOT BE USED WITHOUT PRIOR WRITTEN PERMISSION FROM ADAM TECH

ADAM
TECH

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE
868MHz 915MHz 2.4G WIFI EXTERNAL ANTENNA
R/A, WITH SMA MALE

SIZE X	PART NO. ANT-20090EB56	REV. A
REF: S00207C	SCALE: NTS	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[ANT-20090EB56](#)