

6

5

4

3

2

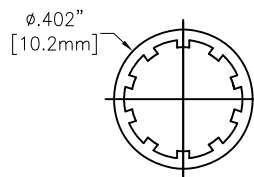
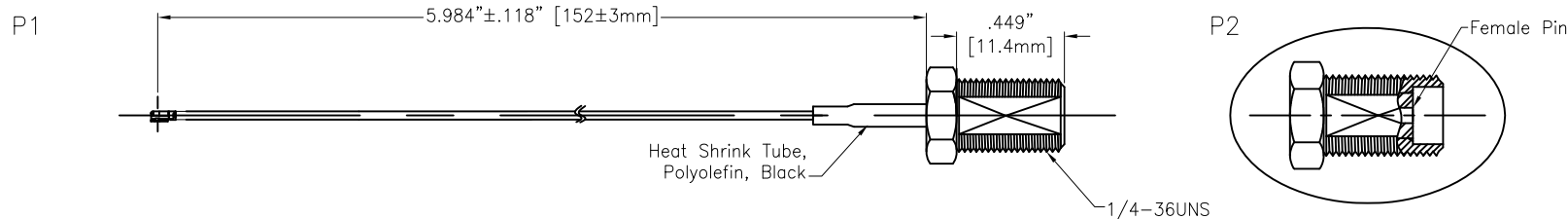
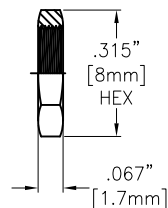
1

APPROVED: _____

DATE: _____ TITLE: _____

CUSTOM CABLE ASSEMBLIES ARE NON-CANCELLABLE / NON-RETURNABLE

Rev	AWO #	Description	Date	Appr
-		RELEASED	11/16/18	

Washer:
Brass, GoldNut:
Brass, Gold**SPECIFICATIONS:****Connector:**

P1= I-PEX (IV) Connector, Gold plated

P2= SMA Jack, Straight, Female pin, Gold plated

Cable:

Ø1.13mm Coaxial Cable, Color: Black

Electrical:

Impedance: 50 ohms

Frequency range: DC-6 GHz

Electrical Test:All Assemblies must be 100% Tested for
Shorts, Open, Continuity, and Physical Appearance.**Environmental:**

Operating Temperature: -45°C to +85°C

Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE INCHES [MM]
TOLERANCES: EXCEPT AS NOTED
INCHES HOLES
.X ± .10 Ø.X ± .10
.XX ± .020 Ø.XX ± .015
.XXX ± .015 Ø.XXX ± .010

APPROVALS		DATE
DRAWN	AY	11/16/18
CHECKED	AC	11/16/18
APPROVED		

ADAM
TECH
INTERCONNECTS

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE
CUSTOM CABLE ASSEMBLY, IPEX IV PLUG
TO SMA S/T JACK WITH OD 1.13MM CABLE

SIZE	PART NO.	REV.
X	CA#DKCA1-152L0-AJ15	-
REF: S00291T	SCALE: NTS	SHEET 1 OF 1

6

5

4

3

2

1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[CA-DKCA1-152L0-AJI5](#)