


APPROVED: _____
 DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	12/22/18	

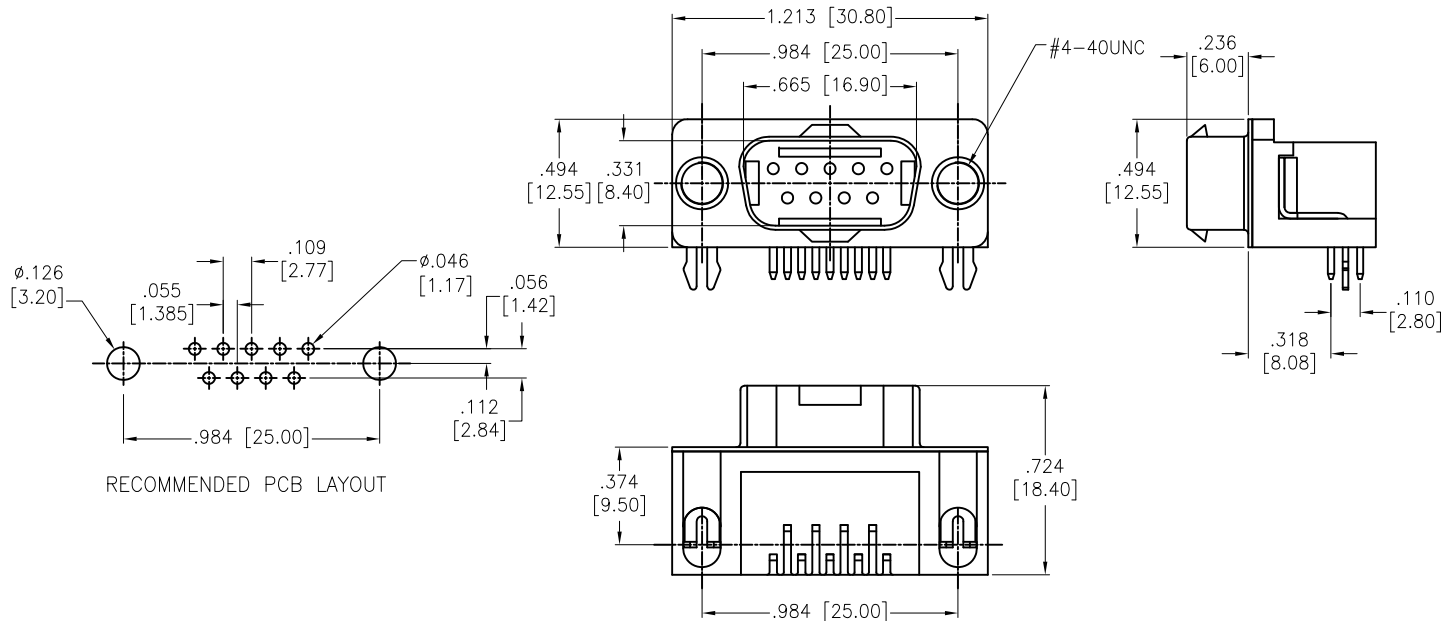

SPECIFICATIONS:

Material:
 Insulator: PBT, rated UL 94V-0
 Insulator color: Black
 Contacts: Brass
 Shell: SPCC, Nickel plated
 Ground: Brass, Nickel plated
 Rivet: Brass, Nickel plated
 Plating:
 Gold flash over Nickel underplate on contact area,
 Tin over Nickel underplate on PCB tails
 Electrical:
 Voltage rating: 500 V
 Current rating: 3 A
 Temperature Rating:
 Operating temperature: -55°C to +105°C
 Environmental:
 Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED INCHES HOLES .X ± .10 Ø.X ± .10 .XX ± .020 Ø.XX ± .015 .XXX ± .015 Ø.XXX ± .010			ADAM TECH INTERCONNECTS		909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710
APPROVALS DRAWN AY CHECKED TW APPROVED			DATE 12/22/18 12/22/18		
TITLE .318 [8.08] FOOTPRINT D-SUB MALE, 9PIN, #4-40, THREADED INSERT, FORKED BOARDLOCKS, W/BUMP			SIZE X	PART NO. DE09-PL-24-BP	REV. -
REF: S00200T			SCALE: NTS	SHEET 1 OF 1	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[DE09-PL-24-BP](#)