
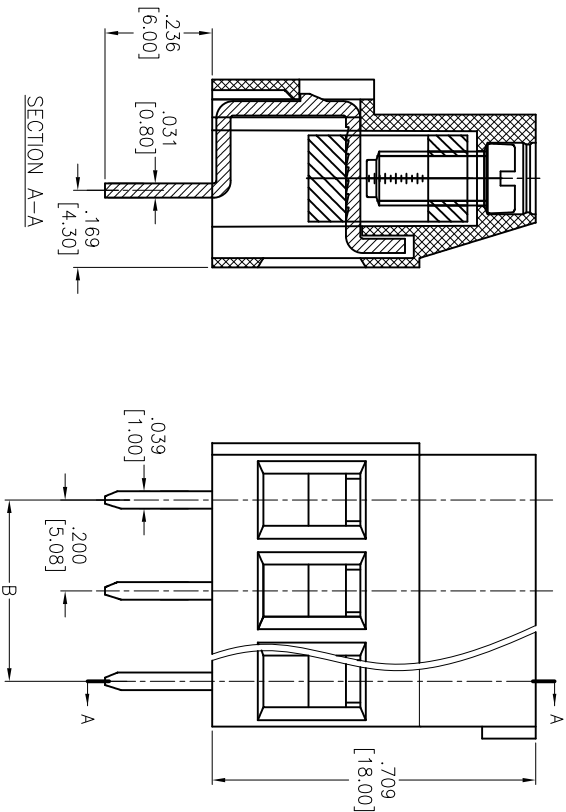
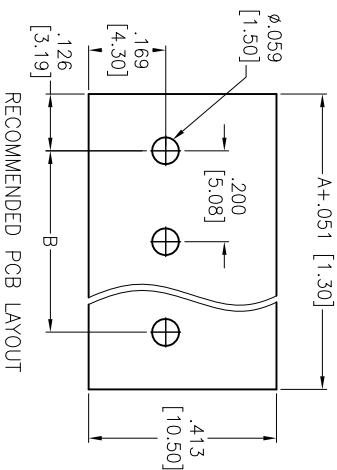


Rev	AWO #	Description	Date	Appr
-		RELEASED	9/10/13	

APPROVED: _____

DATE: _____ TITLE: _____

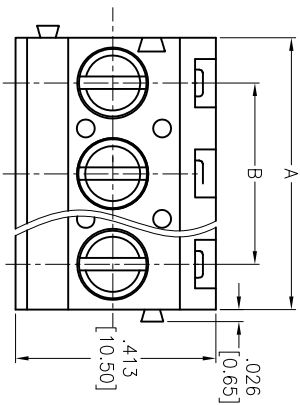

SPECIFICATIONS:

Material:

Insulator: PA66, rated UL 94V-0

Insulator color: Green

Screw: Steel, M3.0/Zinc plated

Cage: Brass, Nickel plated

Pin Header: Brass, Tin plated

Electrical:

Voltage rated: 300 VAC

Current rated: 16 Amps

Contact resistance: 20 mΩ

Insulation resistance: 500 MΩ @ 500 VDC

Withstanding voltage: 2000V AC/1 Min

Mechanical:

Solid wire: 26-12AWG 2.5mm²

Torque (Lb-in): 0.5Nm (4.5lb-in)

Strip length: 6-7mm

Temperature Rating:

Operating temperature: -40°C to +105°C

Environmental:

Lead free, RoHS compliant.



Positions: 02 thru 24
A = .200 [5.08] x No. of Positions
B = .200 [5.08] x No. of Spaces

ADAM TECH

909 Rahway Avenue, Union, NJ 07083

Phone: 908-687-5000 Fax: 908-687-5710

EURO BLOCK, .200 [5.08] PITCH

UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED				INCHES			
.X				± .10			
.XX				± .020			
.XXX				± .015			
Ø.X				± .10			
Ø.XX				± .015			
Ø.XXX				± .010			
APPROVALS				DATE			
DRAWN				AY			
CHECKED				SY			
APPROVED							
TITLE				EURO BLOCK, .200 [5.08] PITCH			
SIZE				PART NO.			
X				EB147A-XX-D			
REF: S00067C				SCALE: NTS			
SHEET 1 OF 1				REV. -			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[EB147A-03-D](#) [EB147A-05-D](#) [EB147A-06-D](#) [EB147A-04-D](#) [EB147A-02-D](#)