

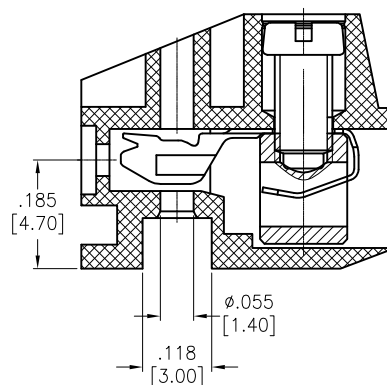


APPROVED: \_\_\_\_\_  
 DATE: \_\_\_\_\_ TITLE: \_\_\_\_\_

Rev	AWO #	Description	Date	Appr
-		RELEASED	3/12/15	
A		UPDATED DRAWING	6/12/17	HR/AC

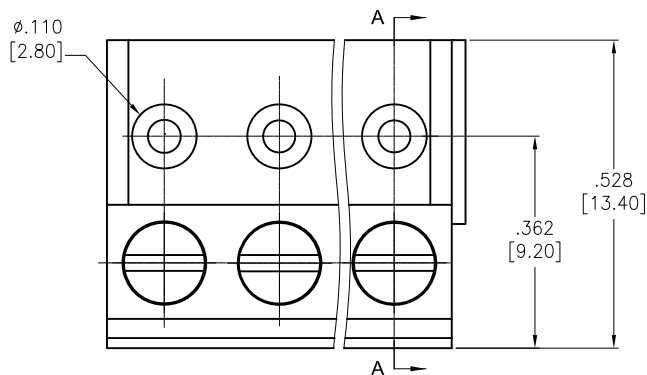

SECTION A-A

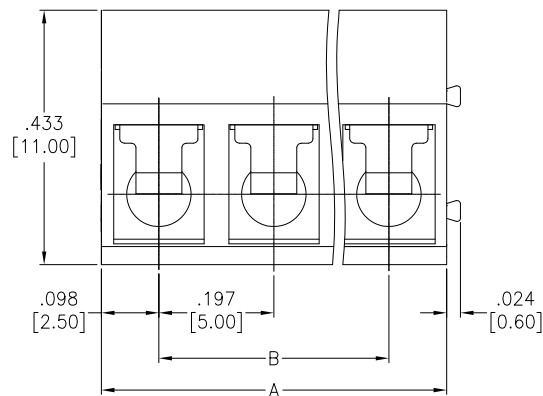

# SPECIFICATIONS:

## Material:

Insulator: PA66, rated UL 94V-0

Insulator color: Black

Clamp: Phosphor Bronze, Nickel plated

Cage: Brass, Nickel plated

Screw: M2.5 Steel, Zinc plated

## Electrical:

Voltage rated: 300 V

Current rated: 10 A

Contact resistance: 20 mΩ

Insulation resistance: 500 MΩ @ 500 VDC

Wire range: 28-16AWG, 1.5mm<sup>2</sup>

Withstanding voltage: 2000V AC/1 Min

Torque: 0.4N-m, 3.6 Lb-In

Strip length: 4.5-5mm

## Temperature Rating:

Operating temperature: -30°C to +120°C

## Environmental:

Lead free, RoHS compliant.



Positions: 2 thru 24

A = .197 [5.00] x No. of Positions

B = .197 [5.00] x No. of Spaces

UNLESS OTHERWISE SPECIFIED  
 ALL DIMENSIONS ARE INCHES [MM]  
 TOLERANCES: EXCEPT AS NOTED

INCHES		HOLES	
.X	± .10	Ø.X	± .10
.XX	± .020	Ø.XX	± .015
.XXX	± .015	Ø.XXX	± .010

APPROVALS		DATE
DRAWN	AY	3/12/15
CHECKED	YC	3/12/15
APPROVED		

# ADAM TECH

909 Rahway Avenue, Union, NJ 07083

Phone: 908-687-5000 Fax: 908-687-5710

TITLE			
EURO BLOCK, .197 [5.00] PITCH			
SIZE	PART NO.	REV.	
X	EBJA-XX-C-BK	A	
REF:	S00067C	SCALE:	NTS
SHEET 1 OF 1			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[EBJA-02-C-BK](#) [EBJA-05-C-BK](#) [EBJA-04-C-BK](#) [EBJA-06-C-BK](#) [EBJA-03-C-BK](#) [EBJA-10-C-BK](#) [EBJA-08-C-BK](#)