


APPROVED: \_\_\_\_\_  
DATE: \_\_\_\_\_ TITLE: \_\_\_\_\_

Rev	AWO #	Description	Date	Appr
-		RELEASED	11/8/04	
A		REDRAWN	8/26/11	
B		REVISED SPEC.	06/13/12	

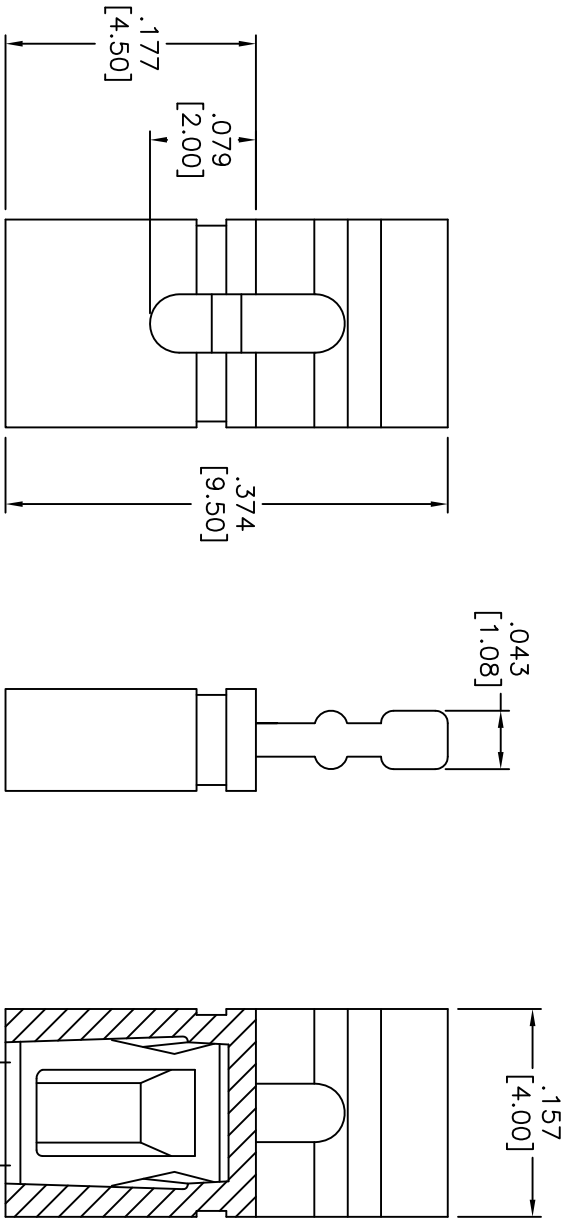

**SPECIFICATIONS:**

**Material:**  
Insulator: Nylon 66, rated UL 94V-2  
Insulator color: Black  
Contacts: Phosphor Bronze  
Plating:  
Gold Flash over Nickel underplate overall  
**Electrical:**  
Current rating: 2 Amp max  
Contact resistance: 30 mohms max  
Insulation resistance: 1000 Mohms min  
Dielectric withstanding voltage: 650 VAC for 1 minut  
Temperature Rating:  
Operating temperature: -55°C to +105°C  
**Environmental:**  
Lead free, RoHS compliant.



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED				<b>ADAM TECH</b> 909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710			
INCHES				Holes			
.X ± .10				ØXX ± .10			
.XX ± .020				ØXXX ± .015			
.XXX ± .015				ØXXX ± .010			
APPROVALS				DATE			
DRAWN				11/8/04			
SS							
CHECKED							
APPROVED							
TITLE				MINI SHUNT, .374 [9.50] HANDLE,			
GOLD PLATED							
SIZE				PART NO.			
X				MS2H-1-G			
REF:				S00076T			
SCALE:				NTS			
SHEET				1 OF 1			
REV.				B			

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[MS2H-1-G](#)