


Rev	AWO #	Description	Date	Appr
-		RELEASED	3/17/14	

APPROVED: \_\_\_\_\_  
 DATE: \_\_\_\_\_ TITLE: \_\_\_\_\_

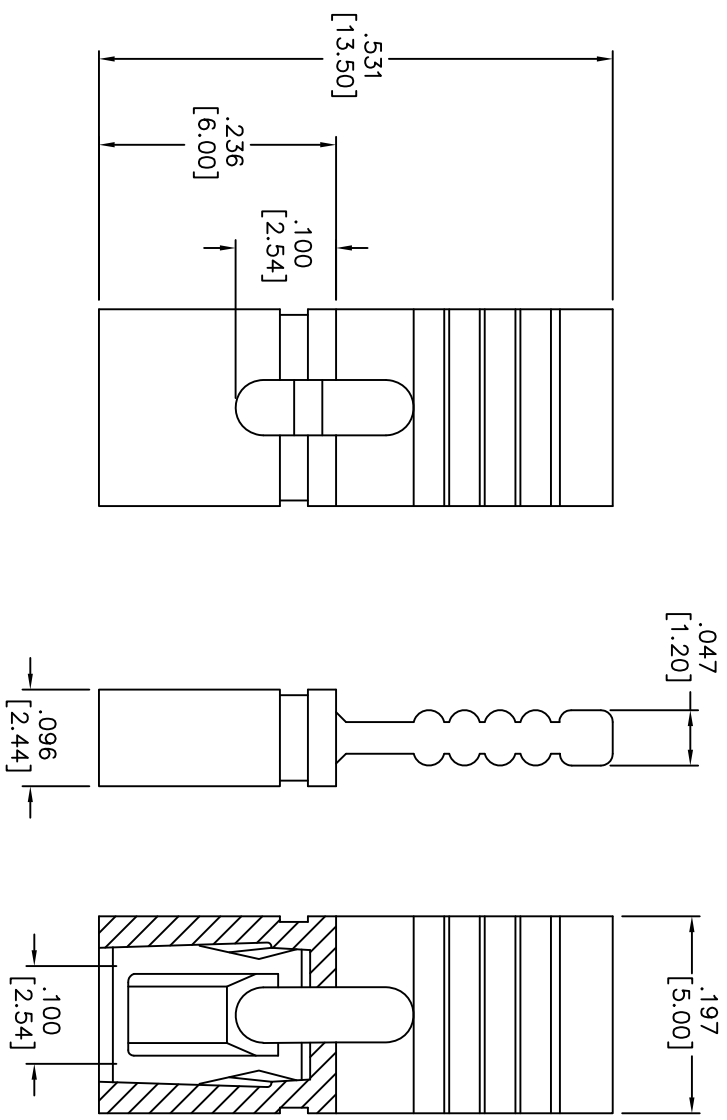

**SPECIFICATIONS:**

- Material: Nylon 66, rated UL 94V-0
- Insulator color: Black
- Contacts: Phosphor Bronze
- Plating: 10u" Gold over Nickel underplate overall
- Electrical:
  - Current rating: 3 Amp max
  - Contact resistance: 30 mohms max
  - Insulation resistance: 1,000 Mohms min
  - Dielectric withstanding voltage: 650 VAC for 1 minute
- Temperature Rating: Operating temperature: -55°C to +105°C
- Environmental: Lead free, RoHS compliant.



**ADAM TECH**

909 Rahway Avenue, Union, NJ 07083  
 Phone: 908-687-5000 Fax: 908-687-5710

TITLE: .100 [2.54] MINI SHUNT, HANDLE TOP  
 .531 [13.50] HEIGHT, 10u" GOLD PLATED

UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED INCHES		HOLE SIZE	
.X ± .10	ØX ± .10	ØXX ± .015	ØXXX ± .010
.XX ± .020	ØXX ± .015	ØXXX ± .010	
.XXX ± .015	ØXXX ± .010		
APPROVALS		DATE	
DRAWN	HR	3/17/14	
CHECKED	SL	3/17/14	
APPROVED		SIZE	PART NO.
		X	MSBH-G-10
		REF:	S00076T
		SCALE:	NTS
		SHEET	1 OF 1

6 5 4 3 2 1

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[MSBH-G-10](#)