
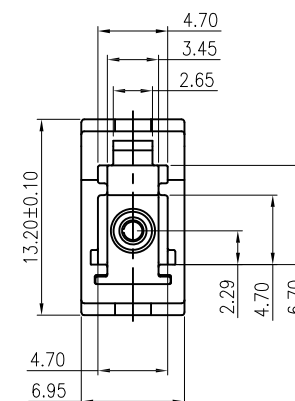
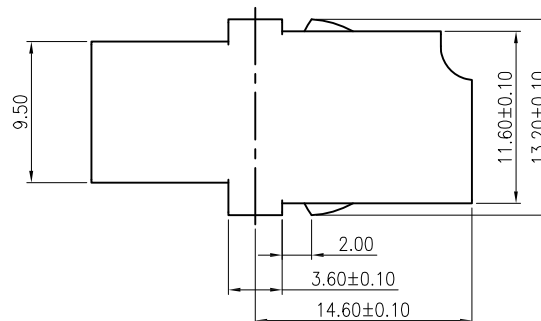
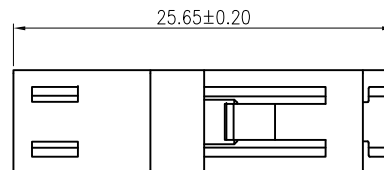


APPROVED: _____
 DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	9/8/20	

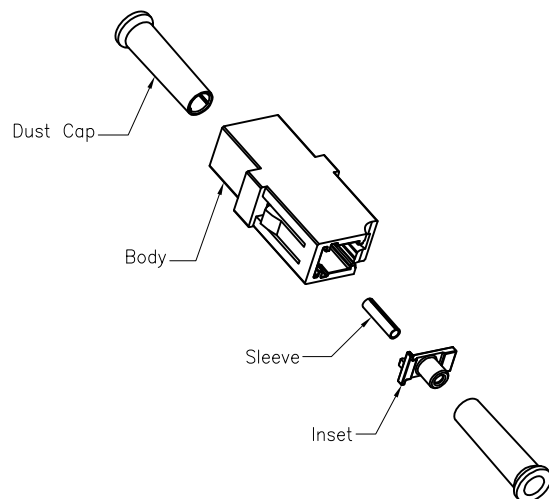

SPECIFICATIONS:

Material:
 Housing: PBT, rated UL 94V-0, Color: See Chart
 Cap: PP, rated UL 94V-0, Color: White
 Sleeve: Zirconia Ceramic
 Electrical:

Standards of IEC 61754-20, YD/T 1272.1-2003
 Repeatability: 500 min times
 Insertion loss: 0.2dB max
 Interchangeability: 0.2dB
 Temperature Rating:
 Operating temperature: -40°C to +85°C
 Environmental:
 Lead free, RoHS compliant.



OPLC1BNNC1NA	PBT Beige	PP White
OPLA1BNNC1NA	PBT Green	PP White
OPLB1BNNC1NA	PBT Blue	PP White
Part name	Material、Color	CAP Color

UNLESS OTHERWISE SPECIFIED
 ALL DIMENSIONS ARE MILLIMETERS
 TOLERANCES: EXCEPT AS NOTED
 MM ANGLE
 X. ± 0.35 X.* ± 2°
 .X ± 0.30 .X* ± 1°
 .XX ± 0.25 .XX* ± 0.5°
 .XXX ± 0.15 .XXX* ± 0.5°

APPROVALS		DATE
DRAWN	OW	9/8/20
CHECKED	JL	9/8/20
APPROVED		

ADAM
TECH
 INTERCONNECTS

909 Rahway Avenue,
 Union, NJ 07083
 Phone: 908-687-5000
 Fax: 908-687-5710

TITLE
 OPTICAL LC ADAPTERS, APC&PC&MM, 1 PORTS
 SHORT EARS, WITH LC DUST CAP

SIZE	PART NO.	REV.
X	OPLX1BNNC1NA	-
REF: S00005C	SCALE: NTS	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[OPLB1BNNC1NA](#)