
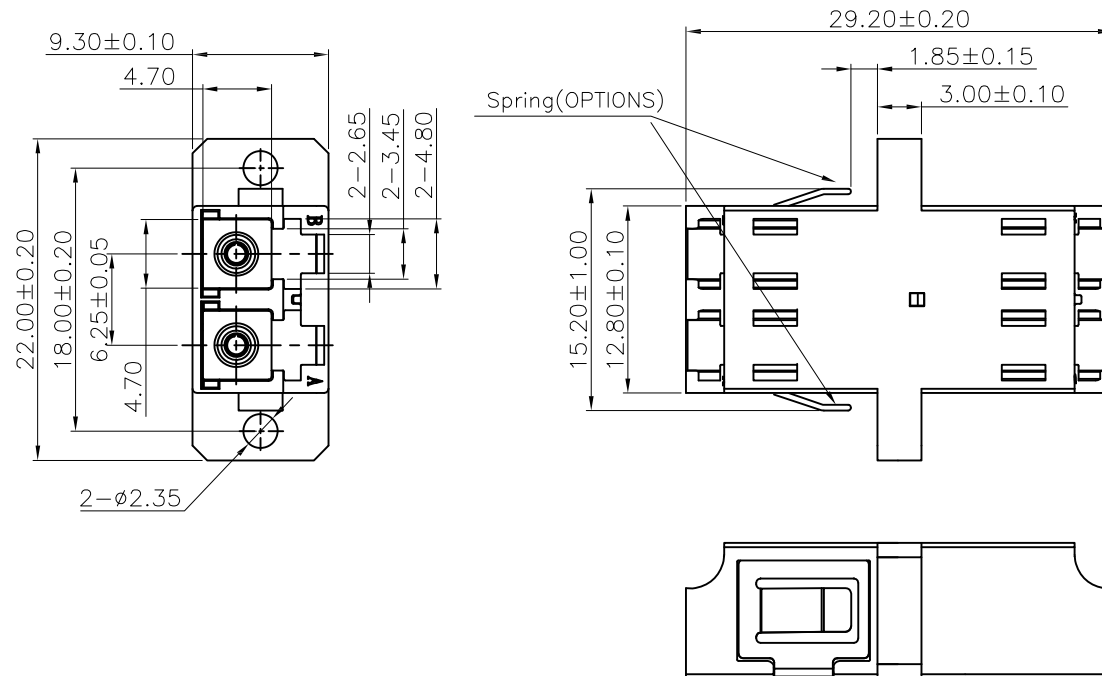


APPROVED: _____

DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	9/14/20	

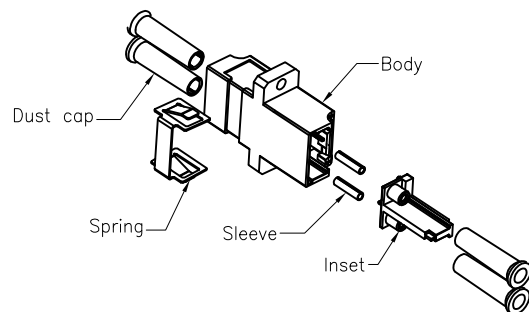

SPECIFICATIONS:

Material:

Housing: PBT, rated UL 94V-0, Color: See Chart

Cap: PP, rated UL 94V-0, Color: White

Spring: SUS

Sleeve: Zirconia Ceramic

Electrical:

Standards of IEC 61754-20, YD/T 1272.1-2003

Repeatability: 1000 min times

Insertion loss: 0.2dB max

Interchangeability: 0.2dB

Temperature Rating:

Operating temperature: -40°C to +85°C

Environmental:

Lead free, RoHS compliant.



OPLC2ANNC1NA	PBT Beige 7501U	W/O
OPLA2ANNC1NA	PBT Green 7737C	W/O
OPLB2ANNC1NA	PBT Blue 2184C	W/O
OPLC2ANNC1PA	PBT Beige 7501U	W/
OPLA2ANNC1PA	PBT Green 7737C	W/
OPLB2ANNC1PA	PBT Blue 2184C	W/
Part name	Material, Color	EMI

UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE MILLIMETERS
TOLERANCES: EXCEPT AS NOTED
MM ANGLE
.X. ± 0.35 .X.* ± 2°
.XX ± 0.30 .XX* ± 1°
.XX ± 0.25 .XX* ± 0.5°
.XXX ± 0.15 .XXX* ± 0.5°

APPROVALS		DATE
DRAWN	OW	9/14/20
CHECKED	JL	9/14/20
APPROVED		

ADAM
TECH
INTERCONNECTS

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE
OPTICAL LC ADAPTERS, APC&PC&MM, 2 PORTS
LONG EARS, WITH LC DUST CAP

SIZE X	PART NO. OPLX2ANNC1XA	REV. -
REF: S00005C	SCALE: NTS	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[OPLC2ANNC1PA](#) [OPLB2ANNC1NA](#)