
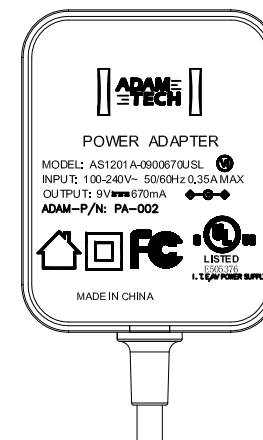


APPROVED: _____
 DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	3/18/21	
A		ADDED TOLERANCE	6/10/21	WX/AC
B		UPDATE SPEC.	11/30/22	LH/SL1

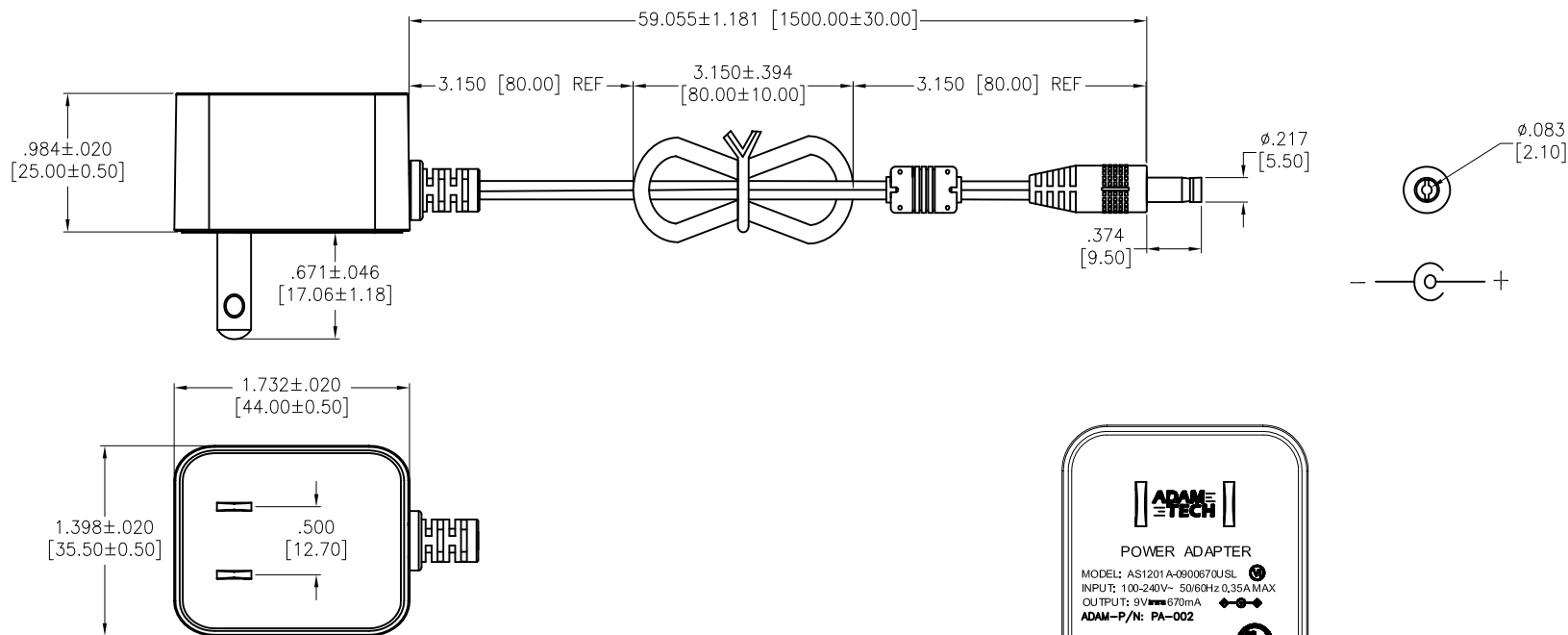

SPECIFICATIONS:

Connector

P1: Power Adapter, NEMA 1-15P

P2: DC Plug, W/Strain Relief, 5.5*2.1*9.5mm

Overmold Color: Black PVC-65P

CABLE:

UL2468: 22AWG(17*0.16)*2C 80°C 300V VW-1, Jacket Color: Black

Electrical:

Input:

Voltage: 100Vac to 240Vac

Current: 0.35A Max. @ 100Vac input & max load

Frequency: 60Hz / 50Hz

Output:

Voltage: 9.0V

Current: 0.67A max.

Load Regulation: ±5%

Line Regulation: ±3%

Insulation Resistance: 10 Mohms min @ 500VDC

Dielectric withstanding voltage (Hi-pot): 3,000V AC For 1 Minute

Leakage Current: 0.25mA max. @ 230V AC/50Hz

Temperature Rating:

Operating Temperature: 0°C to +40°C

Storage Temperature: -40°C to +70°C

Environmental:

Lead free, RoHS compliant. **RoHS COMPLIANT**

UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM]. TOLERANCES: EXCEPT AS NOTED

INCHES	HOLES
.X ± .10	Ø.X ± .10
.XX ± .020	Ø.XX ± .015
.XXX ± .015	Ø.XXX ± .010

DRAWN	WX	3/18/21
CHECKED	AC	3/18/21
APPROVED		

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY AND SHOULD NOT BE USED WITHOUT PRIOR WRITTEN PERMISSION FROM ADAM TECH

ADAM TECH

909 Rahway Avenue,
 Union, NJ 07083
 Phone: 908-687-5000
 Fax: 908-687-5710

TITLE
 POWER ADAPTER, NEMA 1-15 TO 2.1 X 5.5 X 9.5
 DC PLUG, 9 VOLT, 0.67 AMP, UL2468 22 AWG

SIZE X	PART NO. PA-002	REV. B
REF: -	SCALE: NTS	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[PA-002](#)