

6

5

4

3

2

1

APPROVED: _____

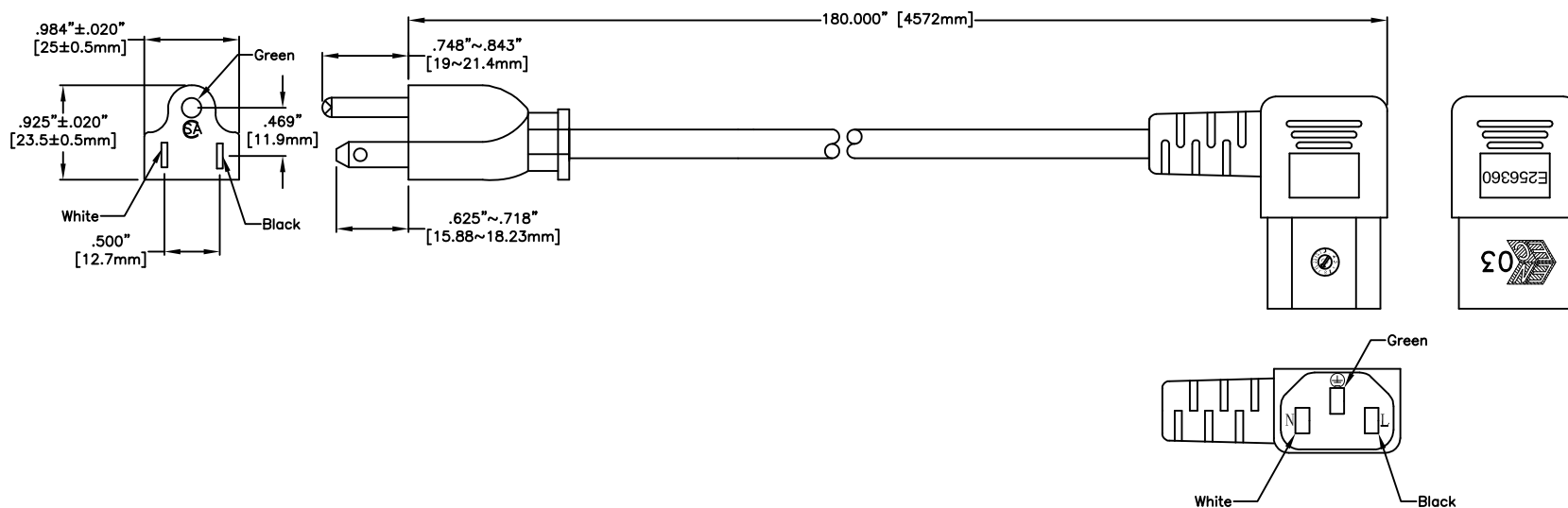
DATE: _____ TITLE: _____

CUSTOM CABLE ASSEMBLIES ARE NON-CANCELLABLE/NON-RETURNABLE

Rev	AWO #	Description	Date	Appr
-		RELEASED	10/5/15	

P1

P2

**SPECIFICATIONS:****Electrical:**

Current rating: 10 Amps

Voltage rating: 125 VAC

Connectors:

P1 = NEMA 5-15P, Color: Black

P2 = IEC C13 Female, Right Angle

Cable:

14AWG/3C SJT, 60°C, Wire color: Black, White, Green

Jacket color: Black

Electrical Test:

All assemblies must be 100% tested for shorts, open continuity and physical appearance.

Environmental:

Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE MM [INCHES] TOLERANCES: EXCEPT AS NOTED INCHES HOLES .X ±.10 Ø.X ±.10 .XX ±.020 Ø.XX ±.015 .XXX ±.015 Ø.XXX ±.010			ADAM TECH 909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710		
APPROVALS			TITLE NORTH AMERICAN POWER CORD, 15 FT, 14/3 SJT, 60°C, BLACK		
DRAWN	AY	10/5/15	SIZE X	PART NO. PC-0103150BA03	REV. -
CHECKED	LL	10/5/15	REF: S00014C	SCALE: NTS	SHEET 1 OF 1
APPROVED					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[PC-0103150BA03](#)