


Rev	AWO #	Description	Date	Appr
-		RELEASED	5/23/16	

APPROVED: _____

DATE: _____ TITLE: _____

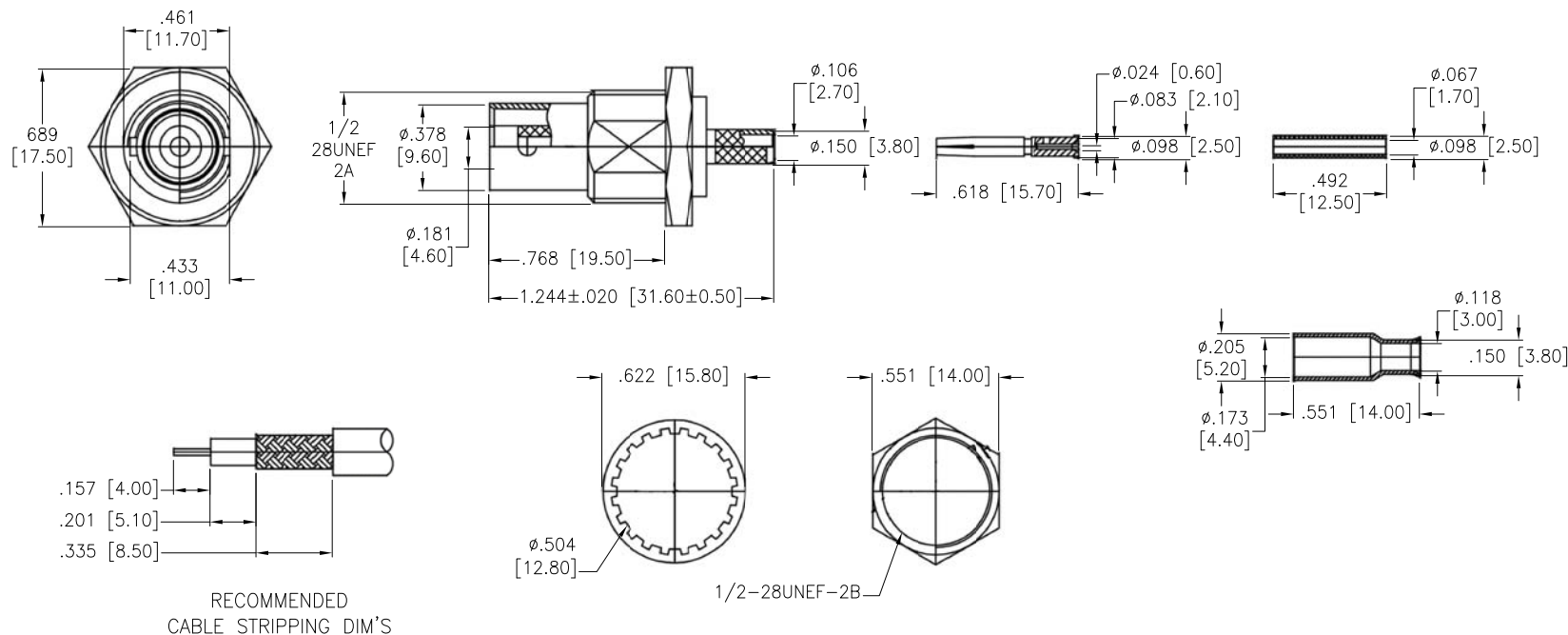

NUT	ZINC	NICKEL
LOCK WASHER	IRON	NICKEL
GASKET	RUBBER	NATURAL
FERRURLE	BRASS	NICKEL
SLEEVE	POM	NATURAL
CONTACT PIN	BRASS	NICKEL
WASHER	IRON	NICKEL
INSULATOR	POM	NATURAL
BODY	ZINC	NICKEL
DESCRIPTION	MATERIAL	FINISH

Electrical:

Nominal Impedance: 50 ohms

Frequency range: 0–4 GHz

Working Voltage: 500 Vrms max

Dielectric withstanding voltage: 1,500 Vrms min

Contact Resistance: 2.1 Milliohms max (Center Contact)

0.2 Milliohms max (Outer Contact)

Insulator Resistance: 5000 Megohms min

Temperature Rating:

Operating temperature: -65°C to $+85^{\circ}\text{C}$

Environmental:

Lead free, RoHS compliant.



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE INCHES [MM]
TOLERANCES: EXCEPT AS NOTED
INCHES HOLES

INCHES	TOLERANCE	MILLIMETERS	TOLERANCE
.X	± .10	Ø.X	±.10
.XX	± .020	Ø.XX	±.015
.XXX	± .015	Ø.XXX	±.010

APPROVALS		DATE
DRAWN	HR	5/23/16
CHECKED	OC	5/23/16
APPROVED		

ADAM TECH

909 Rahway Avenue, Union, NJ 07083

Phone: 908-687-5000 Fax: 908-687-5710

TITLE	BNC FEMALE BULKHEAD CRIMP FOR RG174, RG178, RG196, RG316
-------	---

SIZE X	PART NO. RF1-04A-D-02-50	REV. -
-----------	-----------------------------	-----------

REF:	S00049T	SCALE:	NTS	SHEET	1	OF	1
------	---------	--------	-----	-------	---	----	---

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[RF1-04A-D-02-50](#)