


APPROVED: \_\_\_\_\_  
 DATE: \_\_\_\_\_ TITLE: \_\_\_\_\_

Rev	AWO #	Description	Date	Appr
-		RELEASED	4/22/16	

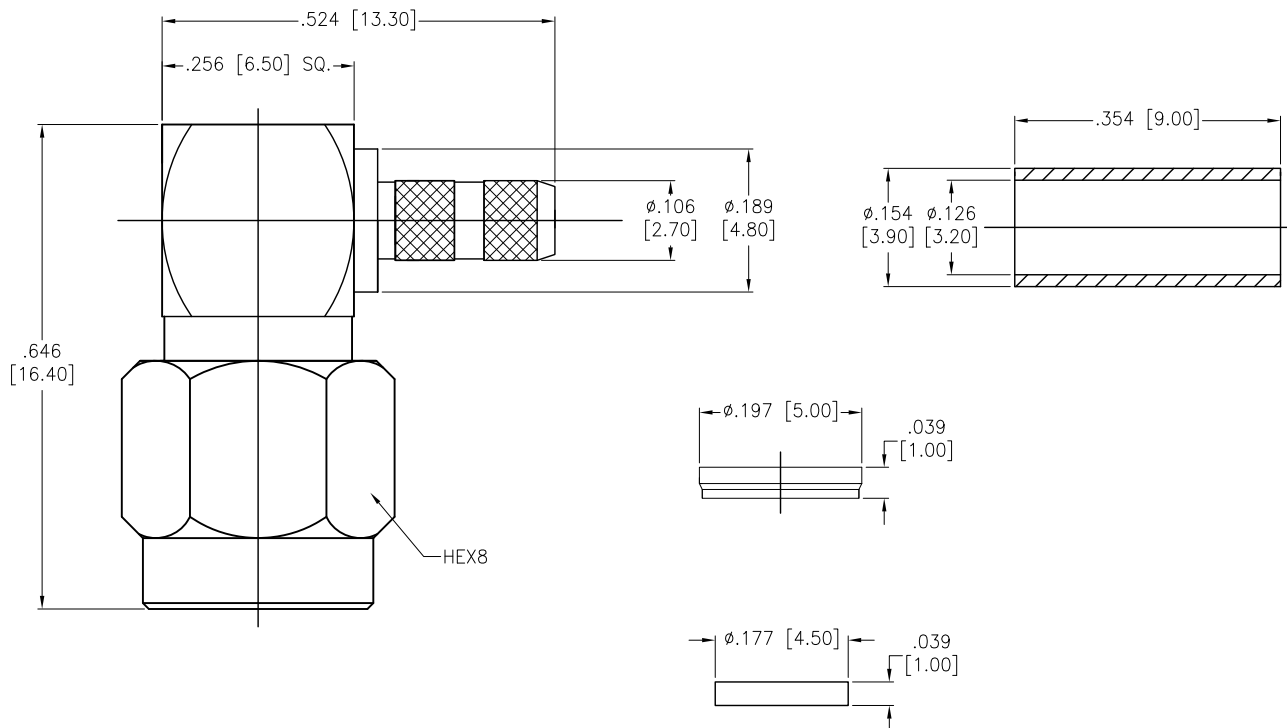

FERRULE	COPPER	NICKEL
CONTACT PIN	BRASS	GOLD
INSULATOR	TEFLON	WHITE
BODY	BRASS	GOLD
DESCRIPTION	MATERIAL	FINISH

#### SPECIFICATIONS:

Electrical:  
 Nominal Impedance: 50 ohms  
 Frequency range: 0–6 GHz  
 VSWR: 1.5 max.  
 Working Voltage: 500 Vrms  
 Insulator Resistance: 5,000 ohms min.  
 Temperature Rating:  
 Operating temperature: –55°C to +155°C  
 Environmental:  
 Lead free, RoHS compliant.



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE INCHES [MM] TOLERANCES: EXCEPT AS NOTED INCHES HOLES .X ± .10 Ø.X ± .10 .XX ± .020 Ø.XX ± .015 .XXX ± .015 Ø.XXX ± .010			<b>ADAM TECH</b> 909 Rahway Avenue, Union, NJ 07083 Phone: 908-687-5000 Fax: 908-687-5710	
APPROVALS DRAWN HR 4/22/16 CHECKED LW 4/22/16 APPROVED			TITLE SMA MALE CRIMP RIGHT ANGLE, RG316 RG174	
SIZE X			PART NO. RF2-153-T-02-50-G	REV. -
REF: S00128C			SCALE: NTS	SHEET 1 OF 1

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[RF2-153-T-02-50-G](#)