
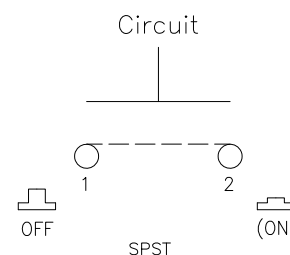
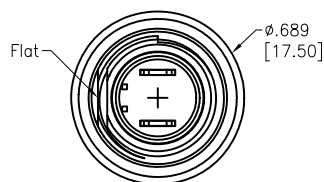
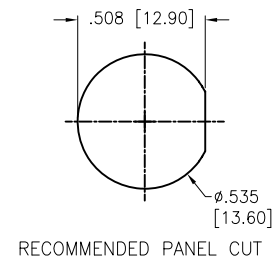
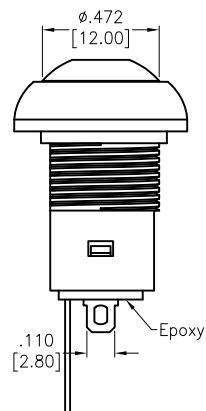


APPROVED: _____

DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	2/18/21	
A		UPDATE DRAWING	6/21/21	WX/RC

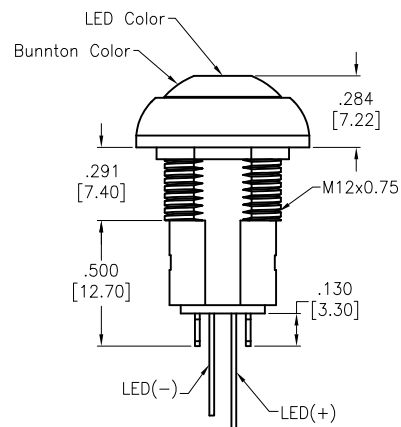

Button Color		LED Color	
R	Red	R	Red
G	Green	G	Green
Y	Yellow	Y	Yellow
O	Orange	B	Blue
B	Blue	W	White
W	White		
K	Black		

SPECIFICATIONS:

Material:

Case: Polyamide66, rated UL 94V-0

Bushing&Button: Polyamide66

Terminal: Gold over Silver Plated

Electrical:

Rating: 100mA 24VDC

2A 125VAC

Contact resistance: 50 mΩ max

Insulation resistance: 1G-ohms min @500VDC

Dielectric withstanding voltage: 1,000 VAC rms

Mechanical:

Torque: 0.5Nm max

Operating Force: 2~5N

Temperature Rating:

Operating temperature: -30°C to +85°C

Environmental:

IP67 front panel protection

Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE INCHES [MM]
TOLERANCES: EXCEPT AS NOTED
INCHES HOLES

.X	± .10	Ø.X	±.10
.XX	± .020	Ø.XX	±.015
.XXX	± .015	Ø.XXX	±.010

APPROVALS		DATE
DRAWN	LH	2/18/21
CHECKED	AC	2/18/21
APPROVED		

ADAM
TECH

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE
IP67 PUSH BUTTON SWITCH, SOLDER TYPE, LIGHTED,
SPST, OFF-ON, GOLD OVER SILVER PLATED

SIZE X	PART NO. SW-PB11-4CSXX-10	REV. A
-----------	------------------------------	-----------

REF: S00198T	SCALE: NTS	SHEET 1 OF 1
--------------	------------	--------------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[SW-PB11-4CSKR-10](#) [SW-PB11-4CSKG-10](#)