

IDC Ribbon Cable

Series 2026



UL Approved cable is available in all industry standard sizes from 9 to 64 conductors, in both grey and rainbow format. AVX can also offer cable which is CSA Approved. For details please contact your local sales office.

TECHNICAL SPECIFICATION

Cable Type:

Flat cable, UL listed, polyvinyl chloride (PVC) insulation. Standard round conductor 28 AWG, 0.381mm (0.015" nominal OD, 7/36 tin coated copper).

Conductor Spacing:


0.050" $\pm$ 0.002"
(1.27mm $\pm$ 0.051mm), center to center

Standard Reel Length:

100 meters (328 feet)

Color:

Grey with marker on reference edge. Rainbow colored, in sequence from reference edge - Brown/Red/Orange/Yellow/Green/Blue/Violet/Grey/White/Black. Colors repeat.

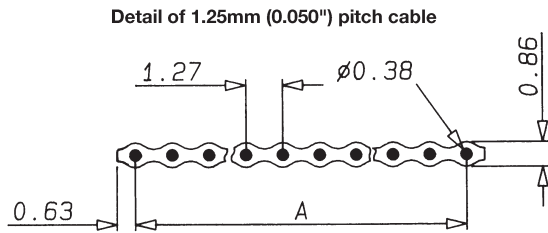

Ordering Code for 0.100" (2.54mm) pitch cable

Reference Number	No. of Contacts	Color
90-2026-7106-01-000	16 position	Grey
90-2026-7096-01-000	24 position	Grey

For use with Series 8284 only. See page 8.

Ordering Code for 0.050" (1.27mm) pitch cable

No. of Conductors	Color	Reference Number	Dim. A
14	Grey	90-2026-7017-01-000	0.650" (16.51mm)
14	Rainbow	90-2026-7016-01-000	0.650" (16.51mm)
20	Grey	90-2026-7013-01-000	0.950" (24.13mm)
26	Grey	90-2026-7011-01-000	1.25" (31.75mm)
34	Grey	90-2026-7009-01-000	1.65" (41.91mm)
40	Grey	90-2026-7007-01-000	1.95" (49.53mm)
40	Rainbow	90-2026-7006-01-000	1.95" (49.53mm)
50	Grey	90-2026-7005-01-000	2.45" (62.23mm)
60	Grey	90-2026-7003-01-000	2.95" (74.93mm)
64	Grey	90-2026-7001-01-000	3.15" (80.01mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AVX:](#)

[902026709501000](#) [902026709601000](#)