


Angle sensor (Hall)

91680




Connector

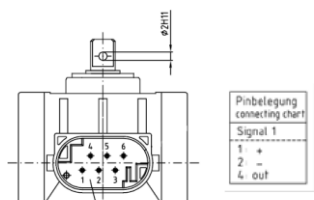


AMP-Kupplung/female connector
AMP-Nr. 114-18063-21/Kodierung A ④
MQS-Gegenstecker/connector housing
AMP-Nr. 1-967616-1
Steckerkontakt/terminals
AMP-Nr. 0-096 3727-2 ④ ⑤
Blindstopfen/blind plug
AMP-Nr. 0-096 7056-1
Einzelleiterabdichtung/core seal
AMP-Nr. 0-096 7067-1

Dimensions

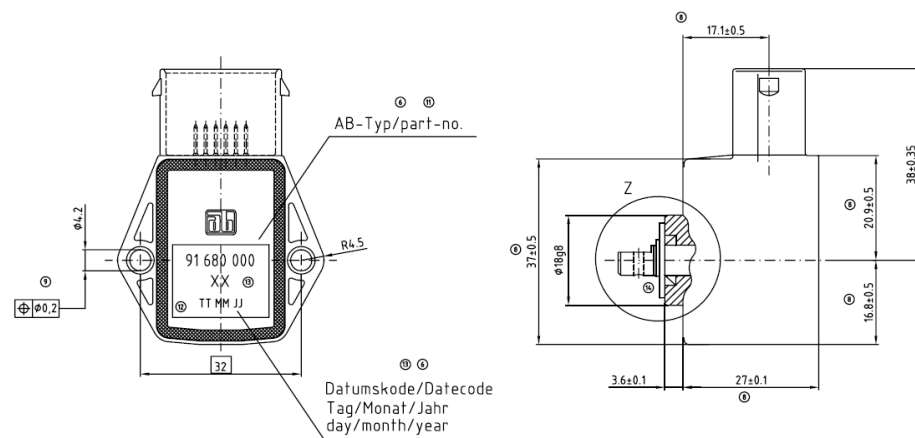

Supply Current	5 V ± 0.25 V 6 mA max.	Temperature range	- 40 °C to + 120 °C
Output signal	Voltage interface, 1 signal	Sealing grade	Protection class according to DIN 40050-9 housing IP6K6 connector IP6K9K
Terminals Sensor	Gold plated	Vibration	Robust against higher requirements
Specification	DHWS670671-6a	Drawing	91680000 Index 14

Angle range (degrees)

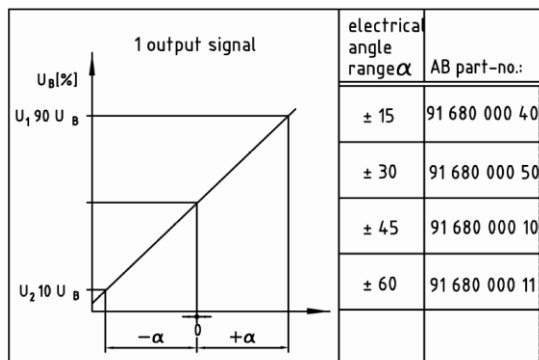

General Note This datasheet does not give any information on product availability. The information given is just meant to describe the product and is not to be considered as guaranteed characteristics in the legal sense. All products are subject to design changes in the interest of further technical development.

Copyright: AB Elektronik GmbH (GER) ▪ info@abelektronik.de ▪ www.abelektronik.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kyocera AVX:](#)

[9168000010](#)