

ROHS COMPLIANCE

CONTROLLED COPY
15.03.12
N.L.I. R&D

20A 125V OPEN CORD SET (USA)

1. UNSHIELDED, 3 CONDUCTORS
2. RATING MIN.: 20A, 125V
3. POWER CORD LENGTH: 2m TYP.
4. JACKET COLOR: BLACK.
5. TEMPERATURE RATING MIN.: 75°C. $\triangle 3$
6. COMPONENTS DESCRIPTION:

1. CABLE:


- TYPE: SJT, SJTO
- CONDUCTORS CROSS-SECTION AREA MIN.: 2.5mm²/12AWG
- RATED MIN.: 20A, 125V;
- SAFETY MARKING: UL MARK/CSA

$\triangle 1$

2. CONNECTOR:

- IEC 60320-1 CERTIFIED, UL/CSA APPROVED, TYPE C19;
- RATED MIN.: 20A, 125V;
- SAFETY MARKING: CERTIFICATION AGENCY MARK(S), UL/CSA MARKS, RATING, TYPE

$\triangle 2$

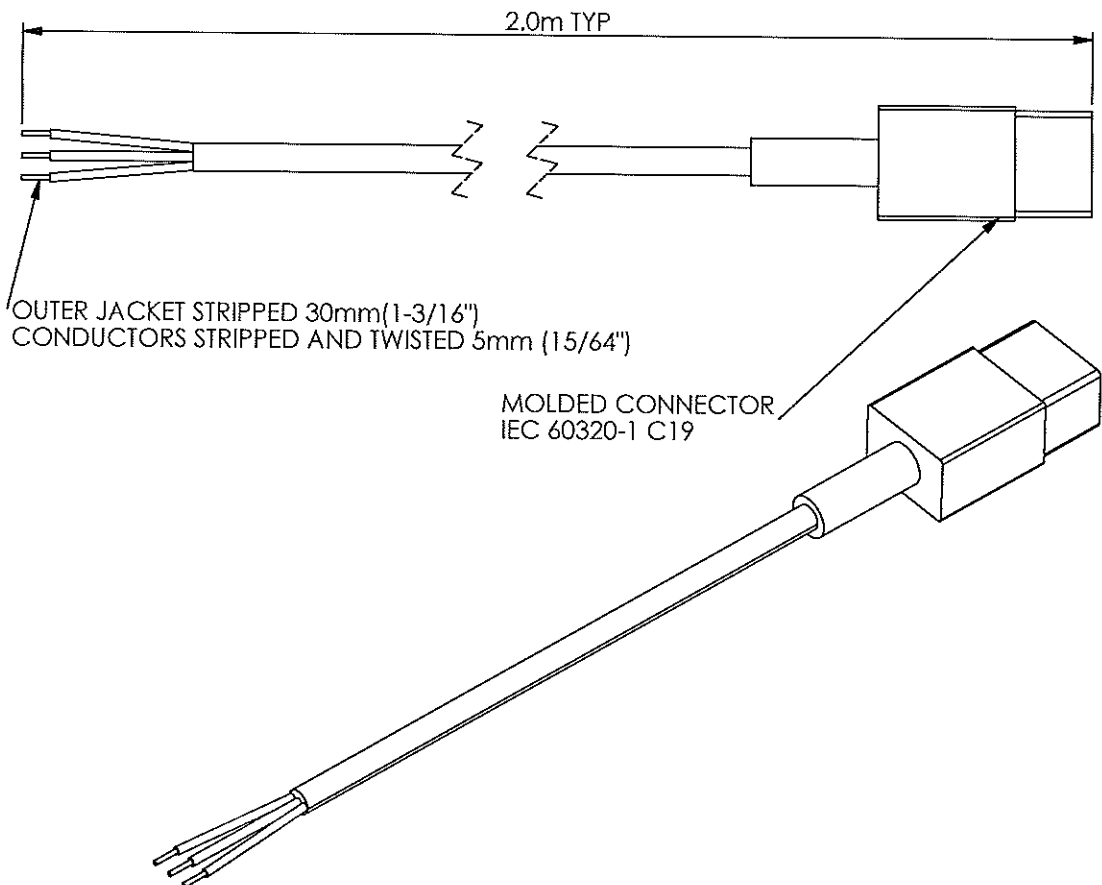

NOTE:
ROHS COMPLIANCE
REFER TO D-L GROUP
GREEN PROCUREMENT
GUIDELINE : DL-EMS-010_

C	2-3	REV. B3	28.FEB.2012					5
B	1	REV. B2	26.JAN.2012					
A	NEW DRAWING		17.JAN.2012					
D	CONTENTS		DATE	ENGR	CHK	APPD		
MATERIALS		TITLE	20A 125V OPEN CORD SET (USA)					
FINISH		DRAWING No.	IA706-81-12 - C					
			TDK-Lambda					

DWG	S.MIKI	28.1.2012	SHEET OF	
ENGR	S.MIKI	28.2.2012	1 1	
CHK		28.02.12	SCALE	NONE
APPD	Kami's.	Feb-28-12	UNITS	mm
ISSUED		Feb-28-12	DATE	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TDK-Lambda:](#)

[HFE/C19U](#)